


TABLE A

PART NO	LENGTH
ZL-D3-CBL18	0.5m [1.6 ft]
ZL-D3-CBL18-1	1.0m [3.3 ft]
ZL-D3-CBL18-2	2.0m [6.6 ft]

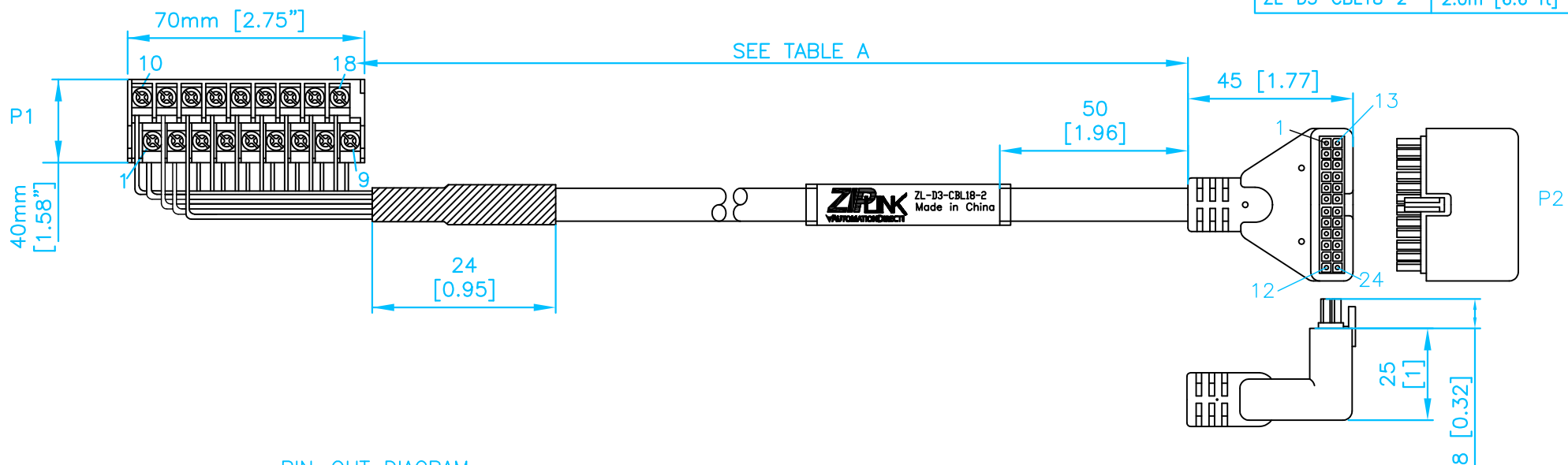

PIN-OUT DIAGRAM

P1	P2	P1	P2
		15	9
10	BROWN	2	LIGHT GREEN
	BROWN/WHITE	14	LIGHT BLUE
1	RED	6	PINK
11	ORANGE	10	BLUE
2	GREEN	11	GREEN/BLACK
12	VIOLET	12	WHITE
3	RED/WHITE	21	RED/BLACK
13	ORANGE/WHITE	15	ORANGE/BLACK
4	GREEN/WHITE	16	BLACK
14	VIOLET/WHITE	17	YELLOW
	GRAY	8	BLACK/WHITE
5	GRAY/BLACK	22	YELLOW/BLACK
	20 CUT AND INSULATE	9	1
		18	7
		8	13
		20	19

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 18 position terminal block for Direct Logic DL305 PLC, AutomationDirect part # D3-16IOCON
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-D3-CBL18-n	
Rev: A	Date: 07/2009
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL305 PLC Cable	