


# Electromechanical Relay Selection Guide

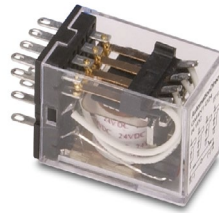

Specification	QL Series	QM Series	RS Series Card Relays
<b>Coil Voltages</b>	110/120VAC, 220VAC, 24VDC	110/120VAC, 220VAC, 24VDC	24VDC
<b>Configuration</b>	2PDT, 4PDT	2PDT, 4PDT	SPST (up to six relays)
<b>Contact Rating</b>	10A	5A DPDT ; 3A 4PDT	5A
<b>Base Socket</b>	8 or 14 pin spade terminal	8 or 14 pin spade terminal	-
<b>Agency Approvals</b>	UL Recognized (#E222847), CE Certified (9667186-9811), CSA Certified (218218)	UL Recognized (#E222847), CE Certified (9667186-9811), CSA Certified (218218)	UL Recognized (E44592), CSA (LR20479) TUV (R95551729)
<b>Prices starting at</b>	\$10.00	\$4.75	\$31.50



Specification	78 Series	H782 Series	750R Series
<b>Coil Voltages</b>	110/120VAC, 220VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC
<b>Configuration</b>	SPDT, DPDT, 3PDT, 4PDT	4PDT	DPDT, 3PDT
<b>Contact Rating</b>	12 to 15A	3A, 5A	10A
<b>Base Socket</b>	5, 8, 11 or 14 pin spade terminal	14 pin spade terminal	11 pin
<b>Agency Approvals</b>	UL Recognized (E191059), CE, CSA 244610 (See specifications for additional information)	UL Recognized (E344123), cULus when used with 782-4C-SKT socket, CSA, CE, RoHS	UL Recognized file E191059, CE, CSA Certified 244610
<b>Prices starting at</b>	\$4.50	\$35.00	\$7.75



Specification	H750 Series	AD-PR Series	Force Guided Relays
<b>Coil Voltages</b>	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VDC, 24VAC, 24VDC	24VDC
<b>Configuration</b>	DPDT or 3PDT	SPDT, DPST, DPDT	4PST, 6PST
<b>Contact Rating</b>	12A	40A	5A
<b>Base Socket</b>	8-pin or 11-pin spade terminal,	Panel mount	10 or 14 pin spade terminal or DIN mount module
<b>Agency Approvals</b>	UL Recognized (E344123), cULus when used with 750 sockets, RoHS	UL Recognized E191059, CE Certified (9667186-9811), CSA Certified 244610, RoHS	UL file E146415
<b>Prices starting at</b>	\$47.75	\$14.75	\$12.00 (relay), \$29.00 (module)