


Electromechanical Relay Selection Guide

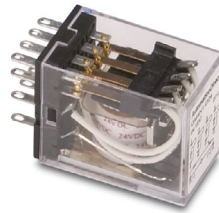

Specification	QL Series	QM Series	RS Series Card Relays
Coil Voltages	110/120VAC, 220VAC, 24VDC	110/120VAC, 220VAC, 24VDC	24VDC
Configuration	2PDT, 4PDT	2PDT, 4PDT	SPST (up to six relays)
Contact Rating	10A	5A DPDT ; 3A 4PDT	5A
Base Socket	8 or 14 pin spade terminal	8 or 14 pin spade terminal	-
Agency Approvals	UL Recognized (#E222847), CE Certified (9667186-9811), CSA Certified (218218)	UL Recognized (#E222847), CE Certified (9667186-9811), CSA Certified (218218)	UL Recognized (E44592), CSA (LR20479) TUV (R95551729)
Prices starting at	\$10.00	\$4.75	\$30.50



Specification	78 Series	H782 Series	750R Series
Coil Voltages	110/120VAC, 220VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC
Configuration	SPDT, DPDT, 3PDT, 4PDT	4PDT	DPDT, 3PDT
Contact Rating	12 to 15A	3A, 5A	10A
Base Socket	5, 8, 11 or 14 pin spade terminal	14 pin spade terminal	11 pin
Agency Approvals	UL Recognized (E191059), CE, CSA 244610 (See specifications for additional information)	UL Recognized (E344123), cULus when used with 782-4C-SKT socket, CSA, CE, RoHS	UL Recognized file E191059, CE, CSA Certified 244610
Prices starting at	\$4.50	\$25.50	\$7.75



Specification	H750 Series	AD-PR Series
Coil Voltages	120VAC, 240VAC, 12VAC, 12VDC, 24VAC, 24VDC	120VAC, 240VAC, 12VDC, 24VAC, 24VDC
Configuration	DPDT or 3PDT	SPDT, DPST, DPDT
Contact Rating	12A	40A
Base Socket	8-pin or 11-pin spade terminal,	Panel mount
Agency Approvals	UL Recognized (E344123), cULus when used with 750 sockets, RoHS	UL Recognized E191059, CE Certified (9667186-9811), CSA Certified 244610, RoHS
Prices starting at	\$34.75	\$14.75