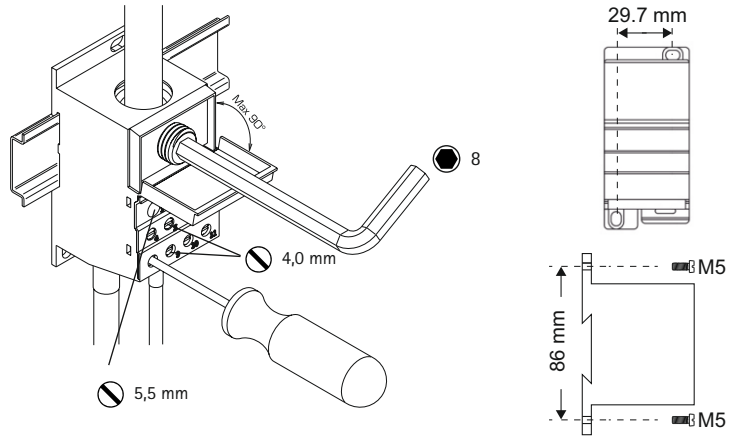

 
 


<b>38019</b>	<b>38019AL</b>
$I_n$ 400 A - IEC	400 A CU - IEC 300 A AL - IEC
310 A - UL	310 A - UL
$U_i$ 1000 V AC / 1500 V DC - IEC	
600 V AC/DC - UL	



TORQUE			
26 Nm 230 lb.in	95 - 150 mm <sup>2</sup> 3/0 AWG - 300*	95 - 185 mm <sup>2</sup> 3/0 AWG - 350*	1 × Ø20 mm 28 mm
3,5 Nm 31 lb.in	2,5 - 25 mm <sup>2</sup> 14 - 4 AWG	2,5 - 35 mm <sup>2</sup> 14 - 2 AWG	2 × Ø9 mm
2 Nm 18 lb.in	2,5 - 16 mm <sup>2</sup> 14 - 6 AWG		5 × Ø6,8 mm
	2,5 - 10 mm <sup>2</sup> 14 - 8 AWG		4 × Ø6,2 mm

\* in kcmil

Technical changes and errors as well as changes in appearance reserved.

BAV-00007-D | 19.06.2024