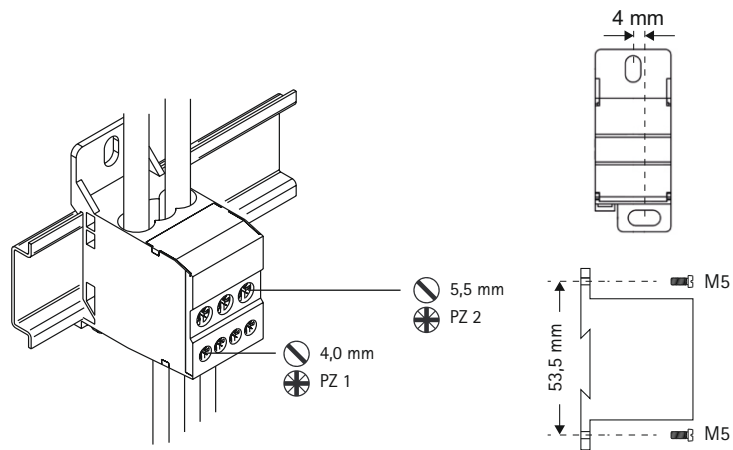

 
 


38049	38049AL
I_n 80 A - IEC	80 A CU - IEC 63 A AL - IEC
80 A - UL	80 A - UL
U_i 1000 V AC / 1500 V DC - IEC	
600 V AC/DC - UL	



TORQUE			
1,5 Nm 13,5 lb.in	2,5 - 16 mm ² 14 - 6 AWG	2,5 - 25 mm ² 14 - 4 AWG	3 × Ø7 mm 15 mm
0,8 Nm 7,2 lb.in	2,5 - 6 mm ² 14 - 10 AWG		4 × Ø4,5 mm 11 mm

Technical changes and errors as well as changes in appearance reserved.

BAV-00040-D | 19.06.2024