



 
 
38057

I_n 400 A CU - IEC
300 A AL - IEC

335 A - UL

U_i 1000 V AC / 1500 V DC - IEC
600 V AC/DC - UL

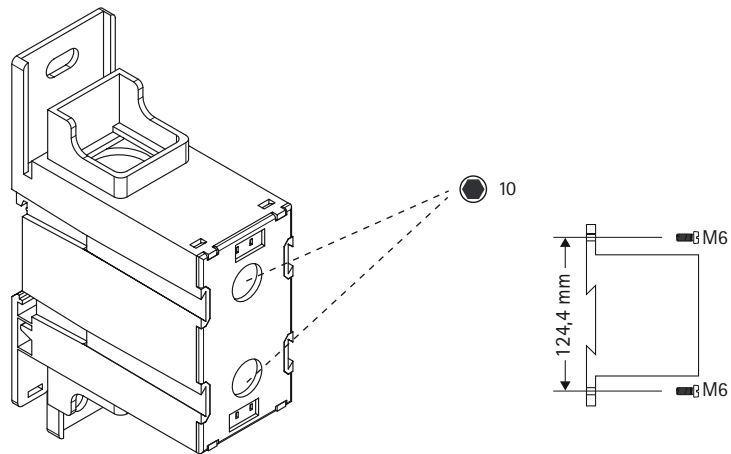

TORQUE			
15 Nm 130 lb.in	16 - 150 mm ² 6 AWG - 350 MCM	16 - 185 mm ² 6 AWG - 400 MCM	2 × Ø21 mm 33 mm

Technical changes and errors as well as changes in appearance reserved.

BAV-00050-C | 19.06.2024