
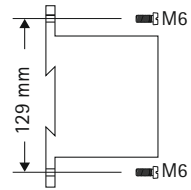


## 38059


 
 
$I_n$  800 A CU - IEC  
630 A AL - IEC

840 A - UL

$U_i$  1000 V AC / 1500 V DC - IEC  
600 V AC/DC - UL

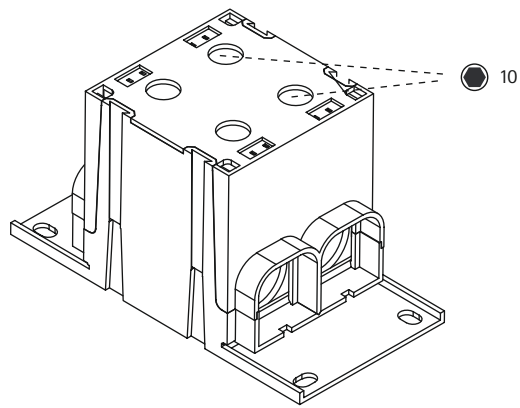

\* in kcmil

TORQUE			
15 Nm 130 lb.in	25 - 185 mm <sup>2</sup> 4 AWG - 500 MCM	25 - 240 mm <sup>2</sup> 4 AWG - 600 MCM	4 × Ø24 mm 33 mm

Technical changes and errors as well as changes in appearance reserved.

BAV-00053-C | 19.06.2024