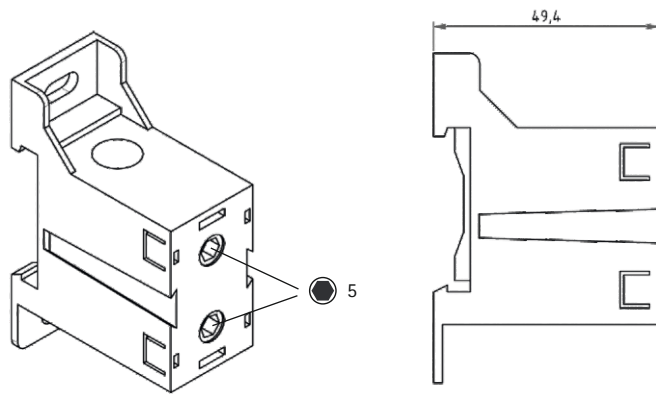

 
 


38064

I_n	175 A CU - IEC
	135 A AL - IEC
	175 A - UL
U_i	1000 V AC / 1500 V DC - IEC
	600 V AC - UL



TORQUE			
12 Nm 100 lb.in	35 - 50 mm ² 2 - 1 AWG	50 - 70 mm ² 1 - 2/0 AWG	2 x Ø11mm 18 mm
9 Nm 80 lb.in	10 - 25 mm ² 8 - 3 AWG	16 - 35 mm ² 6 - 2 AWG	
4 Nm 35 lb.in	2,5 - 6 mm ² 14 - 10 AWG	2,5 - 10 mm ² 14 - 8 AWG	

Technical changes and errors as well as changes in appearance reserved.

BAV-00062-D | 19.06.2024