


### 38620


 

$I_n$  250 A CU - IEC  
200 A AL - IEC

255 A - UL

$U_i$  1000 V AC / 1500 V DC - IEC

600 V AC/DC - UL

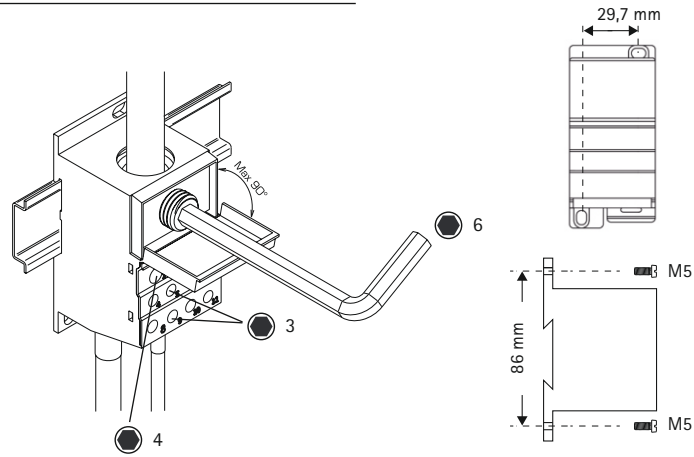

TORQUE				
31 Nm 280 lb.in	35 - 95 mm <sup>2</sup> 2 - 4/0 AWG	35 - 120 mm <sup>2</sup> 2 AWG - 250 kcmil	1 × Ø17,5 mm	28 mm
3,5 Nm 31 lb.in	2,5 - 25 mm <sup>2</sup> 14 - 4 AWG	2,5 - 35 mm <sup>2</sup> 14 - 2 AWG	2 × Ø9 mm	11 mm
2 Nm 18 lb.in	2,5 - 16 mm <sup>2</sup> 14 - 6 AWG		5 × Ø6,8 mm	
	2,5 - 10 mm <sup>2</sup> 14 - 8 AWG		4 × Ø6,2 mm	

Technical changes and errors as well as changes in appearance reserved.

BAV-00115-C | 19.06.2024