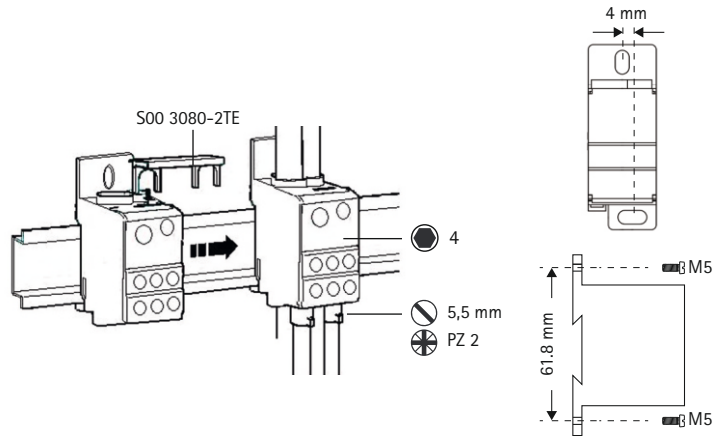

 
 


38641

I_n	125 A CU - IEC
	100 A AL - IEC
	115 A CU - UL
	90 A AL - UL
U_i	1000 V AC / 1500 V DC - IEC
	600 V AC/DC - UL



TORQUE			
3,5 Nm 31 lb.in	10 - 35 mm ² 8 - 2 AWG		1 × Ø10,2 mm 15 mm
2 Nm 18 lb.in	2,5 - 16 mm ² 14 - 6 AWG	2,5 - 25 mm ² 14 - 4 AWG	1 × Ø7 mm
		2,5 - 16 mm ² 14 - 4 AWG	6 × Ø6,5 mm 11 mm

Technical changes and errors as well as changes in appearance reserved.

BAV-00118-C | 19.06.2024