

BantamBox Series – Polycarbonate Enclosures

NEMA 1, 3R, 4, 4X and 12 with Screw Cover



BB060555W

Applications

AttaBox offers an all-polycarbonate product with clear or opaque covers. These enclosures include an external flush wall design, unobstructed internal sidewalls, 304 stainless steel cover screws, and watertight seal.

Construction

- Polycarbonate for 1480 in-lb, high impact resistance per UL746C

Gray in color with gloss Finish



BBCC090603W

- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- Multiple depths available in most sizes
- Flush sides for a perfect fit
- Multiple molded-in bosses for a variety of mounting solutions
- Lift-off cover with 4 screws
- Tightening torque: M4-9 17 lb-in, M6 17-22 lb-in

Listings

- UL/cUL File [UL File E64358]
- NEMA Ratings 1, 3R, 4, 4X, and 12
- IEC 60529 IP66 [UL File 362920]
- Flammability Rating: UL94-V2
- Non-flame propagating
- UV Exposure Rating: UL-f1
- Temperature Range: -40°F to 212°F [-40°C to 100°C]
- Certifications: cULus, REACH, CE, IEC



BantamBox Series – Polycarbonate Enclosures


NEMA 1, 3R, 4, 4X and 12 with Screw Cover



Bantam Box Series – Polycarbonate Enclosures						
Opaque Cover	Price	Clear Cover	Price	Enclosure Overall Size HxWxD	Subpanels	Drawing Link
BB060555W	\$34.50	BBCC060555W	\$35.00	2.56 x 1.97 x 2.17 [65 x 50 x 55]	—	PDF
BB080805W	\$40.00	BBCC080805W	\$42.50	3.23 x 3.15 x 2.17 [82 x 80 x 55]	BPB0808P	PDF
BB080809W	\$45.50	—	—	3.23 x 3.15 x 3.35 [82 x 80 x 85]	BPB0808P	PDF
BB080810W	\$46.00	—	—	3.23 x 3.15 x 3.74 [82 x 80 x 95]	BPB0808P	PDF
BB090603W	\$38.50	BBCC090603W	\$42.00	3.86 x 2.52 x 1.46 [98 x 64 x 37]	—	PDF
BB128055W	\$44.00	BBCC128055W	\$47.00	4.72 x 3.15 x 2.17 [120 x 80 x 55]	BPB1280P	PDF
BBR128080W	\$48.00	—	—	4.72 x 3.15 x 3.15 [120 x 80 x 80]	BPB1280P	PDF
BB128010W	\$51.00	—	—	4.72 x 3.15 x 3.94 [120 x 80 x 100]	BPB1280P	PDF
BB121255W	\$51.00	—	—	4.80 x 4.72 x 2.17 [122 x 120 x 55]	BPB1212P	PDF
BB121275W	\$55.00	BBCC121275W	\$59.00	4.80 x 4.72 x 2.95 [122 x 120 x 75]	BPB1212P	PDF
BB121211W	\$64.00	BBCC121211W	\$68.00	4.80 x 4.72 x 4.13 [122 x 120 x 105]	BPB1212P	PDF
BB168055W	\$53.00	—	—	6.30 x 3.15 x 2.17 [160 x 80 x 55]	BPB1680P	PDF
BB168090W	\$58.00	BBCC168090W	\$61.00	6.30 x 3.15 x 3.54 [160 x 80 x 90]	BPB1680P	PDF
BB161255W	\$69.00	BBCC161255W	\$73.00	6.30 x 4.72 x 2.17 [160 x 120 x 55]	BPB1612P	PDF
BB161290W	\$71.00	BBCC161290W	\$75.00	6.30 x 4.72 x 3.54 [160 x 120 x 90]	BPB1612P	PDF
BB161214W	\$84.00	BBCC161214W	\$88.00	6.30 x 4.72 x 5.51 [160 x 120 x 140]	BPB1612P	PDF
BB201275W	\$74.00	BBCC201275W	\$77.00	7.87 x 4.72 x 2.95 [200 x 120 x 75]	BPB2012P	PDF
BB201290W	\$75.00	—	—	7.87 x 4.72 x 3.54 [200 x 120 x 90]	BPB2012P	PDF
BB201510W	\$86.00	BBCC201510W	\$92.00	7.87 x 5.91 x 3.94 [200 x 150 x 100]	BPB2015P	PDF
BB201513W	\$89.00	BBCC201513W	\$96.00	7.87 x 5.91 x 4.92 [200 x 150 x 125]	BPB2015P	PDF
BB251690W	\$89.00	—	—	9.84 x 6.30 x 3.54 [250 x 160 x 90]	BPB2516P	PDF
BB251611W	\$106.00	—	—	9.84 x 6.30 x 4.53 [250 x 160 x 115]	BPB2516P	PDF
BB251612W	\$108.00	BBCC251612W	\$114.00	9.84 x 6.30 x 4.72 [250 x 160 x 120]	BPB2516P	PDF
BB251615W	\$110.00	BBCC251615W	\$118.00	9.84 x 6.30 x 5.91 [250 x 160 x 150]	BPB2516P	PDF

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].

Dimensions

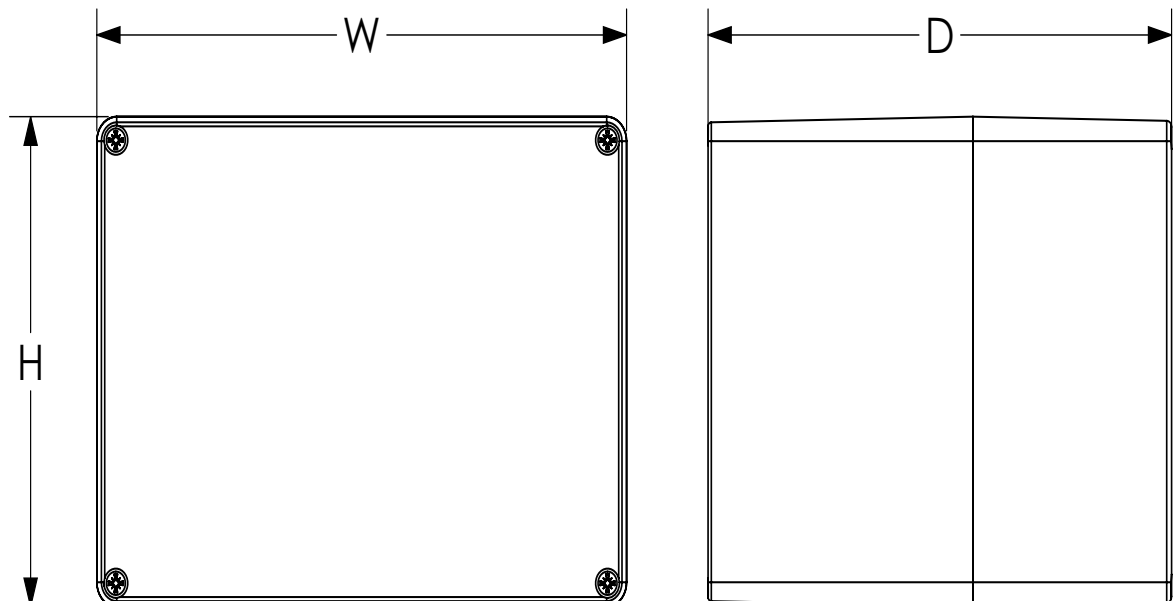


Subpanels for BantamBox Series Enclosures



Phenolic Resin Hard Paper Subpanels

Lightweight, durable and electrically resistant. Includes mounting hardware.

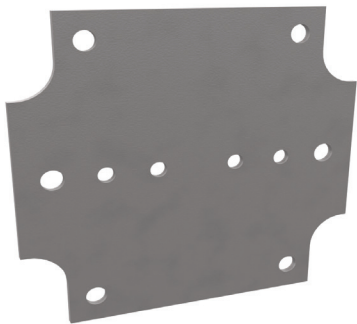

[BPB0808P](#)

Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

BantamBox Series Subpanels		
Part Number	Price	Subpanel Size
<u>BPB0808P</u>	\$5.25	2.83 x 2.76 [72 x 70]
<u>BPB1280P</u>	\$5.25	4.33 x 2.76 [110 x 70]
<u>BPB1680P</u>	\$6.25	5.91 x 2.76 [150 x 70]
<u>BPB1212P</u>	\$8.00	4.41 x 4.33 [112 x 110]
<u>BPB1612P</u>	\$8.25	5.94 x 4.41 [151 x 112]
<u>BPB2012P</u>	\$7.50	7.44 x 4.29 [189 x 109]
<u>BPB2015P</u>	\$10.50	7.52 x 5.59 [191 x 142]
<u>BPB2516P</u>	\$12.50	9.53 x 5.98 [242 x 152]
Note: Dimensions in inches [millimeters].		

Dimensions

