



CANEO Series41 and Series40 Standard Capacitive Switches



IO-Link

[CS41KCRBK-P10-01E7](#)

[CS41KCRBK-P11-029F](#)

[CS41KCRBK-P20-0253](#)

*22mm Series41 and Series40 Standard Capacitive Switches

Part Number	Price	LED Color (Idle/Active)	Switch Type	LED Control	Legend	Symbol Illuminated	Connection	Output Pulse	Drawing Link		
CS40KMSBN-P20-063A	\$159.00	green/red	Dynamic	Automatic	-	No	3-pole	Approx. 300ms	PDF		
CS40KMSBN-P10-05BC	\$159.00			Semi-automatic	Hand Symbol					4-pole	PDF
CS41KCRBK-P10-01E7	\$142.00			Automatic							PDF
CS41KCRBK-P10-029A	\$142.00			Semi-automatic			PDF				
CS41KCRBK-P10-029B	\$142.00			Manual	5-pole		PDF				
CS41KCRBK-P11-029F	\$142.00			Automatic	Power Symbol		4-pole		PDF		
CS41KCRBK-P11-02A0	\$142.00			Semi-automatic			4-pole		PDF		
CS41KCRBK-P11-02A1	\$142.00			Manual			5-pole		PDF		
CS41KDMBL-P11-0552	\$142.00	red/green		Automatic			3-pole		PDF		
CS41KDMBL-P11-0553	\$142.00			Semi-automatic			4-pole		PDF		
CS41KDMBL-P11-0554	\$142.00			Manual			5-pole		PDF		
CS41KDMBL-P12-0555	\$142.00			Automatic	STOP		3-pole		PDF		
CS41KDMBL-P12-0556	\$142.00			Semi-automatic			4-pole		PDF		
CS41KDMBL-P12-0557	\$142.00			Manual			5-pole		PDF		
CS41KCRBK-P13-02AB	\$142.00	green/red		Automatic	START		3-pole		PDF		
CS41KDMBL-P13-0591	\$142.00			Semi-automatic			4-pole		PDF		
CS41KDMBL-P13-0594	\$142.00			Manual			5-pole		PDF		
CS41KCRBK-P20-0253	\$142.00			Automatic	-		3-pole		PDF		
CS41KDMBL-P20-0595	\$142.00		Semi-automatic	4-pole			PDF				
CS41KDMBL-P20-0596	\$142.00		Manual	5-pole			PDF				

*Purchase cable separately.



CANEO Series41 Standard Capacitive Switches




22mm Series41 Standard Capacitive Switches Specifications	
Supply Voltage	24VDC [19.2 to 28.8 V]
Output	PNP-N.O.
Load Current	Max 200mA
Current Consumption	Max 90mA @24V
Operating Temperature	-25 to 50°C [-13 to 122°F]
Storage Temperature	-25 to 50°C [-13 to 122°F]
IP Rating	IP69K
Material	Housing : Polycarbonate (PC) Switch surface Polycarbonate (PC)
Weight (lbs)	0.1
Agency Approvals	CE, CSA


IO-Link Specifications	
IO-Link	v1.1
Port Speed	COM2
SIO Supported	Yes
ISDU Supported	Yes
Data Storage	Yes
Block Parameter	No

Wiring Diagrams


Plug M12, 3-pin

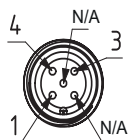


Plug M12, 4-pin

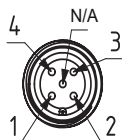


Plug M12, 5-pin

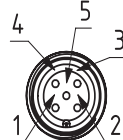

3-pin

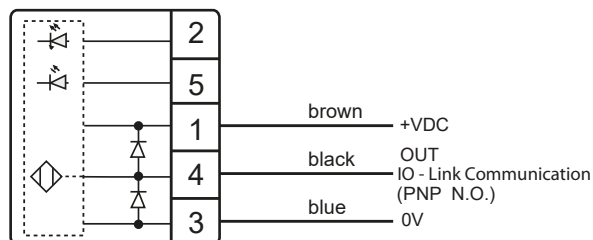

4-pin

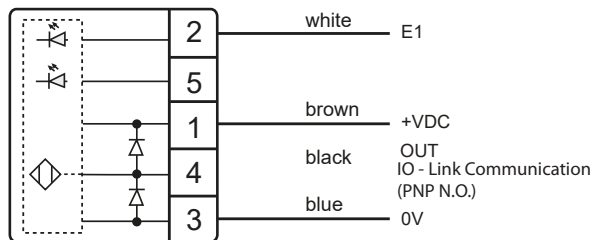

5-pin

