



# Wrenches





## Adjustable Wrenches

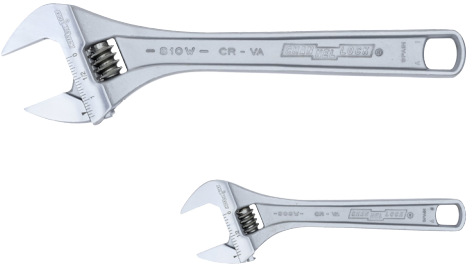
The CHANNELLOCK® adjustable wrenches feature non-protruding jaws for greater access in tight spaces. The combination of a smart and comfortable tapered handle design, precise four-thread knurl, and minimal head width improves performance in everyday use.

### Features

- Measurement scales are laser engraved for sizing nuts, pipe, and tube diameters
- Precise four-thread knurl improved adjustment accuracy
- Non-protruding jaws allow access to hard-to-reach as
- Rugged chrome vanadium steel construction
- Chrome finish for ultimate rust prevention



Adjustable Wrenches						
Part Number	Part Image	Overall Length	Fastening Size	Jaw Thickness	Wrench Features	Price
<a href="#"><u>804</u></a>		4.5in (114mm)	0-1/2in	0.37in (9.5mm)	4-thread knurl adjuster laser engraved measurement scales	\$18.00
<a href="#"><u>806W</u></a>		6.2in (157mm)	0-15/16in	0.43in (10.9mm)	Extra wide jaws 4-thread knurl adjuster laser engraved measurement scales	\$19.00
<a href="#"><u>808W</u></a>		8.0in (203mm)	0-1 1/16in	0.55in (14.0mm)		\$21.00
<a href="#"><u>810W</u></a>		10.0in (254mm)	0-1 5/16in	0.62in (15.7mm)		\$26.00

Adjustable Wrench Sets					
Part Number	Part Image	Contains	Description	Set Includes	Price
<a href="#"><u>WS-2</u></a>		<a href="#"><u>806W</u></a> <a href="#"><u>810W</u></a>	CHANNELLOCK adjustable wrench set, 2 pieces, extra wide jaws, 4-thread knurl adjuster and laser engraved measurement scales.	(2) Chrome vanadium steel wide adjustable wrenches (0-15/16in capacity, 0-1 5/16in capacity)	\$45.00