



Disconnect Terminal Blocks


Both the DN-DIS10 (MN) and the DN-KBD12 (MN) allow fast circuit disconnection without rewiring and are 35mm DIN-rail mountable. The DN-DIS10 (MN) is supplied with a copper disconnect bar installed in the fuse holder. The DN-KBD12 (MN) offers circuit disconnection capability by means of a pivoting, insulated "knife blade".



WARNING: DO NOT DISCONNECT UNDER LOAD



DN-DIS10
Series: EURO S 4LH/35

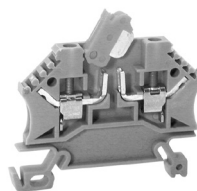


DN-KBD12
Series: EURO T2.5/35

Ordering Information								
	Part Number		Qty	Price	Part Number		Qty	Price
Gray Disconnect Block	DN-DIS10		50	\$274.00	DN-KBD12		50	\$151.00
	DN-DIS10MN		10	\$43.50	DN-KBD12MN		10	\$26.00
Technical Specifications								
Stripping Length		10mm [0.39 in]			10mm [0.39 in]			
Tightening Torque		0.6 N·m [5.3 lb·in]			0.5 N·m [4.4 lb·in]			
Density		125/m [30 pcs/ft]			200/m [60 pcs/ft]			
UL Approval*		300V	30A	24-10 AWG	600V	20A	22-12 AWG	
VDE Approval		500V	25A	4mm²	600V	16A	2.5 mm²	
Disconnect Type		Copper bar			Copper blade			
Operating Temperature		Ambient air temperature: -20°C to 85°C [-4°F to 185°F] Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]						
SCCR Rating		10kA per Table SB4.1, 2009, UL 508A, Maximum short circuit current rating for unmarked components						
CE Conformity		CE (EN 60947-1 / EN 60947-7-3)			CE (EN 60947-1 / EN 60947-7-1)			
Agency File #		UL E179129 / LR84816						
Accessories								
End Cover		Included			DN-ECKBD	100	\$43.00	
					DN-ECKBDMN	10	\$6.00	
35mm DIN Rail	7.5 mm high	DN-R35S1	10	\$39.00	DN-R35S1	10	\$39.00	
		DN-R35S1-2	2	\$11.00	DN-R35S1-2	2	\$11.00	
	15mm high	DN-R35HS1	10	\$68.00	DN-R35HS1	10	\$68.00	
		DN-R35HS1-2	2	\$16.50	DN-R35HS1-2	2	\$16.50	
End Bracket		DN-EB35	50	\$67.00	DN-EB35	50	\$67.00	
		DN-EB35MN	20	\$31.50	DN-EB35MN	20	\$31.50	
		DN-EB35-A	50	\$47.50	DN-EB35-A	50	\$47.50	
		DN-EB35-A-10	10	\$12.00	DN-EB35-A-10	10	\$12.00	
		DN-QEB35	50	\$42.50	DN-QEB35	50	\$42.50	
		DN-QEB35-10	10	\$11.50	DN-QEB35-10	10	\$11.50	
		Angled Support Bracket	DN-ASB1	50	\$107.00	DN-ASB1	50	\$107.00
Marking Tags		DN-L or DN-LT series	500/100	various	DN-LA or DN-LT series	500/100	various	


*For copper wire only

Note: For more information on accessories, see the DINnectors Accessories section of this chapter.

DN-DIS10 / DN-DIS10MN

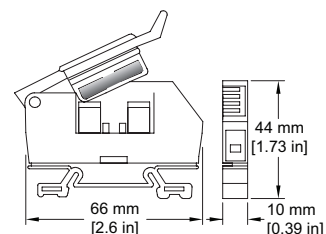

DN-KBD12 / DN-KBD12MN

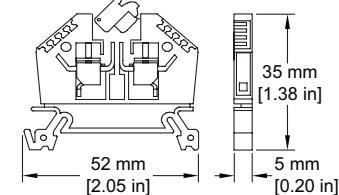

 DINnectors® Accessories
Marking Tags Cross Reference Charts - Screw-type

DINnector Marking Tags Cross Reference - Screw-type					
<i>Block Type</i>	<i>DN-L</i>	<i>DN-LA</i>	<i>DN-LT</i>	<i>DN-LAT</i>	<i>DN-EMLBL</i>
DN-T12	–	X	X	–	–
DN-T10	X	–	X	–	–
DN-T8	X	–	X	–	–
DN-T6	X	–	X	–	–
DN-T4	X	–	X	–	–
DN-T1/0	X	–	X	–	–
<u>DN-T3/0</u>	X	–	X	–	–
DN-D10	X	–	X	–	–
DN-D10X	X	–	X	–	–
DN-D10LED	X	–	X	–	–
DN-D10DR	X	–	X	–	–
DN-TL14	–	–	–	X	–
DN-THERM	X	–	X	–	–
DN-EMXM1	–	X	X	–	X
DN-EMXDV	–	X	X	–	X
DN-M10	–	–	X	–	–
<u>DN-MG10</u>	–	–	X	–	–
DN-G10	X	–	X	–	–
DN-G8	X	–	X	–	–
DN-G6	X	–	X	–	–
DN-G4	X	–	X	–	–
DN-G1/0	X	–	X	–	–
DN-F6	X	–	X	–	–
DN-F10	X	–	X	–	–
DN-DIS2	–	X	X	–	–
DN-DIS4	X	–	X	–	–
DN-FE2	–	X	X	–	–
DN-FE4	X	–	X	–	–
DN-DIS10	X	–	X	–	–
DN-KBD12	–	X	X	–	–


Continued on next page

Marking Tags

Marking Tags DN-L Series

Part Number	Marking Sequence	Qty	Price
<u>DN-L50</u>	1-50	500	\$56.00
<u>DN-L100</u>	51-100	500	\$56.00
<u>DN-L150</u>	101-150	500	\$56.00
<u>DN-L200</u>	151-200	500	\$56.00
<u>DN-L250</u>	201-250	500	\$56.00
<u>DN-L300</u>	251-300	500	\$56.00
<u>DN-L350</u>	301-350	500	\$56.00
<u>DN-L400</u>	351-400	500	\$56.00
<u>DN-L450</u>	401-450	500	\$56.00
<u>DN-LB</u>	Blank	500	\$38.00
<u>DN-LS</u>	L1, L2, L3, L, N, GND, +, -, COM, COM*	500	\$56.00

Dimensions

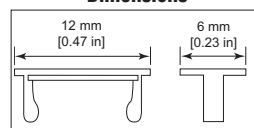


- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500.
- The DN-L tags fit all DINnectors 6mm wide and wider.
- There will be a gap between tags on blocks wider than 6mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LA Series

Part Number	Marking Sequence	Qty	Price
<u>DN-LA100</u>	1-100	500	\$56.00
<u>DN-LA200</u>	101-200	500	\$56.00
<u>DN-LA300</u>	201-300	500	\$56.00
<u>DN-LA400</u>	301-400	500	\$56.00
<u>DN-LAB</u>	Blank Tags	500	\$56.00
<u>DN-LAS</u>	L1, L2, L3, L, N, GND, +, -, COM, COM*	500	\$56.00

 Dimensions




- The marking sequence of 100 tags (i.e. 1-100) is printed five times in each package of 500.
- The DN-LA tags fit all DINnectors 5mm wide and wider. There will be a gap between tags on blocks wider than 5mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LAT Series

Part Number	Marking Sequence	Qty	Price
<u>DN-LAT100-A</u>	1-100	500	\$49.00
<u>DN-LAT200-A</u>	101-200	500	\$49.00
<u>DN-LAT300-A</u>	201-300	500	\$49.00
<u>DN-LAT400-A</u>	301-400	500	\$49.00
<u>DN-LAT500-A</u>	401-500	500	\$49.00
<u>DN-LAT600-A</u>	501-600	500	\$49.00
<u>DN-LATB-A</u>	Blank Tags	500	\$35.50
<u>DN-LATS-A</u>	L1, L2, L3, L, N, +, -, COM, COM*	500	\$49.00

 Dimensions




- The marking sequence of 500 tags (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-QL Series

Part Number	Marking Sequence	Qty	Price
<u>DN-QL100</u>	1-100	500	\$42.50
<u>DN-QL200</u>	101-200	500	\$42.50
<u>DN-QL300</u>	201-300	500	\$42.50
<u>DN-QL400</u>	301-400	500	\$42.50
<u>DN-QL500</u>	401-500	500	\$42.50
<u>DN-QLB</u>	Blank Tags	500	\$36.00
<u>DN-QLS</u>	L1, L2, L3, L, N, +, -, COM, COM*	500	\$49.00

 Dimensions




- The marking sequence of 500 (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

DINnectors® Accessories


Marking Tags continued

Marking Tags DN-LT Series			
Part Number	Marking Sequence	Qty	Price
DN-LT15	1-5	100	\$10.00
DN-LT60	6-0	100	\$10.00
DN-LT1	1	100	\$10.00
DN-LT2	2	100	\$10.00
DN-LT3	3	100	\$10.00
DN-LT4	4	100	\$10.00
DN-LT5	5	100	\$10.00
DN-LT6	6	100	\$10.00
DN-LT7	7	100	\$10.00
DN-LT8	8	100	\$10.00
DN-LT9	9	100	\$10.00
DN-LT0	0	100	\$10.00
DN-LTBLNK	Unprinted	100	\$10.00
DN-LTA	A	100	\$10.00
DN-LTB	B	100	\$10.00
DN-LTC	C	100	\$10.00
DN-LTD	D	100	\$10.00
DN-LTE	E	100	\$10.00
DN-LTF	F	100	\$10.00
DN-LTG	G	100	\$10.00
DN-LTH	H	100	\$10.00
DN-LTI	I	100	\$10.00
DN-LTJ	J	100	\$10.00
DN-LTK	K	100	\$10.00
DN-LTL	L	100	\$10.00
DN-LTM	M	100	\$10.00
DN-LTN	N	100	\$10.00
-	-	-	-
DN-LTP	P	100	\$10.00
DN-LTQ	Q	100	\$10.00
DN-LTR	R	100	\$10.00
DN-LTS	S	100	\$10.00
DN-LTT	T	100	\$10.00
DN-LTU	U	100	\$10.00
DN-LTV	V	100	\$10.00
DN-LTW	W	100	\$10.00
DN-LTX	X	100	\$10.00
DN-LTY	Y	100	\$10.00
DN-LTZ	Z	100	\$10.00
DN-LTGND	⊕	100	\$10.00
DN-LTPOS	+	100	\$10.00
DN-LTNEG	-	100	\$10.00
DN-LTAC	~	100	\$10.00
DN-LTDC	=	100	\$10.00

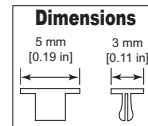


- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
- Material: Thermoplastic with heat embossed black print.

DN-MTA marking tag adapter

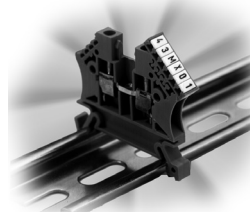

DN-MTA dimensions

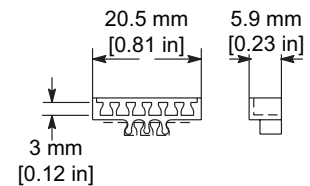

Part Number	Description	Qty	Price
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	\$14.50

Note: [DN-MTA](#) adapter does not fit [DN-T12-A](#) terminal blocks.

DINnectors Accessories

Terminal Marking Accessories

**DN-EMLBL1****DN-EMLBL2****DN-EMLBL3**

Part Number	Description	For Use With	Qty	Price
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMXxx plug-in terminal blocks	100	\$9.25
DN-EMLBL2	Labels printed 1 – 12		100	\$13.00
DN-EMLBL3	Labels printed 13 – 24		100	\$13.00

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part Number	Description	Qty	Price
DN-MP	Staedtler-Mars marking pen, for use with blank marking tags. Permanent Ink, fine tip.	1	\$4.50

**Marking pen**

Wire Marking Accessories

**DN-WMTAG1 wire tags &
DN-WM-x wire tag holders**

Part Number	Description	For Use With	Qty	Price
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	\$60.00
DN-WM-1	Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	\$12.50
DN-WM-2	Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	\$12.50
DN-WM-3	Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	\$8.25
DN-WM-4	Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire		100	\$7.75