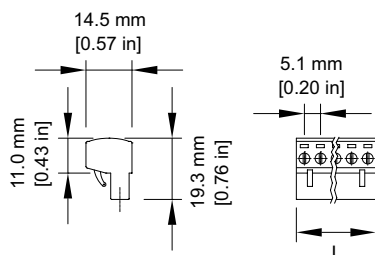


# DINnectors® Accessories

## Terminal Plugs



**DN-xxPLUG / DN-xxPLUGMN**



| Accessories – Terminal Plugs |     |                                                                                                                           |                             |     |         |                 |                |
|------------------------------|-----|---------------------------------------------------------------------------------------------------------------------------|-----------------------------|-----|---------|-----------------|----------------|
| Plugs* Part Number           | Qty | Price                                                                                                                     | Plugs* Part Number          | Qty | Price   | Number of Poles | Length mm [in] |
| <a href="#">DN-2PLUG</a>     | 200 | \$115.00                                                                                                                  | <a href="#">DN-2PLUGMN</a>  | 10  | \$7.25  | 2               | 10.2 [0.40]    |
| <a href="#">DN-3PLUG</a>     | 200 | \$177.00                                                                                                                  | <a href="#">DN-3PLUGMN</a>  | 10  | \$11.50 | 3               | 15.2 [0.60]    |
| <a href="#">DN-4PLUG</a>     | 100 | \$118.00                                                                                                                  | <a href="#">DN-4PLUGMN</a>  | 10  | \$14.50 | 4               | 20.3 [0.80]    |
| <a href="#">DN-5PLUG</a>     | 100 | \$136.00                                                                                                                  | <a href="#">DN-5PLUGMN</a>  | 10  | \$18.00 | 5               | 25.4 [1.00]    |
| <a href="#">DN-6PLUG</a>     | 100 | \$176.00                                                                                                                  | <a href="#">DN-6PLUGMN</a>  | 10  | \$18.00 | 6               | 30.5 [1.20]    |
| <a href="#">DN-7PLUG</a>     | 50  | \$92.00                                                                                                                   | <a href="#">DN-7PLUGMN</a>  | 5   | \$14.50 | 7               | 35.6 [1.40]    |
| <a href="#">DN-8PLUG</a>     | 50  | \$117.00                                                                                                                  | <a href="#">DN-8PLUGMN</a>  | 5   | \$14.50 | 8               | 40.6 [1.60]    |
| <a href="#">DN-9PLUG</a>     | 50  | \$128.00                                                                                                                  | <a href="#">DN-9PLUGMN</a>  | 5   | \$15.00 | 9               | 45.7 [1.80]    |
| <a href="#">DN-10PLUG</a>    | 50  | \$136.00                                                                                                                  | <a href="#">DN-10PLUGMN</a> | 5   | \$17.00 | 10              | 50.8 [2.00]    |
| <a href="#">DN-11PLUG</a>    | 50  | \$161.00                                                                                                                  | <a href="#">DN-11PLUGMN</a> | 5   | \$19.50 | 11              | 55.9 [2.20]    |
| <a href="#">DN-12PLUG</a>    | 50  | \$176.00                                                                                                                  | <a href="#">DN-12PLUGMN</a> | 5   | \$20.00 | 12              | 61.0 [2.40]    |
| Terminal Plugs Ratings       |     |                                                                                                                           |                             |     |         |                 |                |
| <b>Voltage/Current</b>       |     | 300V, 12A                                                                                                                 |                             |     |         |                 |                |
| <b>Wire Gauge</b>            |     | 14–22 AWG, CU only                                                                                                        |                             |     |         |                 |                |
| <b>Torque</b>                |     | Tightening Torque: 0.51 N·m [4.5 lb·in]                                                                                   |                             |     |         |                 |                |
| <b>Usage Temperature</b>     |     | Ambient air temperature: -20 to 105°C [-4 to 221°F]<br>Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F] |                             |     |         |                 |                |
| <b>Agency Approvals</b>      |     | UL file #: E179129                                                                                                        |                             |     |         |                 |                |

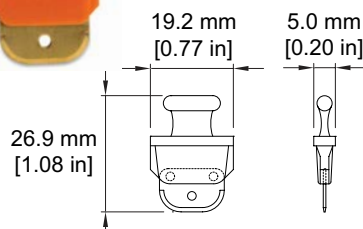
Note: To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

\* DN-xxPLUGs fit all DN-EMXxx & DN-QEMXxx plug-in terminal blocks

## Disconnect Blade



**DN-DIS-BLADE  
DN-DIS-BMN**




| Disconnect Blade             |                                                                         |     |         |
|------------------------------|-------------------------------------------------------------------------|-----|---------|
| Part Number                  | Description                                                             | Qty | Price   |
| <a href="#">DN-DIS-BLADE</a> | Terminal block disconnect blade for DN-FE2, DN-FE4, DN-DIS2 and DN-DIS4 | 50  | \$36.00 |
| <a href="#">DN-DIS-BMN</a>   |                                                                         | 10  | \$9.75  |


## End Brackets



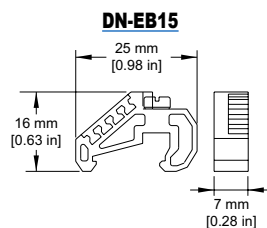
| End Brackets                 |                                                                                        |          |
|------------------------------|----------------------------------------------------------------------------------------|----------|
| Part Number                  | Description                                                                            | Price    |
| <a href="#">DN-EB15</a>      | DINnecter snap-on end bracket, 7mm wide. Package of 100. For use with 15mm DIN rail.   | \$108.00 |
| <a href="#">DN-EB15MN</a>    | DINnecter snap-on end bracket, 7mm wide. Package of 20. For use with 15mm DIN rail.    | \$25.50  |
| <a href="#">DN-EB35</a>      | DINnecter screw-down end bracket, 9mm wide. Package of 50. For use with 35mm DIN rail. | \$67.00  |
| <a href="#">DN-EB35MN</a>    | DINnecter screw-down end bracket, 9mm wide. Package of 20. For use with 35mm DIN rail. | \$31.50  |
| <a href="#">DN-EB35-A</a>    | DINnecter screw-down end bracket, 6mm wide. Package of 50. For use with 35mm DIN rail. | \$47.50  |
| <a href="#">DN-EB35-A-10</a> | DINnecter screw-down end bracket, 6mm wide. Package of 10. For use with 35mm DIN rail. | \$12.00  |
| <a href="#">DN-QEB35</a>     | DINnecter snap-on end bracket, 6mm wide. Package of 50. For use with 35mm DIN rail.    | \$42.50  |
| <a href="#">DN-QEB35-10</a>  | DINnecter snap-on end bracket, 6mm wide. Package of 10. For use with 35mm DIN rail.    | \$11.50  |




**DN-EB15**

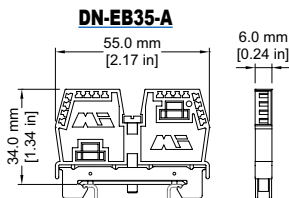

**DN-EB35-A**

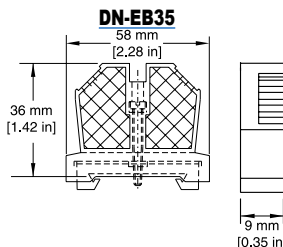

**DN-EB35**

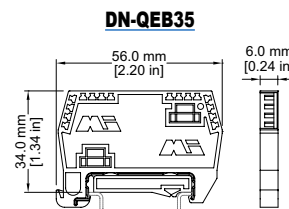

**DN-QEB35**

For more information on accessories, see the "DINnectors Accessories" section of this section.

 **DINnectors** Accessories

## End Covers

Certain end covers can be used with multiple terminal block parts to cover and insulate the open side, or to put more space between adjacent blocks.

| DINnectors End Covers               |                                                                                                                   |         |
|-------------------------------------|-------------------------------------------------------------------------------------------------------------------|---------|
| Part Number                         | Description                                                                                                       | Price   |
| <a href="#"><u>DN-EC1210</u></a>    | DINnector terminal block end cover, gray. Package of 100. For use with DN-T12 or DN-T10 series terminal blocks.   | \$43.00 |
| <a href="#"><u>DN-EC1210MN</u></a>  | DINnector terminal block end cover, gray. Package of 25. For use with DN-T12 or DN-T10 series terminal blocks.    | \$14.50 |
| <a href="#"><u>DN-EC86</u></a>      | DINnector terminal block end cover, gray. Package of 100. For use with DN-T8 or DN-T6 series terminal blocks.     | \$47.00 |
| <a href="#"><u>DN-EC86MN</u></a>    | DINnector terminal block end cover, gray. Package of 25. For use with DN-T8 or DN-T6 series terminal blocks.      | \$14.50 |
| <a href="#"><u>DN-EC4</u></a>       | DINnector terminal block end cover, gray. Package of 50. For use with DN-T4 series terminal blocks.               | \$29.50 |
| <a href="#"><u>DN-EC4MN</u></a>     | DINnector terminal block end cover, gray. Package of 10. For use with DN-T4 series terminal blocks.               | \$5.75  |
| <a href="#"><u>DN-EC1/0</u></a>     | DINnector terminal block end cover, gray. Package of 50. For use with DN-T1/0 series terminal blocks.             | \$33.50 |
| <a href="#"><u>DN-EC1/0MN</u></a>   | DINnector terminal block end cover, gray. Package of 10. For use with DN-T1/0 series terminal blocks.             | \$8.00  |
| <a href="#"><u>DN-DEC10</u></a>     | DINnector terminal block end cover, gray. Package of 50. For use with DN-D10-A series terminal blocks.            | \$31.50 |
| <a href="#"><u>DN-DEC10MN</u></a>   | DINnector terminal block end cover, gray. Package of 10. For use with DN-D10-A series terminal blocks.            | \$6.00  |
| <a href="#"><u>DN-EC14</u></a>      | DINnector terminal block end cover, gray. Package of 25. For use with DN-TL14 series terminal blocks.             | \$18.00 |
| <a href="#"><u>DN-EC14S</u></a>     | DINnector terminal block end cover, gray. Package of 25. For use with DN-TL14S series terminal blocks.            | \$15.00 |
| <a href="#"><u>DN-ECM10</u></a>     | DINnector terminal block end cover, gray. Package of 100. For use with DN-M10-A series terminal blocks.           | \$43.00 |
| <a href="#"><u>DN-ECM10MN</u></a>   | DINnector terminal block end cover, gray. Package of 25. For use with DN-M10-A series terminal blocks.            | \$14.50 |
| <a href="#"><u>DN-ECKBD</u></a>     | DINnector terminal block end cover, gray. Package of 100. For use with DN-KBD12 series terminal blocks.           | \$43.00 |
| <a href="#"><u>DN-ECKBDMN</u></a>   | DINnector terminal block end cover, gray. Package of 10. For use with DN-KBD12 series terminal blocks.            | \$6.00  |
| <a href="#"><u>DN-EMXM1EC1</u></a>  | DINnector terminal block end cover, gray. Package of 25. For use with DN-EMXM1 series terminal block leftside.    | \$15.00 |
| <a href="#"><u>DN-EMXM1EC2</u></a>  | DINnector terminal block end cover, gray. Package of 25. For use with DN-EMXM1 series terminal block rightside.   | \$15.00 |
| <a href="#"><u>DN-EMXDVEC1</u></a>  | DINnector terminal block end cover, gray. Package of 25. For use with DN-EMXDV series terminal block leftside.    | \$15.00 |
| <a href="#"><u>DN-EMXDVEC2</u></a>  | DINnector terminal block end cover, gray. Package of 25. For use with DN-EMXDV series terminal block rightside.   | \$15.00 |
| <a href="#"><u>DN-FESEP</u></a>     | DINnector terminal block end cover, gray. Package of 50. For use with DN-FE and DN-DIS series terminal blocks.    | \$26.50 |
| <a href="#"><u>DN-FESEP-10</u></a>  | DINnector terminal block end cover, gray. Package of 10. For use with DN-FE and DN-DIS series terminal blocks.    | \$5.25  |
| <a href="#"><u>DN-QEC12</u></a>     | DINnector terminal block end cover, gray. Package of 50. For use with DN-Q12-A or DN-QG12 series terminal blocks. | \$21.50 |
| <a href="#"><u>DN-QEC12MN</u></a>   | DINnector terminal block end cover, gray. Package of 10. For use with DN-Q12-A or DN-QG12 series terminal blocks. | \$5.25  |
| <a href="#"><u>DN-QEC10</u></a>     | DINnector terminal block end cover, gray. Package of 50. For use with DN-Q10-A or DN-QG10 series terminal blocks. | \$21.50 |
| <a href="#"><u>DN-QEC10MN</u></a>   | DINnector terminal block end cover, gray. Package of 10. For use with DN-Q10-A or DN-QG10 series terminal blocks. | \$5.25  |
| <a href="#"><u>DN-QEC8</u></a>      | DINnector terminal block end cover, gray. Package of 50. For use with DN-Q8-A or DN-QG8 series terminal blocks.   | \$25.50 |
| <a href="#"><u>DN-QEC8MN</u></a>    | DINnector terminal block end cover, gray. Package of 10. For use with DN-Q8-A or DN-QG8 series terminal blocks.   | \$5.75  |
| <a href="#"><u>DN-QEC12-1-2</u></a> | DINnector terminal block end cover, gray. Package of 25. For use with DN-Q12-1-2-A series terminal blocks.        | \$15.00 |
| <a href="#"><u>DN-QEC12-2-2</u></a> | DINnector terminal block end cover, gray. Package of 25. For use with DN-Q12-2-2-A series terminal blocks.        | \$16.50 |
| <a href="#"><u>DN-QDEC12</u></a>    | DINnector terminal block end cover, gray. Package of 25. For use with DN-QD12 series terminal blocks.             | \$16.50 |

## Spacers

Spacers are used to put more space between adjacent blocks.

| DINnectors Spacers                  |                                                                        |     |         |
|-------------------------------------|------------------------------------------------------------------------|-----|---------|
| Part Number                         | Description                                                            | Qty | Price   |
| <a href="#"><u>DN-S1210</u></a>     | Spacer for DN-T12-A and DN-T10-A series terminal blocks                | 100 | \$51.00 |
| <a href="#"><u>DN-S1210MN</u></a>   |                                                                        | 25  | \$16.00 |
| <a href="#"><u>DN-S86</u></a>       | Spacer for DN-T8 and DN-T6 series terminal blocks                      | 100 | \$61.00 |
| <a href="#"><u>DN-S86MN</u></a>     |                                                                        | 25  | \$14.00 |
| <a href="#"><u>DN-EMXM1SPA1</u></a> | Spacer for DN-EMXM1 and DN-QEMXM1 single-level plug-in terminal blocks | 25  | \$13.00 |
| <a href="#"><u>DN-EMXDVSPA1</u></a> | Spacer for DN-EMXDV and DN-QEMXDV double-level plug-in terminal blocks | 25  | \$14.50 |
| <a href="#"><u>DN-FESPA</u></a>     | Spacer for DN-FE sockets and DN-DIS disconnects                        | 50  | \$26.50 |
| <a href="#"><u>DN-FESPA-10</u></a>  |                                                                        | 10  | \$5.25  |

## Top Covers

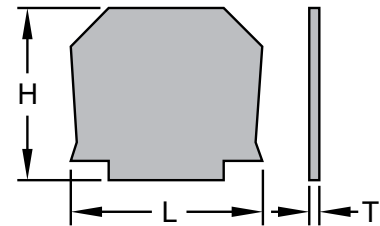
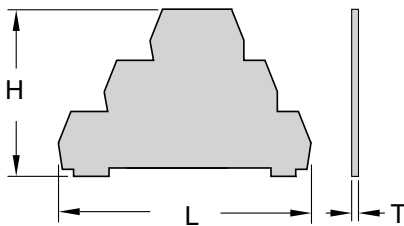
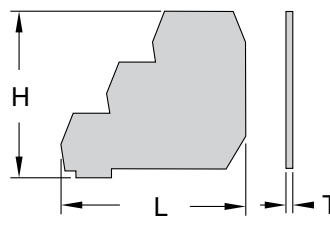
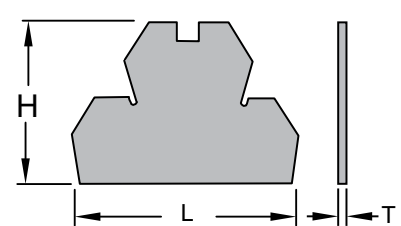
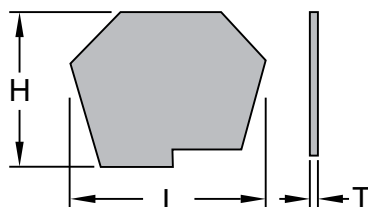
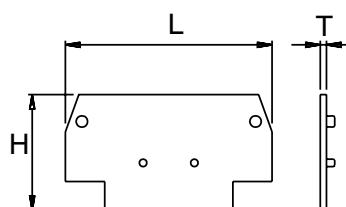
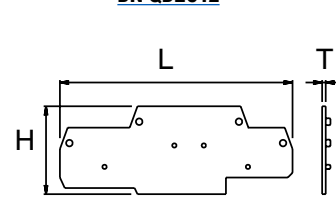
| DINnectors Top Covers            |                                              |                                                              |     |         |
|----------------------------------|----------------------------------------------|--------------------------------------------------------------|-----|---------|
| Part Number                      | Description                                  | For Use With                                                 | Qty | Price   |
| <a href="#"><u>DN-C12</u></a>    | Top cover, clear, printed electrical symbol. | <a href="#"><u>DN-T12-A</u></a>                              | 100 | \$62.00 |
| <a href="#"><u>DN-C12MN</u></a>  |                                              |                                                              | 25  | \$14.00 |
| <a href="#"><u>DN-C10</u></a>    | Top cover, clear, printed electrical symbol. | <a href="#"><u>DN-T10-A</u></a>                              | 100 | \$62.00 |
| <a href="#"><u>DN-C10MN</u></a>  |                                              |                                                              | 25  | \$14.00 |
| <a href="#"><u>DN-C86</u></a>    | Top cover, clear, printed electrical symbol. | <a href="#"><u>DN-T8</u></a><br><a href="#"><u>DN-T6</u></a> | 100 | \$62.00 |
| <a href="#"><u>DN-C86MN</u></a>  |                                              |                                                              | 25  | \$14.00 |
| <a href="#"><u>DN-DC10</u></a>   | Top cover, clear, printed electrical symbol. | DN-D10                                                       | 100 | \$60.00 |
| <a href="#"><u>DN-DC10MN</u></a> |                                              |                                                              | 25  | \$14.00 |
| <a href="#"><u>DN-MC10</u></a>   | Top cover, clear, printed electrical symbol. | DN-M10                                                       | 100 | \$64.00 |
| <a href="#"><u>DN-MC10MN</u></a> |                                              |                                                              | 25  | \$14.00 |

 **DINnectors** Accessories

**DINnector End Covers and Spacers Dimensions**








| Part Number                         |                                     | Length<br>mm[in]      | Height<br>mm [in] | Thickness<br>mm [in] |
|-------------------------------------|-------------------------------------|-----------------------|-------------------|----------------------|
| <a href="#"><u>DN-EC1210</u></a>    | <a href="#"><u>DN-EC1210MN</u></a>  | 44 [1.73]             | 35 [1.38]         | 1.5 [0.06]           |
| <a href="#"><u>DN-S1210</u></a>     | <a href="#"><u>DN-S1210MN</u></a>   | 55 [2.17]             | 44 [1.73]         |                      |
| <a href="#"><u>DN-EC86</u></a>      | <a href="#"><u>DN-EC86MN</u></a>    | 50 [1.97]             | 43 [1.69]         |                      |
| <a href="#"><u>DN-S86</u></a>       | <a href="#"><u>DN-S86MN</u></a>     | 55 [2.17]             | 49 [1.93]         |                      |
| <a href="#"><u>DN-EC4</u></a>       | <a href="#"><u>DN-EC4MN</u></a>     | 56 [2.21]             | 48 [1.89]         |                      |
| <a href="#"><u>DN-EC1/0</u></a>     | <a href="#"><u>DN-EC1/0MN</u></a>   | 62 [2.44]             | 60 [2.36]         |                      |
| <a href="#"><u>DN-DEC10</u></a>     | <a href="#"><u>DN-DEC10MN</u></a>   | 72 [2.80]             | 49 [1.93]         |                      |
| <a href="#"><u>DN-EC14</u></a>      | —                                   | 78 [3.08]             | 55 [2.17]         |                      |
| <a href="#"><u>DN-EC14S</u></a>     | —                                   | 55 [2.17]             | 50 [1.97]         |                      |
| <a href="#"><u>DN-ECM10</u></a>     | <a href="#"><u>DN-ECM10MN</u></a>   | 32 [1.26]             | 27 [1.06]         |                      |
| <a href="#"><u>DN-ECKBD</u></a>     | <a href="#"><u>DN-ECKBDMN</u></a>   | 52 [2.05]             | 34.5 [1.36]       |                      |
| <a href="#"><u>DN-EMXM1EC1</u></a>  | <a href="#"><u>DN-EMXM1EC2</u></a>  | as shown on next page |                   |                      |
| <a href="#"><u>DN-EMXDVEC1</u></a>  | <a href="#"><u>DN-EMXDVEC2</u></a>  |                       |                   |                      |
| <a href="#"><u>DN-EMXDVSPA1</u></a> | <a href="#"><u>DN-EMXM1SPA1</u></a> |                       |                   |                      |
| <a href="#"><u>DN-FESPA</u></a>     | <a href="#"><u>DN-FESPA-10</u></a>  |                       |                   |                      |
| <a href="#"><u>DN-FESEP</u></a>     | <a href="#"><u>DN-FESEP-10</u></a>  |                       |                   |                      |
| <a href="#"><u>DN-QEC12</u></a>     | <a href="#"><u>DN-QEC12MN</u></a>   | 50 [1.97]             | 23 [0.9]          | 1.5 [0.06]           |
| <a href="#"><u>DN-QEC10</u></a>     | <a href="#"><u>DN-QEC10MN</u></a>   | 57.4 [2.26]           | 33.6 [1.32]       |                      |
| <a href="#"><u>DN-QEC8</u></a>      | <a href="#"><u>DN-QEC8MN</u></a>    | 63 [2.48]             | 38.5 [1.52]       |                      |
| <a href="#"><u>DN-QEC12-1-2</u></a> | —                                   | 68.5 [2.70]           | 28.5 [1.12]       |                      |
| <a href="#"><u>DN-QEC12-2-2</u></a> | —                                   | 87.5 [3.44]           | 28.5 [1.12]       |                      |
| <a href="#"><u>DN-QDEC12</u></a>    | —                                   | 98 [3.86]             | 37 [1.46]         |                      |

**DN-EC1210 (MN), DN-EC86 (MN), DN-EC4 (MN),  
DN-EC1/0 (MN), DN-ECKBD (MN), DN-S1210 (MN),  
DN-S86 (MN)**

**DN-EC14****DN-EC14S****DN-DEC10 / DN-DEC10MN****DN-ECM10  
DN-ECM10MN****DN-QEC12 (MN), DN-QEC10 (MN)  
DN-QEC8 (MN),  
DN-QEC12-1-2, DN-QEC12-2-2****DN-QDEC12**

# **DINnectors** Accessories
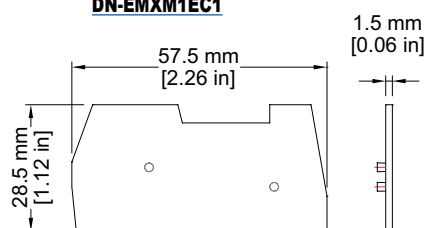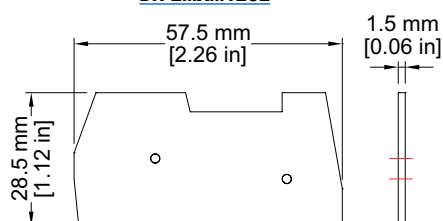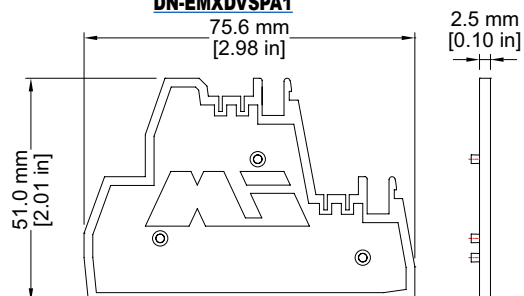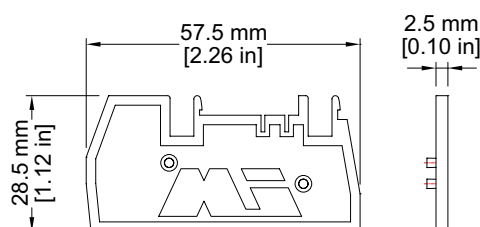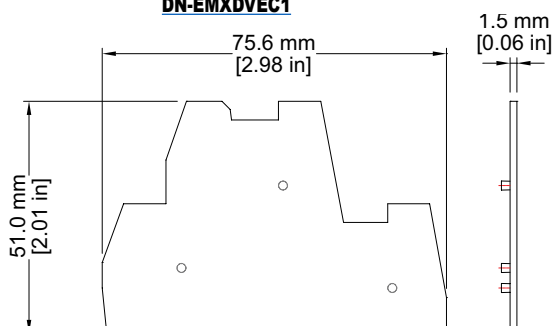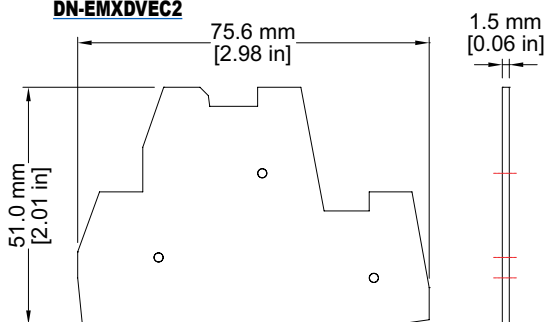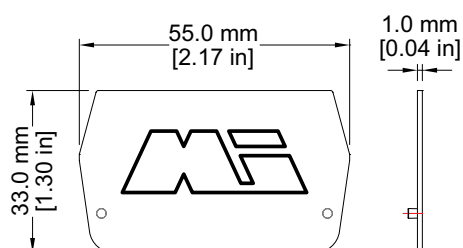
## Dimensional Drawings

**DN-EMXM1EC1****DN-EMXM1EC2****DN-EMXDVSPA1****DN-EMXM1SPA1****DN-EMXDVEC1****DN-EMXDVEC2****DN-FESEP,  
DN-FESEP-10****DN-FESPA, DN-FESPA-10**