


# DINnectors® Single-Level Terminal Blocks

 
Feed-through terminal blocks provide the means to connect two wires together, and are available in sizes suitable for up to 8AWG wire.

- Screw connection terminal
- 35mm DIN-rail mountable
- LVD 2006/95/EC


**DN-T12-A**  
Series: EURO 2.5

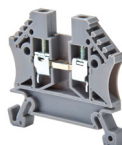

**DN-T10-A**  
Series: EURO 4




**DN-T8**  
Series: EURO 6

 


**Dimensions**  
mm [inches]


**DN-T12-A**

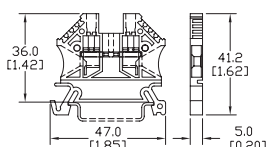

**DN-T10-A**

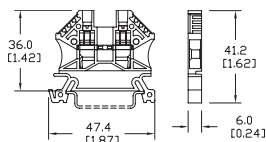

**DN-T8**

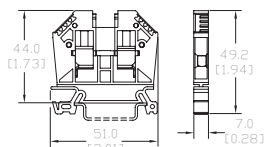

## Ordering Information

| Available Colors | Part Number                 | Qty | Price   | Part Number                 | Qty | Price   | Part Number              | Qty | Price   |
|------------------|-----------------------------|-----|---------|-----------------------------|-----|---------|--------------------------|-----|---------|
| Gray             | <a href="#">DN-T12-A</a>    | 100 | \$64.00 | <a href="#">DN-T10-A</a>    | 100 | \$74.00 | <a href="#">DN-T8</a>    | 50  | \$60.00 |
| Blue             | <a href="#">DN-T12B-A</a>   | 100 | \$71.00 | <a href="#">DN-T10B-A</a>   | 100 | \$81.00 | <a href="#">DN-T8B</a>   | 50  | \$64.00 |
| Brown            | <a href="#">DN-T12BR-A</a>  | 100 | \$71.00 | <a href="#">DN-T10BR-A</a>  | 100 | \$81.00 | —                        | —   | —       |
| Black            | <a href="#">DN-T12BLK-A</a> | 100 | \$71.00 | <a href="#">DN-T10BLK-A</a> | 100 | \$81.00 | <a href="#">DN-T8BLK</a> | 50  | \$64.00 |
| Green            | <a href="#">DN-T12GRN-A</a> | 100 | \$71.00 | <a href="#">DN-T10GRN-A</a> | 100 | \$81.00 | <a href="#">DN-T8GRN</a> | 50  | \$64.00 |
| Orange           | <a href="#">DN-T12ORG-A</a> | 100 | \$71.00 | <a href="#">DN-T10ORG-A</a> | 100 | \$81.00 | <a href="#">DN-T8ORG</a> | 50  | \$64.00 |
| Red              | <a href="#">DN-T12RED-A</a> | 100 | \$71.00 | <a href="#">DN-T10RED-A</a> | 100 | \$81.00 | <a href="#">DN-T8RED</a> | 50  | \$64.00 |
| Yellow           | <a href="#">DN-T12YEL-A</a> | 100 | \$71.00 | <a href="#">DN-T10YEL-A</a> | 100 | \$81.00 | <a href="#">DN-T8YEL</a> | 50  | \$64.00 |
| White            | <a href="#">DN-T12W-A</a>   | 100 | \$71.00 | <a href="#">DN-T10W-A</a>   | 100 | \$81.00 | <a href="#">DN-T8W</a>   | 50  | \$64.00 |

## Technical Specifications

|                              |                                                                                                                    |     |           |                   |     |           |                      |     |          |
|------------------------------|--------------------------------------------------------------------------------------------------------------------|-----|-----------|-------------------|-----|-----------|----------------------|-----|----------|
| <b>Stripping Length</b>      | 10mm [0.39 in]                                                                                                     |     |           | 10mm [0.39 in]    |     |           | 12mm [0.47 in]       |     |          |
| <b>Tightening Torque</b>     | 0.5 N·m [4 lb·in]                                                                                                  |     |           | 0.8 N·m [7 lb·in] |     |           | 1.2 N·m [10.6 lb·in] |     |          |
| <b>Density</b>               | 200/m [60 pcs/ft]                                                                                                  |     |           | 166/m [50 pcs/ft] |     |           | 142/m [43 pcs/ft]    |     |          |
| <b>UL Approval*</b>          | 600V                                                                                                               | 20A | 24-12 AWG | 600V              | 30A | 24-10 AWG | 600V                 | 50A | 22-8 AWG |
| <b>VDE Approval</b>          | 800V                                                                                                               | 24A | 2.5 mm²   | 800V              | 32A | 4mm²      | 800V                 | 41A | 6mm²     |
| <b>Operating Temperature</b> | Ambient air temp: -20 to 105°C [-4 to 221°F]<br>Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F] |     |           |                   |     |           |                      |     |          |
| <b>SCCR Rating</b>           | 100kA                                                                                                              |     |           |                   |     |           |                      |     |          |
| <b>CE Conformity</b>         | CE (EN 60947-1 / EN 60947-7-1)                                                                                     |     |           |                   |     |           |                      |     |          |
| <b>Agency File #</b>         | UL E179129                                                                                                         |     |           |                   |     |           |                      |     |          |

## Accessories

|                       |                |                              |             |                         |                              |             |                         |                              |             |                         |         |
|-----------------------|----------------|------------------------------|-------------|-------------------------|------------------------------|-------------|-------------------------|------------------------------|-------------|-------------------------|---------|
| End Covers            |                | <a href="#">DN-EC1210</a>    | 100         | \$43.00                 | <a href="#">DN-EC1210</a>    | 100         | \$43.00                 | <a href="#">DN-EC86</a>      |             | 100                     | \$47.00 |
|                       |                | <a href="#">DN-EC1210MN</a>  | 25          | \$14.50                 | <a href="#">DN-EC1210MN</a>  | 25          | \$14.50                 | <a href="#">DN-EC86MN</a>    |             | 25                      | \$14.50 |
| Separators            |                | <a href="#">DN-S1210</a>     | 100         | \$51.00                 | <a href="#">DN-S1210</a>     | 100         | \$51.00                 | <a href="#">DN-S86</a>       |             | 100                     | \$61.00 |
|                       |                | <a href="#">DN-S1210MN</a>   | 25          | \$16.00                 | <a href="#">DN-S1210MN</a>   | 25          | \$16.00                 | <a href="#">DN-S86MN</a>     |             | 25                      | \$14.00 |
| Jumpers               | 2-pole         | <a href="#">DN-2J2Y</a>      | 100         | \$43.00                 | <a href="#">DN-2J4Y</a>      | 100         | \$46.00                 | —                            |             |                         |         |
|                       |                | <a href="#">DN-2J2YMN</a>    | 25          | \$13.00                 | <a href="#">DN-2J4YMN</a>    | 25          | \$14.50                 |                              |             |                         |         |
|                       | 3-pole         | <a href="#">DN-3J2Y</a>      | 100         | \$62.00                 | <a href="#">DN-3J4Y</a>      | 100         | \$74.00                 |                              |             |                         |         |
|                       |                | <a href="#">DN-3J2YMN</a>    | 25          | \$18.00                 | <a href="#">DN-3J4YMN</a>    | 25          | \$22.00                 |                              |             |                         |         |
|                       | 24-pole        | <a href="#">DN-24J2Y</a>     | 5           | \$28.00                 | <a href="#">DN-24J4Y</a>     | 5           | \$29.50                 | <a href="#">DN-24J8</a>      | 5           | \$41.00                 |         |
| Jumper Cutting Tool** |                | <a href="#">DN-J2CUT</a>     | 1           | \$79.00                 | <a href="#">DN-J4CUT</a>     | 1           | \$79.00                 | —                            |             |                         |         |
| Top Cover             |                | <a href="#">DN-C12</a>       | 100         | \$62.00                 | <a href="#">DN-C10</a>       | 100         | \$62.00                 | <a href="#">DN-C86</a>       |             | 100                     | \$62.00 |
|                       |                | <a href="#">DN-C12MN</a>     | 25          | \$14.00                 | <a href="#">DN-C10MN</a>     | 25          | \$14.00                 | <a href="#">DN-C86MN</a>     |             | 25                      | \$14.00 |
| Test Plug/Red         |                | <a href="#">DN-TPR</a>       | 10          | \$42.00                 | <a href="#">DN-TPR</a>       | 10          | \$42.00                 | —                            |             |                         |         |
| Test Plug/Black       |                | <a href="#">DN-TPB</a>       | 10          | \$42.00                 | <a href="#">DN-TPB</a>       | 10          | \$42.00                 |                              |             |                         |         |
| 35mm<br>DIN Rail      | 7.5 mm<br>high | <a href="#">DN-R35S1</a>     | 10          | \$39.00                 | <a href="#">DN-R35S1</a>     | 10          | \$39.00                 | <a href="#">DN-R35S1</a>     |             | 10                      | \$39.00 |
|                       |                | <a href="#">DN-R35S1-2</a>   | 2           | \$11.00                 | <a href="#">DN-R35S1-2</a>   | 2           | \$11.00                 | <a href="#">DN-R35S1-2</a>   |             | 2                       | \$11.00 |
|                       | 15mm<br>high   | <a href="#">DN-R35HS1</a>    | 10          | \$68.00                 | <a href="#">DN-R35HS1</a>    | 10          | \$68.00                 | <a href="#">DN-R35HS1</a>    |             | 10                      | \$68.00 |
|                       |                | <a href="#">DN-R35HS1-2</a>  | 2           | \$16.50                 | <a href="#">DN-R35HS1-2</a>  | 2           | \$16.50                 | <a href="#">DN-R35HS1-2</a>  |             | 2                       | \$16.50 |
| End Brackets          |                | <a href="#">DN-EB35</a>      | 50          | \$67.00                 | <a href="#">DN-EB35</a>      | 50          | \$67.00                 | <a href="#">DN-EB35</a>      |             | 50                      | \$67.00 |
|                       |                | <a href="#">DN-EB35MN</a>    | 20          | \$31.50                 | <a href="#">DN-EB35MN</a>    | 20          | \$31.50                 | <a href="#">DN-EB35MN</a>    |             | 20                      | \$31.50 |
|                       |                | <a href="#">DN-EB35-A</a>    | 50          | \$47.50                 | <a href="#">DN-EB35-A</a>    | 50          | \$47.50                 | <a href="#">DN-EB35-A</a>    |             | 50                      | \$47.50 |
|                       |                | <a href="#">DN-EB35-A-10</a> | 10          | \$12.00                 | <a href="#">DN-EB35-A-10</a> | 10          | \$12.00                 | <a href="#">DN-EB35-A-10</a> |             | 10                      | \$12.00 |
|                       |                | <a href="#">DN-QEB35</a>     | 50          | \$42.50                 | <a href="#">DN-QEB35</a>     | 50          | \$42.50                 | <a href="#">DN-QEB35</a>     |             | 50                      | \$42.50 |
|                       |                | <a href="#">DN-QEB35-10</a>  | 10          | \$11.50                 | <a href="#">DN-QEB35-10</a>  | 10          | \$11.50                 | <a href="#">DN-QEB35-10</a>  |             | 10                      | \$11.50 |
|                       |                | Angled Support Bracket       |             | <a href="#">DN-ASB1</a> | 50                           | \$107.00    | <a href="#">DN-ASB1</a> | 50                           | \$107.00    | <a href="#">DN-ASB1</a> |         |
| Marking Tags          |                | DN-LA or<br>DN-LT series     | 500/<br>100 | various                 | DN-L or<br>DN-LT series      | 500/<br>100 | various                 | DN-L or<br>DN-LT series      | 500/<br>100 | various                 |         |

\*Copper Wire Only


\*\*Jumper Cutting Tools DN-JxCUT cut the applicable multi-pole jumpers and maintain the jumper insulation.

Note: For more information on accessories, see the DINnectors Accessories section of this chapter.




# Single-Level Terminal Blocks


- Screw connection terminal
- 35mm DIN-rail mountable
- LVD 2006/95/EC

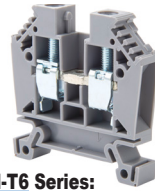

**DN-T6 Series:**  
EURO 10/35

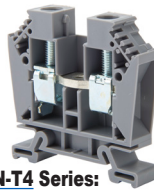

**DN-T4 Series:**  
EURO 16-25/35

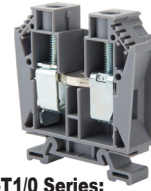

**DN-T1/0 Series:**  
EURO 35-50/35



**DN-T3/0 Series:**  
EURO 70/35

## Ordering Information

| Available Colors | Part Number            | Qty | Price   | Part Number            | Qty | Price   | Part Number              | Qty | Price   | Part Number             | Qty | Price    |
|------------------|------------------------|-----|---------|------------------------|-----|---------|--------------------------|-----|---------|-------------------------|-----|----------|
| Gray             | <a href="#">DN-T6</a>  | 50  | \$78.00 | <a href="#">DN-T4</a>  | 25  | \$67.00 | <a href="#">DN-T1/0</a>  | 25  | \$94.00 | <a href="#">DN-T3/0</a> | 10  | \$138.00 |
| Blue             | <a href="#">DN-T6B</a> | 50  | \$84.00 | <a href="#">DN-T4B</a> | 25  | \$70.00 | <a href="#">DN-T1/0B</a> | 25  | \$98.00 | –                       | –   | –        |

## Technical Specifications





|                              |                                                                                                                          |     |          |                      |      |          |                    |      |            |                   |      |           |
|------------------------------|--------------------------------------------------------------------------------------------------------------------------|-----|----------|----------------------|------|----------|--------------------|------|------------|-------------------|------|-----------|
| <b>Stripping Length</b>      | 12mm [0.47 in]                                                                                                           |     |          | 14mm [0.55 in]       |      |          | 17mm [0.67 in]     |      |            | 26mm [1.02 in]    |      |           |
| <b>Tightening Torque</b>     | 2.0 N·m [18.0 lb·in]                                                                                                     |     |          | 3.0 N·m [26.5 lb·in] |      |          | 5.0 N·m [44 lb·in] |      |            | 10 N·m [89 lb·in] |      |           |
| <b>Density</b>               | 111/m [33 pcs/ft]                                                                                                        |     |          | 83/m [25 pcs/ft]     |      |          | 62/m [19 pcs/ft]   |      |            | 38/m [11 pcs/ft]  |      |           |
| <b>UL Approval*</b>          | 600V                                                                                                                     | 65A | 20-6 AWG | 600V                 | 85A  | 14-4 AWG | 600V               | 130A | 14-1/0 AWG | 600V              | 185A | 4-3/0 AWG |
| <b>VDE Approval</b>          | 750V                                                                                                                     | 63A | 10mm²    | 750V                 | 110A | 25mm²    | 800V               | 150A | 50mm²      | 800V              | 192A | 70mm²     |
| <b>Operating Temperature</b> | Ambient air temperature: -20 to 105°C [-4 to 221°F] / Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F] |     |          |                      |      |          |                    |      |            |                   |      |           |
| <b>SCCR Rating</b>           | 100kA                                                                                                                    |     |          |                      |      |          |                    |      |            |                   |      |           |
| <b>CE Conformity</b>         | CE (EN 60947-1 / EN 60947-7-1)                                                                                           |     |          |                      |      |          |                    |      |            |                   |      |           |
| <b>Agency File #</b>         | UL E179129                                                                                                               |     |          |                      |      |          |                    |      |            |                   |      |           |

## Accessories

|                        |                |                             |             |          |                             |             |          |                             |             |          |                             |             |          |
|------------------------|----------------|-----------------------------|-------------|----------|-----------------------------|-------------|----------|-----------------------------|-------------|----------|-----------------------------|-------------|----------|
| End Covers             |                | <a href="#">DN-EC86</a>     | 100         | \$47.00  | <a href="#">DN-EC4</a>      | 50          | \$29.50  | <a href="#">DN-EC1/0</a>    | 50          | \$33.50  | Included                    | –           | –        |
|                        |                | <a href="#">DN-EC86MN</a>   | 25          | \$14.50  | <a href="#">DN-EC4MN</a>    | 10          | \$5.75   | <a href="#">DN-EC1/0MN</a>  | 10          | \$8.00   | –                           |             |          |
| Separators             |                | <a href="#">DN-S86</a>      | 100         | \$61.00  | –                           |             |          | –                           |             |          |                             |             |          |
|                        |                | <a href="#">DN-S86MN</a>    | 25          | \$14.00  |                             |             |          |                             |             |          |                             |             |          |
| Jumpers                | 2-pole         | <a href="#">DN-2J6</a>      | 100         | \$76.00  |                             |             |          |                             |             |          |                             |             |          |
|                        | 3-pole         | <a href="#">DN-3J6</a>      | 100         | \$132.00 |                             |             |          |                             |             |          |                             |             |          |
|                        | 4-pole         | <a href="#">DN-4J6</a>      | 100         | \$169.00 |                             |             |          |                             |             |          |                             |             |          |
| Multi-pole             |                | <a href="#">DN-55J6</a>     | 1           | \$26.50  |                             |             |          |                             |             |          |                             |             |          |
| Top Cover              |                | <a href="#">DN-C86</a>      | 100         | \$62.00  |                             |             |          |                             |             |          |                             |             |          |
|                        |                | <a href="#">DN-C86MN</a>    | 25          | \$14.00  |                             |             |          |                             |             |          |                             |             |          |
| 35mm<br>DIN Rail       | 7.5 mm<br>high | <a href="#">DN-R35S1</a>    | 10          | \$39.00  |                             |             |          |                             |             |          | <a href="#">DN-R35S1</a>    | 10          | \$39.00  |
|                        |                | <a href="#">DN-R35S1-2</a>  | 2           | \$11.00  | <a href="#">DN-R35S1-2</a>  | 2           | \$11.00  | <a href="#">DN-R35S1-2</a>  | 2           | \$11.00  | <a href="#">DN-R35S1-2</a>  | 2           | \$11.00  |
|                        | 15mm<br>high   | <a href="#">DN-R35HS1</a>   | 10          | \$68.00  | <a href="#">DN-R35HS1</a>   | 10          | \$68.00  | <a href="#">DN-R35HS1</a>   | 10          | \$68.00  | <a href="#">DN-R35HS1</a>   | 10          | \$68.00  |
|                        |                | <a href="#">DN-R35HS1-2</a> | 2           | \$16.50  | <a href="#">DN-R35HS1-2</a> | 2           | \$16.50  | <a href="#">DN-R35HS1-2</a> | 2           | \$16.50  | <a href="#">DN-R35HS1-2</a> | 2           | \$16.50  |
| Angled Support Bracket |                | <a href="#">DN-ASB1</a>     | 50          | \$107.00 | <a href="#">DN-ASB1</a>     | 50          | \$107.00 | <a href="#">DN-ASB1</a>     | 50          | \$107.00 | <a href="#">DN-ASB1</a>     | 50          | \$107.00 |
| Marking Tags           |                | DN-L or<br>DN-LT series     | 500/<br>100 | various  | DN-L or<br>DN-LT            | 500/<br>100 | various  | DN-L or<br>DN-LT series     | 500/<br>100 | various  | DN-L or<br>DN-LT series     | 500/<br>100 | various  |

\*Copper wire only

## Dimensions

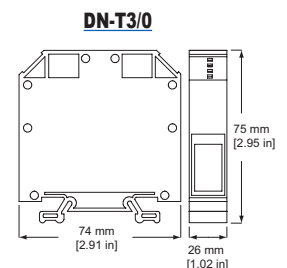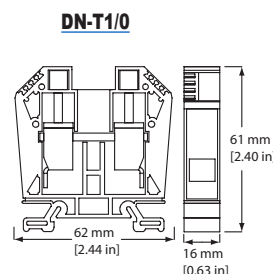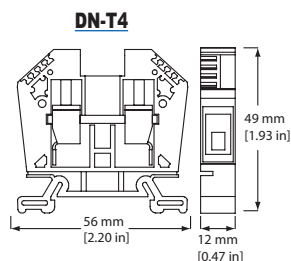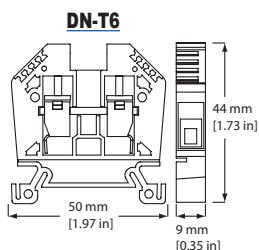

Note: Screw is a Hex Bolt,  
Size M8

 **DINnectors® Accessories**

## Marking Tags Cross Reference Charts - Screw-type

| <b>DINnector Marking Tags Cross Reference - Screw-type</b> |             |              |              |               |                 |
|------------------------------------------------------------|-------------|--------------|--------------|---------------|-----------------|
| <i>Block Type</i>                                          | <i>DN-L</i> | <i>DN-LA</i> | <i>DN-LT</i> | <i>DN-LAT</i> | <i>DN-EMLBL</i> |
| <b>DN-T12</b>                                              | –           | X            | X            | –             | –               |
| <b>DN-T10</b>                                              | X           | –            | X            | –             | –               |
| <b>DN-T8</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-T6</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-T4</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-T1/0</b>                                             | X           | –            | X            | –             | –               |
| <b><u>DN-T3/0</u></b>                                      | X           | –            | X            | –             | –               |
| <b>DN-D10</b>                                              | X           | –            | X            | –             | –               |
| <b>DN-D10X</b>                                             | X           | –            | X            | –             | –               |
| <b>DN-D10LED</b>                                           | X           | –            | X            | –             | –               |
| <b>DN-D10DR</b>                                            | X           | –            | X            | –             | –               |
| <b>DN-TL14</b>                                             | –           | –            | –            | X             | –               |
| <b>DN-THERM</b>                                            | X           | –            | X            | –             | –               |
| <b>DN-EMXM1</b>                                            | –           | X            | X            | –             | X               |
| <b>DN-EMXDV</b>                                            | –           | X            | X            | –             | X               |
| <b>DN-M10</b>                                              | –           | –            | X            | –             | –               |
| <b><u>DN-MG10</u></b>                                      | –           | –            | X            | –             | –               |
| <b>DN-G10</b>                                              | X           | –            | X            | –             | –               |
| <b>DN-G8</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-G6</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-G4</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-G1/0</b>                                             | X           | –            | X            | –             | –               |
| <b>DN-F6</b>                                               | X           | –            | X            | –             | –               |
| <b>DN-F10</b>                                              | X           | –            | X            | –             | –               |
| <b>DN-DIS2</b>                                             | –           | X            | X            | –             | –               |
| <b>DN-DIS4</b>                                             | X           | –            | X            | –             | –               |
| <b>DN-FE2</b>                                              | –           | X            | X            | –             | –               |
| <b>DN-FE4</b>                                              | X           | –            | X            | –             | –               |
| <b>DN-DIS10</b>                                            | X           | –            | X            | –             | –               |
| <b>DN-KBD12</b>                                            | –           | X            | X            | –             | –               |


Continued on next page

# **DINnectors** Accessories

## Marking Tags

| Marking Tags DN-L Series       |                                        |     |         |
|--------------------------------|----------------------------------------|-----|---------|
| Part Number                    | Marking Sequence                       | Qty | Price   |
| <a href="#"><u>DN-L50</u></a>  | 1-50                                   | 500 | \$56.00 |
| <a href="#"><u>DN-L100</u></a> | 51-100                                 | 500 | \$56.00 |
| <a href="#"><u>DN-L150</u></a> | 101-150                                | 500 | \$56.00 |
| <a href="#"><u>DN-L200</u></a> | 151-200                                | 500 | \$56.00 |
| <a href="#"><u>DN-L250</u></a> | 201-250                                | 500 | \$56.00 |
| <a href="#"><u>DN-L300</u></a> | 251-300                                | 500 | \$56.00 |
| <a href="#"><u>DN-L350</u></a> | 301-350                                | 500 | \$56.00 |
| <a href="#"><u>DN-L400</u></a> | 351-400                                | 500 | \$56.00 |
| <a href="#"><u>DN-L450</u></a> | 401-450                                | 500 | \$56.00 |
| <a href="#"><u>DN-LB</u></a>   | Blank                                  | 500 | \$38.00 |
| <a href="#"><u>DN-LS</u></a>   | L1, L2, L3, L, N, GND, +, -, COM, COM* | 500 | \$56.00 |


### Dimensions

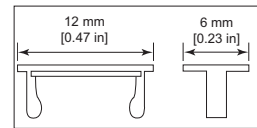

- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500.
- The DN-L tags fit all DINnectors 6mm wide and wider.
- There will be a gap between tags on blocks wider than 6mm.
- Material: Thermoplastic with heat embossed black print.

| Marking Tags DN-LA Series       |                                        |     |         |
|---------------------------------|----------------------------------------|-----|---------|
| Part Number                     | Marking Sequence                       | Qty | Price   |
| <a href="#"><u>DN-LA100</u></a> | 1-100                                  | 500 | \$56.00 |
| <a href="#"><u>DN-LA200</u></a> | 101-200                                | 500 | \$56.00 |
| <a href="#"><u>DN-LA300</u></a> | 201-300                                | 500 | \$56.00 |
| <a href="#"><u>DN-LA400</u></a> | 301-400                                | 500 | \$56.00 |
| <a href="#"><u>DN-LAB</u></a>   | Blank Tags                             | 500 | \$56.00 |
| <a href="#"><u>DN-LAS</u></a>   | L1, L2, L3, L, N, GND, +, -, COM, COM* | 500 | \$56.00 |


### Dimensions

 

- The marking sequence of 100 tags (i.e. 1-100) is printed five times in each package of 500.
- The DN-LA tags fit all DINnectors 5mm wide and wider. There will be a gap between tags on blocks wider than 5mm.
- Material: Thermoplastic with heat embossed black print.

| Marking Tags DN-LAT Series         |                                   |     |         |
|------------------------------------|-----------------------------------|-----|---------|
| Part Number                        | Marking Sequence                  | Qty | Price   |
| <a href="#"><u>DN-LAT100-A</u></a> | 1-100                             | 500 | \$49.00 |
| <a href="#"><u>DN-LAT200-A</u></a> | 101-200                           | 500 | \$49.00 |
| <a href="#"><u>DN-LAT300-A</u></a> | 201-300                           | 500 | \$49.00 |
| <a href="#"><u>DN-LAT400-A</u></a> | 301-400                           | 500 | \$49.00 |
| <a href="#"><u>DN-LAT500-A</u></a> | 401-500                           | 500 | \$49.00 |
| <a href="#"><u>DN-LAT600-A</u></a> | 501-600                           | 500 | \$49.00 |
| <a href="#"><u>DN-LATB-A</u></a>   | Blank Tags                        | 500 | \$35.50 |
| <a href="#"><u>DN-LATS-A</u></a>   | L1, L2, L3, L, N, +, -, COM, COM* | 500 | \$49.00 |


### Dimensions

 

- The marking sequence of 500 tags (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

| Marking Tags DN-QL Series       |                                   |     |         |
|---------------------------------|-----------------------------------|-----|---------|
| Part Number                     | Marking Sequence                  | Qty | Price   |
| <a href="#"><u>DN-QL100</u></a> | 1-100                             | 500 | \$42.50 |
| <a href="#"><u>DN-QL200</u></a> | 101-200                           | 500 | \$42.50 |
| <a href="#"><u>DN-QL300</u></a> | 201-300                           | 500 | \$42.50 |
| <a href="#"><u>DN-QL400</u></a> | 301-400                           | 500 | \$42.50 |
| <a href="#"><u>DN-QL500</u></a> | 401-500                           | 500 | \$42.50 |
| <a href="#"><u>DN-QLB</u></a>   | Blank Tags                        | 500 | \$36.00 |
| <a href="#"><u>DN-QLS</u></a>   | L1, L2, L3, L, N, +, -, COM, COM* | 500 | \$49.00 |

### Dimensions

 


- The marking sequence of 500 (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

# DINnectors® Accessories


## Marking Tags continued

| Marking Tags DN-LT Series |                  |     |         |
|---------------------------|------------------|-----|---------|
| Part Number               | Marking Sequence | Qty | Price   |
| <a href="#">DN-LT15</a>   | 1-5              | 100 | \$10.00 |
| <a href="#">DN-LT60</a>   | 6-0              | 100 | \$10.00 |
| <a href="#">DN-LT1</a>    | 1                | 100 | \$10.00 |
| <a href="#">DN-LT2</a>    | 2                | 100 | \$10.00 |
| <a href="#">DN-LT3</a>    | 3                | 100 | \$10.00 |
| <a href="#">DN-LT4</a>    | 4                | 100 | \$10.00 |
| <a href="#">DN-LT5</a>    | 5                | 100 | \$10.00 |
| <a href="#">DN-LT6</a>    | 6                | 100 | \$10.00 |
| <a href="#">DN-LT7</a>    | 7                | 100 | \$10.00 |
| <a href="#">DN-LT8</a>    | 8                | 100 | \$10.00 |
| <a href="#">DN-LT9</a>    | 9                | 100 | \$10.00 |
| <a href="#">DN-LT0</a>    | 0                | 100 | \$10.00 |
| <a href="#">DN-LTBLNK</a> | Unprinted        | 100 | \$10.00 |
| <a href="#">DN-LTA</a>    | A                | 100 | \$10.00 |
| <a href="#">DN-LTB</a>    | B                | 100 | \$10.00 |
| <a href="#">DN-LTC</a>    | C                | 100 | \$10.00 |
| <a href="#">DN-LTD</a>    | D                | 100 | \$10.00 |
| <a href="#">DN-LTE</a>    | E                | 100 | \$10.00 |
| <a href="#">DN-LTF</a>    | F                | 100 | \$10.00 |
| <a href="#">DN-LTG</a>    | G                | 100 | \$10.00 |
| <a href="#">DN-LTH</a>    | H                | 100 | \$10.00 |
| <a href="#">DN-LTI</a>    | I                | 100 | \$10.00 |
| <a href="#">DN-LTJ</a>    | J                | 100 | \$10.00 |
| <a href="#">DN-LTK</a>    | K                | 100 | \$10.00 |
| <a href="#">DN-LTL</a>    | L                | 100 | \$10.00 |
| <a href="#">DN-LTM</a>    | M                | 100 | \$10.00 |
| <a href="#">DN-LTN</a>    | N                | 100 | \$10.00 |
| -                         | -                | -   | -       |
| <a href="#">DN-LTP</a>    | P                | 100 | \$10.00 |
| <a href="#">DN-LTQ</a>    | Q                | 100 | \$10.00 |
| <a href="#">DN-LTR</a>    | R                | 100 | \$10.00 |
| <a href="#">DN-LTS</a>    | S                | 100 | \$10.00 |
| <a href="#">DN-LTT</a>    | T                | 100 | \$10.00 |
| <a href="#">DN-LTU</a>    | U                | 100 | \$10.00 |
| <a href="#">DN-LTV</a>    | V                | 100 | \$10.00 |
| <a href="#">DN-LTW</a>    | W                | 100 | \$10.00 |
| <a href="#">DN-LTX</a>    | X                | 100 | \$10.00 |
| <a href="#">DN-LTY</a>    | Y                | 100 | \$10.00 |
| <a href="#">DN-LTZ</a>    | Z                | 100 | \$10.00 |
| <a href="#">DN-LTGND</a>  | ⊕                | 100 | \$10.00 |
| <a href="#">DN-LTPOS</a>  | +                | 100 | \$10.00 |
| <a href="#">DN-LTNEG</a>  | -                | 100 | \$10.00 |
| <a href="#">DN-LTAC</a>   | ~                | 100 | \$10.00 |
| <a href="#">DN-LTDC</a>   | =                | 100 | \$10.00 |

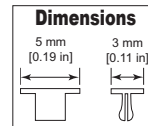


- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
- Material: Thermoplastic with heat embossed black print.

**DN-MTA marking tag adapter**

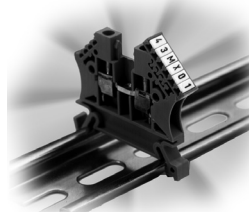

**DN-MTA dimensions**

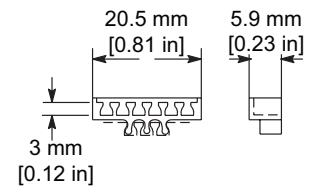

| Part Number            | Description                                    | Qty | Price   |
|------------------------|------------------------------------------------|-----|---------|
| <a href="#">DN-MTA</a> | Marking tag adapter holds up to six DN-LT tags | 50  | \$14.50 |

Note: [DN-MTA](#) adapter does not fit [DN-T12-A](#) terminal blocks.

# DINnectors® Accessories

## Terminal Marking Accessories

**DN-EMLBL1****DN-EMLBL2****DN-EMLBL3**

| Part Number      | Description            | For Use With                                                         | Qty | Price   |
|------------------|------------------------|----------------------------------------------------------------------|-----|---------|
| <b>DN-EMLBL1</b> | Blank labels           | DN-EMPEG1 pin protectors for<br>DN-xEMXxx plug-in terminal<br>blocks | 100 | \$9.25  |
| <b>DN-EMLBL2</b> | Labels printed 1 – 12  |                                                                      | 100 | \$13.00 |
| <b>DN-EMLBL3</b> | Labels printed 13 – 24 |                                                                      | 100 | \$13.00 |

## Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

| Part Number  | Description                                                                           | Qty | Price  |
|--------------|---------------------------------------------------------------------------------------|-----|--------|
| <b>DN-MP</b> | Staedtler-Mars marking pen, for use with blank marking tags. Permanent Ink, fine tip. | 1   | \$4.50 |

**Marking pen**

## Wire Marking Accessories

**DN-WMTAG1 wire tags &  
DN-WM-x wire tag holders**

| Part Number      | Description                                                                      | For Use With                 | Qty | Price   |
|------------------|----------------------------------------------------------------------------------|------------------------------|-----|---------|
| <b>DN-WMTAG1</b> | Wire tag – blank                                                                 | all DN-WM-x wire tag holders | 525 | \$60.00 |
| <b>DN-WM-1</b>   | Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire | <b>DN-WMTAG1</b>             | 200 | \$12.50 |
| <b>DN-WM-2</b>   | Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire |                              | 200 | \$12.50 |
| <b>DN-WM-3</b>   | Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire  |                              | 100 | \$8.25  |
| <b>DN-WM-4</b>   | Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire      |                              | 100 | \$7.75  |