



Fuse Terminal Blocks

Fuse terminal blocks are available for 1 1/4" x 1/4" and 5x20mm-5x25mm fuses and they are 35mm DIN rail mountable. These blocks are available with or without a blown fuse LED. Fuse terminal blocks with blown fuse LED are polarity sensitive. The hinge side is positive.




DN-F6 Series:
EURO S 10H/35



DN-F6L Series:
EURO S 10H/35



DN-F10 Series:
EURO S 4LH/35

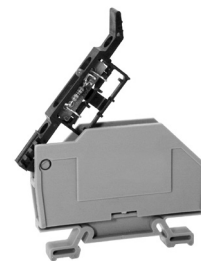

DN-F10L Series:
EURO S 4LH/35

Ordering Information

	Part Number	Qty	Price	Part Number	Qty	Price	Part Number	Qty	Price	Part Number	Qty	Price
Gray Terminal Block	DN-F6	25	\$156.00	-			DN-F10	50	\$251.00	-		
	DN-F6MN	7	\$34.00				DN-F10MN	10	\$39.50			
12-24 VAC/DC*	-			DN-F6L24	10	\$89.00	-			DN-F10L24	10	\$87.00
110 VAC/DC*				DN-F6L110	10	\$89.00				DN-F10L110	10	\$87.00
220 VAC/DC*				DN-F6L220	10	\$89.00				DN-F10L220	10	\$87.00

Technical Specifications

Stripping Length	12mm [0.47 in]			10mm [0.39 in]		
Tightening Torque	0.8 N·m [10 lb·in]			0.6 N·m [5.3 lb·in]		
Density	100/m [30 pcs/ft]			100/m [30 pcs/ft]		
UL Approval**	600V	30A	20-6 AWG	250V per EN60947-7-3	6.3A per EN60947-7-3	24-10 AWG
VDE Approval	750V	8A	–	250V per EN60947-7-3	6.3A per EN60947-7-3	4mm²
Fuse Size (not supplied)	1 1/4" x 1/4"			5x20mm-5x25mm		
Indicator Type	Non-indicating		LED blown fuse indicator	Non-indicating		LED blown fuse indicator
Operating Temperature	Ambient air temperature: -20 to 85°C [-4 to 185°F] / Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]					
SCCR Rating	10kA per Table SB4.1, 2009, UL 508A, Maximum short circuit current rating for unmarked components					
CE Conformity	CE (EN 60947-1 / 60947-7-3)					
Agency File #	UL E179129 / LR84816					

Accessories

End Covers		Included			Included			Included			Included		
35mm DIN Rail	7.5 mm high	DN-R35S1	10	\$39.00	DN-R35S1	10	\$39.00	DN-R35S1	10	\$39.00	DN-R35S1	10	\$39.00
		DN-R35S1-2	2	\$11.00	DN-R35S1-2	2	\$11.00	DN-R35S1-2	2	\$11.00	DN-R35S1-2	2	\$11.00
	15mm high	DN-R35HS1	10	\$68.00	DN-R35HS1	10	\$68.00	DN-R35HS1	10	\$68.00	DN-R35HS1	10	\$68.00
		DN-R35HS1-2	2	\$16.50	DN-R35HS1-2	2	\$16.50	DN-R35HS1-2	2	\$16.50	DN-R35HS1-2	2	\$16.50
End Brackets		DN-EB35	50	\$67.00	DN-EB35	50	\$67.00	DN-EB35	50	\$67.00	DN-EB35	50	\$67.00
		DN-EB35MN	20	\$31.50	DN-EB35MN	20	\$31.50	DN-EB35MN	20	\$31.50	DN-EB35MN	20	\$31.50
		DN-EB35-A	50	\$47.50	DN-EB35-A	50	\$47.50	DN-EB35-A	50	\$47.50	DN-EB35-A	50	\$47.50
		DN-EB35-A-10	10	\$12.00	DN-EB35-A-10	10	\$12.00	DN-EB35-A-10	10	\$12.00	DN-EB35-A-10	10	\$12.00
		DN-QEB35	50	\$42.50	DN-QEB35	50	\$42.50	DN-QEB35	50	\$42.50	DN-QEB35	50	\$42.50
		DN-QEB35-10	10	\$11.50	DN-QEB35-10	10	\$11.50	DN-QEB35-10	10	\$11.50	DN-QEB35-10	10	\$11.50
Angled Support Bracket		DN-ASB1	50	\$107.00	DN-ASB1	50	\$107.00	DN-ASB1	50	\$107.00	DN-ASB1	50	\$107.00
Marking Tags		DN-L*** or DN-LT****	500/100	various	DN-L*** or DN-LT****	500/100	various	DN-L*** or DN-LT****	500/100	various	DN-L*** or DN-LT****	500/100	various


*Working voltage **For copper wire only ***On lever arm ****On terminal body

Note: DN-F6 series fuse holders will accommodate the following AutomationDirect fuses: ABC, AGC, MDA and MDL Series.


DN-F10 series fuse holders will accommodate the following AutomationDirect fuses: GMA, GMC, S500, and S506 Series.

For more information on accessories, see the DINnectors Accessories section of this chapter.


DN-F6 / DN-F6MN

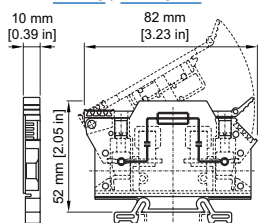


DN-F6L

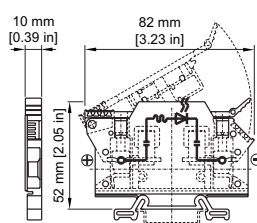

DN-F10 / DN-F10MN

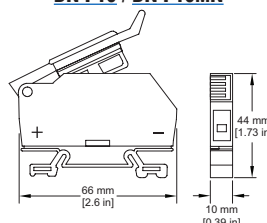

DN-F10L

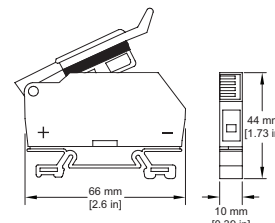

 DINnectors® Accessories
Marking Tags Cross Reference Charts - Screw-type

DINnector Marking Tags Cross Reference - Screw-type					
<i>Block Type</i>	<i>DN-L</i>	<i>DN-LA</i>	<i>DN-LT</i>	<i>DN-LAT</i>	<i>DN-EMLBL</i>
DN-T12	–	X	X	–	–
DN-T10	X	–	X	–	–
DN-T8	X	–	X	–	–
DN-T6	X	–	X	–	–
DN-T4	X	–	X	–	–
DN-T1/0	X	–	X	–	–
<u>DN-T3/0</u>	X	–	X	–	–
DN-D10	X	–	X	–	–
DN-D10X	X	–	X	–	–
DN-D10LED	X	–	X	–	–
DN-D10DR	X	–	X	–	–
DN-TL14	–	–	–	X	–
DN-THERM	X	–	X	–	–
DN-EMXM1	–	X	X	–	X
DN-EMXDV	–	X	X	–	X
DN-M10	–	–	X	–	–
<u>DN-MG10</u>	–	–	X	–	–
DN-G10	X	–	X	–	–
DN-G8	X	–	X	–	–
DN-G6	X	–	X	–	–
DN-G4	X	–	X	–	–
DN-G1/0	X	–	X	–	–
DN-F6	X	–	X	–	–
DN-F10	X	–	X	–	–
DN-DIS2	–	X	X	–	–
DN-DIS4	X	–	X	–	–
DN-FE2	–	X	X	–	–
DN-FE4	X	–	X	–	–
DN-DIS10	X	–	X	–	–
DN-KBD12	–	X	X	–	–

Continued on next page


DINnectors® Accessories

Marking Tags

Marking Tags DN-L Series

Part Number	Marking Sequence	Qty	Price
<u>DN-L50</u>	1-50	500	\$56.00
<u>DN-L100</u>	51-100	500	\$56.00
<u>DN-L150</u>	101-150	500	\$56.00
<u>DN-L200</u>	151-200	500	\$56.00
<u>DN-L250</u>	201-250	500	\$56.00
<u>DN-L300</u>	251-300	500	\$56.00
<u>DN-L350</u>	301-350	500	\$56.00
<u>DN-L400</u>	351-400	500	\$56.00
<u>DN-L450</u>	401-450	500	\$56.00
<u>DN-LB</u>	Blank	500	\$38.00
<u>DN-LS</u>	L1, L2, L3, L, N, GND, +, -, COM, COM*	500	\$56.00

Dimensions

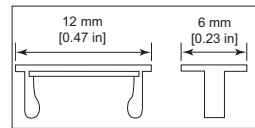


- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500.
- The DN-L tags fit all DINnectors 6mm wide and wider.
- There will be a gap between tags on blocks wider than 6mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LA Series

Part Number	Marking Sequence	Qty	Price
<u>DN-LA100</u>	1-100	500	\$56.00
<u>DN-LA200</u>	101-200	500	\$56.00
<u>DN-LA300</u>	201-300	500	\$56.00
<u>DN-LA400</u>	301-400	500	\$56.00
<u>DN-LAB</u>	Blank Tags	500	\$56.00
<u>DN-LAS</u>	L1, L2, L3, L, N, GND, +, -, COM, COM*	500	\$56.00

 Dimensions




- The marking sequence of 100 tags (i.e. 1-100) is printed five times in each package of 500.
- The DN-LA tags fit all DINnectors 5mm wide and wider. There will be a gap between tags on blocks wider than 5mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LAT Series

Part Number	Marking Sequence	Qty	Price
<u>DN-LAT100-A</u>	1-100	500	\$49.00
<u>DN-LAT200-A</u>	101-200	500	\$49.00
<u>DN-LAT300-A</u>	201-300	500	\$49.00
<u>DN-LAT400-A</u>	301-400	500	\$49.00
<u>DN-LAT500-A</u>	401-500	500	\$49.00
<u>DN-LAT600-A</u>	501-600	500	\$49.00
<u>DN-LATB-A</u>	Blank Tags	500	\$35.50
<u>DN-LATS-A</u>	L1, L2, L3, L, N, +, -, COM, COM*	500	\$49.00

 Dimensions




- The marking sequence of 500 tags (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-QL Series

Part Number	Marking Sequence	Qty	Price
<u>DN-QL100</u>	1-100	500	\$42.50
<u>DN-QL200</u>	101-200	500	\$42.50
<u>DN-QL300</u>	201-300	500	\$42.50
<u>DN-QL400</u>	301-400	500	\$42.50
<u>DN-QL500</u>	401-500	500	\$42.50
<u>DN-QLB</u>	Blank Tags	500	\$36.00
<u>DN-QLS</u>	L1, L2, L3, L, N, +, -, COM, COM*	500	\$49.00

 Dimensions




- The marking sequence of 500 (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

DINnectors® Accessories


Marking Tags continued

Marking Tags DN-LT Series			
Part Number	Marking Sequence	Qty	Price
DN-LT15	1-5	100	\$10.00
DN-LT60	6-0	100	\$10.00
DN-LT1	1	100	\$10.00
DN-LT2	2	100	\$10.00
DN-LT3	3	100	\$10.00
DN-LT4	4	100	\$10.00
DN-LT5	5	100	\$10.00
DN-LT6	6	100	\$10.00
DN-LT7	7	100	\$10.00
DN-LT8	8	100	\$10.00
DN-LT9	9	100	\$10.00
DN-LT0	0	100	\$10.00
DN-LTBLNK	Unprinted	100	\$10.00
DN-LTA	A	100	\$10.00
DN-LTB	B	100	\$10.00
DN-LTC	C	100	\$10.00
DN-LTD	D	100	\$10.00
DN-LTE	E	100	\$10.00
DN-LTF	F	100	\$10.00
DN-LTG	G	100	\$10.00
DN-LTH	H	100	\$10.00
DN-LTI	I	100	\$10.00
DN-LTJ	J	100	\$10.00
DN-LTK	K	100	\$10.00
DN-LTL	L	100	\$10.00
DN-LTM	M	100	\$10.00
DN-LTN	N	100	\$10.00
-	-	-	-
DN-LTP	P	100	\$10.00
DN-LTQ	Q	100	\$10.00
DN-LTR	R	100	\$10.00
DN-LTS	S	100	\$10.00
DN-LTT	T	100	\$10.00
DN-LTU	U	100	\$10.00
DN-LTV	V	100	\$10.00
DN-LTW	W	100	\$10.00
DN-LTX	X	100	\$10.00
DN-LTY	Y	100	\$10.00
DN-LTZ	Z	100	\$10.00
DN-LTGND	⊕	100	\$10.00
DN-LTPOS	+	100	\$10.00
DN-LTNEG	-	100	\$10.00
DN-LTAC	~	100	\$10.00
DN-LTDC	=	100	\$10.00

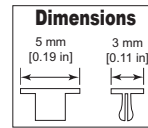


- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
- Material: Thermoplastic with heat embossed black print.

DN-MTA marking tag adapter

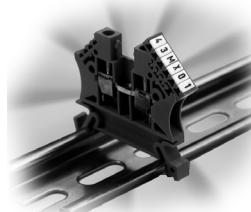

DN-MTA dimensions

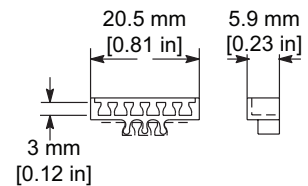

Part Number	Description	Qty	Price
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	\$14.50

Note: [DN-MTA](#) adapter does not fit [DN-T12-A](#) terminal blocks.

DINnectors® Accessories

Terminal Marking Accessories

**DN-EMLBL1****DN-EMLBL2****DN-EMLBL3**

Part Number	Description	For Use With	Qty	Price
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMXxx plug-in terminal blocks	100	\$9.25
DN-EMLBL2	Labels printed 1 – 12		100	\$13.00
DN-EMLBL3	Labels printed 13 – 24		100	\$13.00

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part Number	Description	Qty	Price
DN-MP	Staedtler-Mars marking pen, for use with blank marking tags. Permanent Ink, fine tip.	1	\$4.50

**Marking pen**

Wire Marking Accessories

**DN-WMTAG1 wire tags &
DN-WM-x wire tag holders**

Part Number	Description	For Use With	Qty	Price
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	\$60.00
DN-WM-1	Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	\$12.50
DN-WM-2	Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	\$12.50
DN-WM-3	Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	\$8.25
DN-WM-4	Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire		100	\$7.75