

# Modular Ferrule Fuse Blocks for Midget Class and CC Fuses



## Description

- BCM Series for use with Class CC fuses EDCC, HCTR and HCLR
- BMM Series for use with Midget Class Midget fuses MCL, MEQ, MEN & MOL

### Mounting

35mm DIN rail or panel mount

## Specifications

### Materials:

Base – Thermoplastic

Terminals – Tin-plated bimetallic copper

Covers – Thermoplastic

Screws and pressure plates – Zinc-plated steel

**SCCR:** 200kA

### Flammability rating:

Blocks – UL 94V0, self-extinguishing

Covers – UL 94HB, self-extinguishing

### Operating and storage temp range:

Blocks – -40° to 120°C [-40° to 248°F]

Covers – indicating -20° to 90°C [-4° to 194°F]

– non-indicating -40° to 120°C [-40° to 248°F]

### Wire:

Cu – 75°/90°C [167°/194°F]

Ring or Fork terminal to fit a #10-32 screw

## Agency Approvals


### Fuse Blocks

- BCM – UL® Listed E14853 - IZLT
- BMM and BCCM UL Recognized E14853-IZLT2
- CSA® Certified 47235-6225-01
- CE
- RoHS Compliant
- Conflict mineral free
- REACH Compliant

### Covers

- Covers are included in the overall UL Listing/Recognition and CSA Certification
- IP20 finger-safe
- RoHS compliant
- REACH Compliant

To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

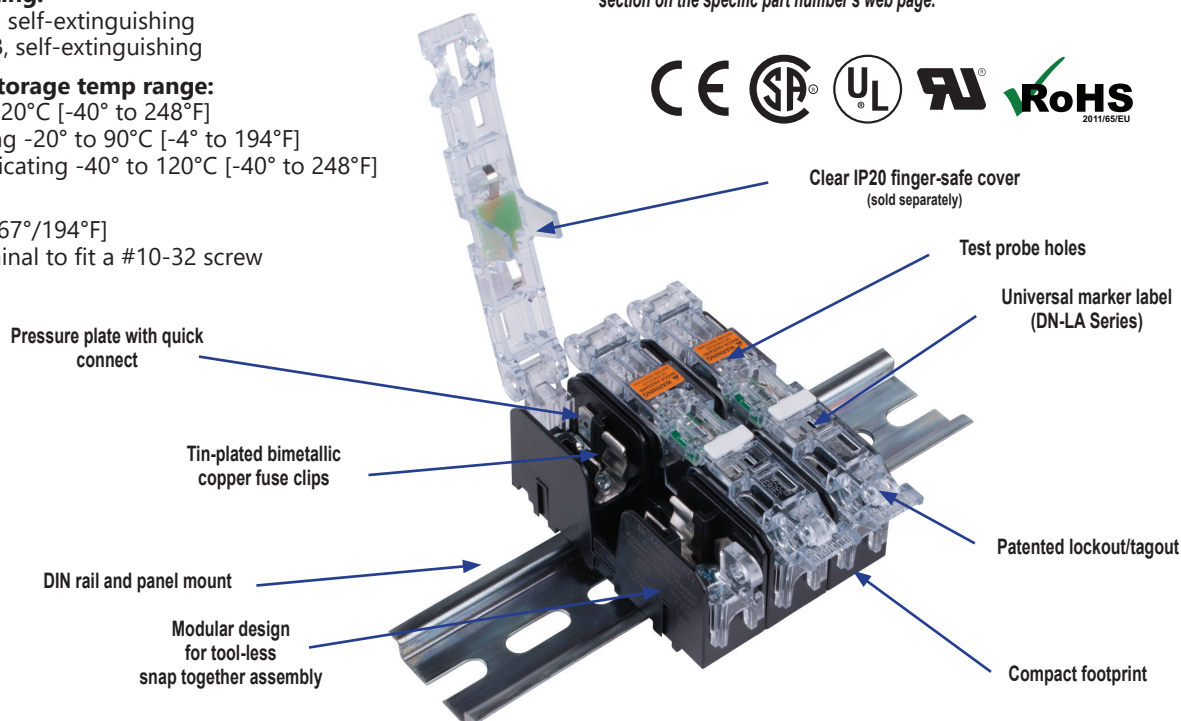

| Pressure Plate (with Quick Connect**) Modular Ferrule Fuse Blocks for Midget Class and CC Fuses |                           |        |          |            |      |       |                         |               |                       |                |                           |                              |        |
|-------------------------------------------------------------------------------------------------|---------------------------|--------|----------|------------|------|-------|-------------------------|---------------|-----------------------|----------------|---------------------------|------------------------------|--------|
| Class                                                                                           | Part Number               | Pc/pkg | Price    | Volts      | Amps | Poles | Wire Range <sup>1</sup> |               | Torque<br>lb-in [N·m] | Wt.<br>lb [kg] | Covers* (Sold Separately) |                              |        |
|                                                                                                 |                           |        |          |            |      |       | Solid and Stranded      | Fine Stranded |                       |                | w/o Indication            | With Indication <sup>3</sup> | Pc/pkg |
| Midget                                                                                          | BMM603-1PQ                | 15     | \$132.00 | 600V AC/DC | 30   | 1     | 18-10 AWG               | 18-10 AWG     | 20 [2.3]              | 0.05 [0.04]    | CVR-CCM-QC<br>\$27.50     | CVRI-CCM-QC<br>\$35.50       | 3      |
|                                                                                                 | BMM603-2PQ                | 5      | \$75.00  |            |      | 2     |                         |               |                       | 0.15 [0.06]    |                           |                              |        |
|                                                                                                 | BMM603-3PQ                | 5      | \$95.00  |            |      | 3     |                         |               |                       | 0.20 [0.10]    |                           |                              |        |
|                                                                                                 | BMM603-1PQ-1              | 1      | \$9.75   |            |      | 1     |                         |               |                       | 0.05 [0.04]    |                           |                              |        |
| CC                                                                                              | BCM603-1PQ                | 15     | \$181.00 |            |      | 1     |                         |               |                       | 0.05 [0.04]    |                           |                              |        |
|                                                                                                 | BCM603-2PQ                | 5      | \$93.00  |            |      | 2     |                         |               |                       | 0.15 [0.06]    |                           |                              |        |
|                                                                                                 | BCM603-3PQ                | 5      | \$116.00 |            |      | 3     |                         |               |                       | 0.20 [0.10]    |                           |                              |        |
|                                                                                                 | BCM603-1PQ-1              | 1      | \$13.00  |            |      | 1     |                         |               |                       | 0.05 [0.04]    |                           |                              |        |
| Combo                                                                                           | BCCMM603-3PQ <sup>2</sup> | 5      | \$127.00 |            |      | 3     |                         |               |                       | 0.20 [0.10]    |                           |                              |        |

<sup>1</sup> Ratings are for copper wire only.

<sup>2</sup> Combination modular fuse block for use with transformers. Accepts two (2) Class CC and one (1) Midget class fuse.

<sup>3</sup> Open fuse indication requires 90V minimum and closed circuit to operate.

\*Once installed, the cover cannot be removed.



\*\*Quick connect terminal rated for 20A maximum.



# Modular Ferrule Fuse Blocks for Midget Class and CC Fuses

## Dimensions

in [mm]

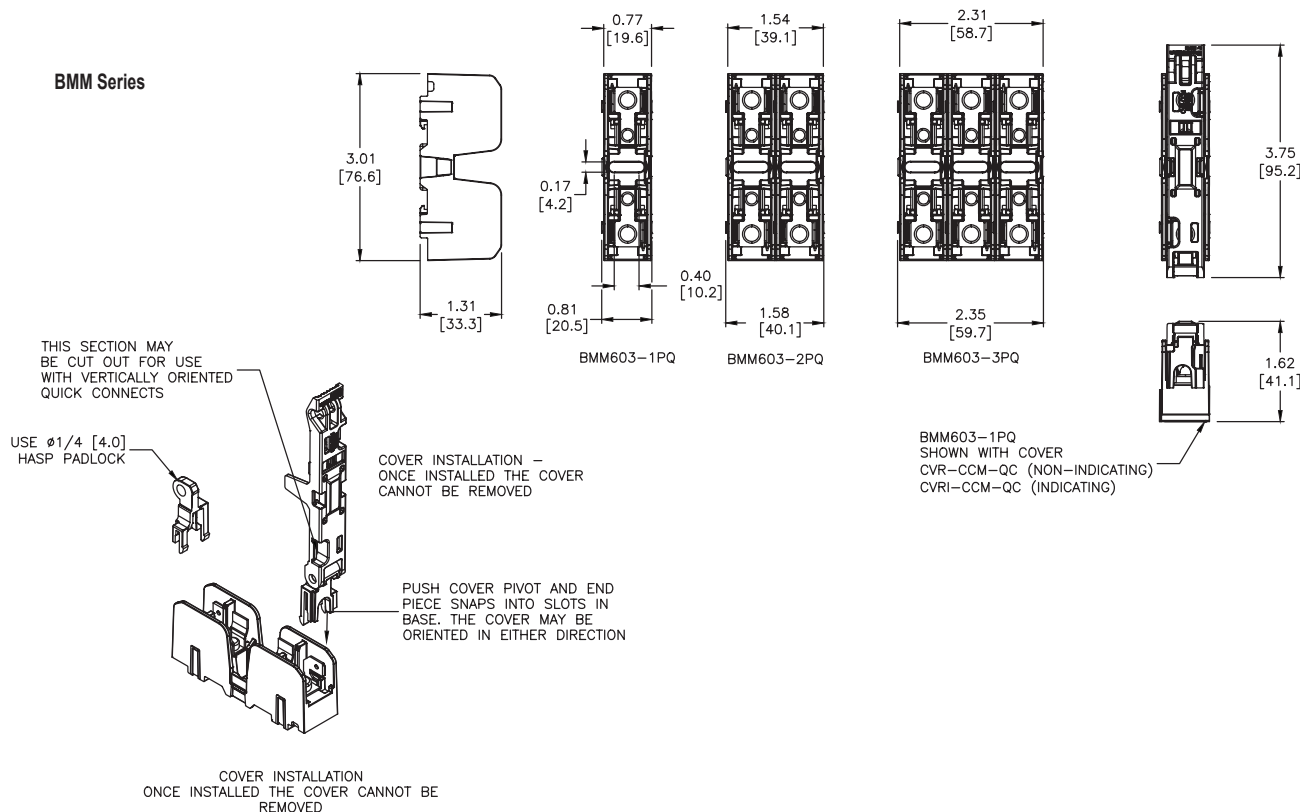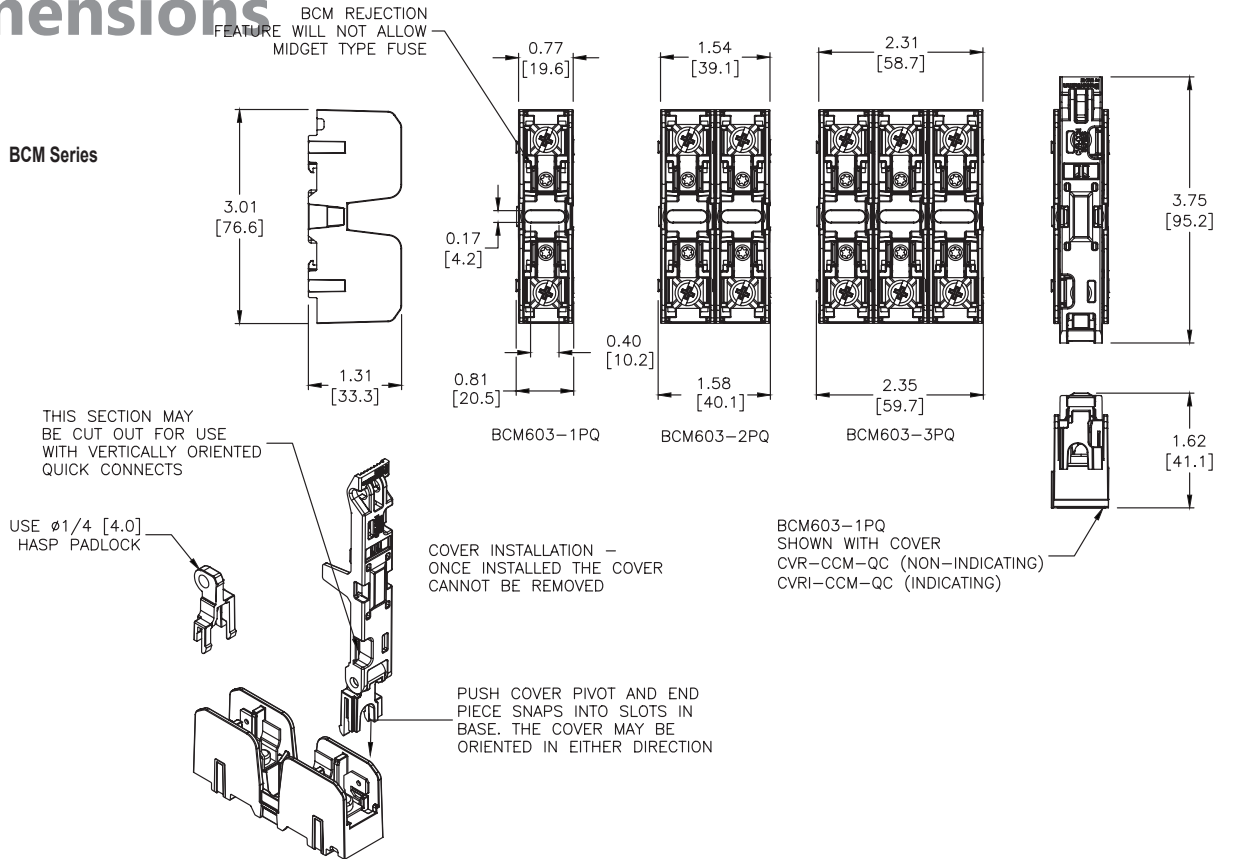


Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings. Dimensions are approximate. Not for construction purposes.

# Modular Ferrule Fuse Blocks for Midget Class and CC Fuses

## Dimensions

in [mm]

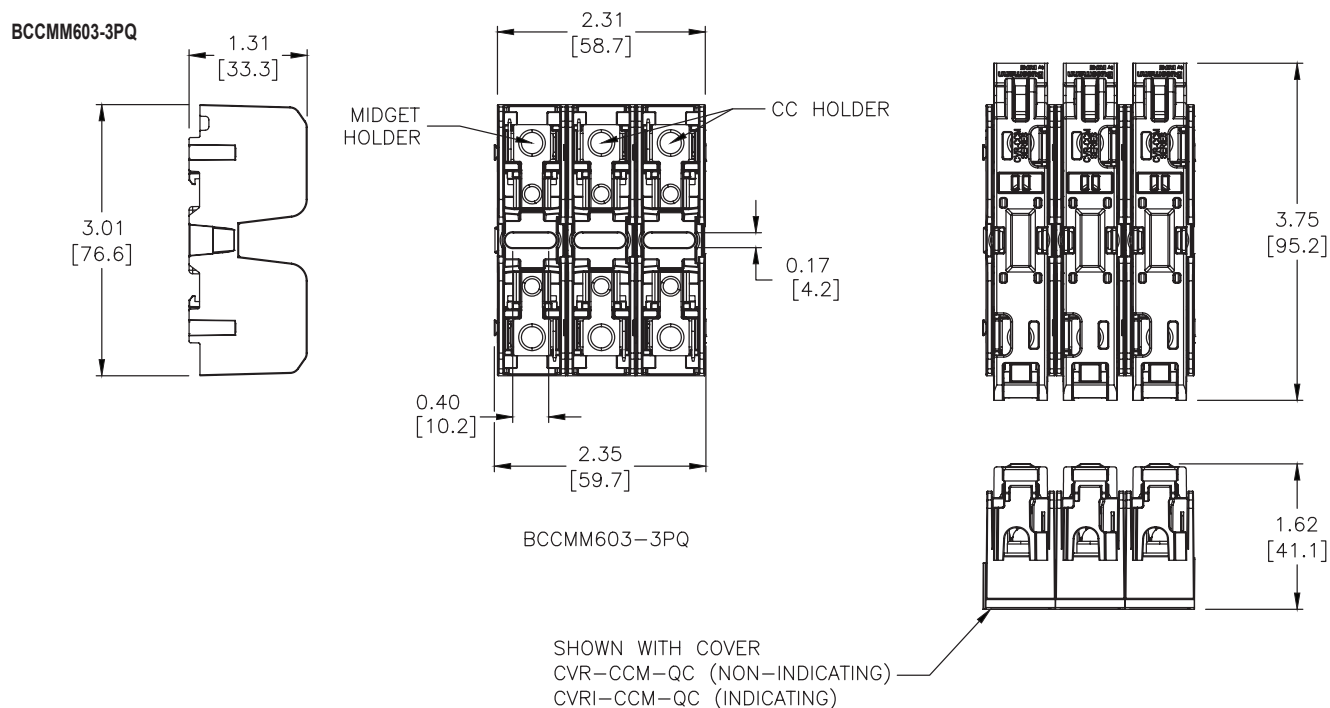

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings. Dimensions are approximate. Not for construction purposes.