


WA-F1/F2 Panels for Single-Door Freestanding Enclosures

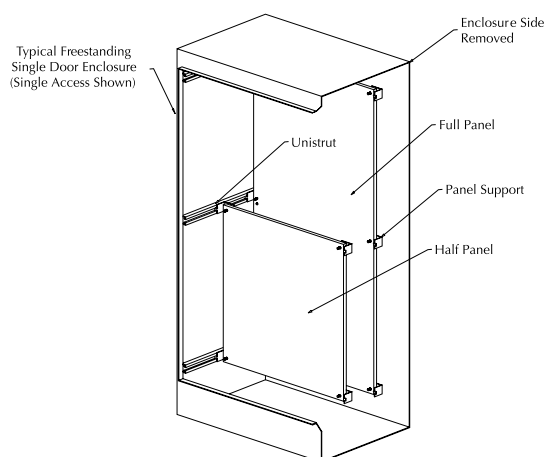

Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

Painted Steel	Price	Galvanized	Price	Steel Gauge	Panel Size HxW	Subpanel Type
<u>WA60P24F1</u>	\$359.00	—	—	12	48.00 x 20.00 [1219 x 508]	Full
<u>WA60P24F2</u>	\$259.00	—	—	10	24.88 x 20.00 [632 x 508]	Half
<u>WA60P36F1</u>	\$463.00	<u>WA60P36F1G</u>	\$463.00	12	48.00 x 32.00 [1219 x 813]	Full
<u>WA60P36F2</u>	\$292.00	<u>WA60P36F2G</u>	\$292.00	12	24.88 x 32.00 [632 x 813]	Half
<u>WA72P24F1</u>	\$402.00	<u>WA72P24F1G</u>	\$402.00	12	60.00 x 20.00 [1524 x 508]	Full
<u>WA72P30F1</u>	\$468.00	<u>WA72P30F1G</u>	\$506.00	12	60.00 x 26.00 [1524 x 660]	Full
<u>WA72P36F1</u>	\$533.00	<u>WA72P36F1G</u>	\$533.00	12	60.00 x 32.00 [1524 x 813]	Full
<u>WA90P24F1</u>	\$468.00	<u>WA90P24F1G</u>	\$468.00	12	78.00 x 20.00 [1981 x 508]	Full
<u>WA90P36F1</u>	\$637.00	<u>WA90P36F1G</u>	\$637.00	12	78.00 x 32.00 [1981 x 813]	Full


Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.


If used in a two-door enclosure, a center panel support must be ordered.

Suffix F1= full panel, F2 = half panel

Dimensions

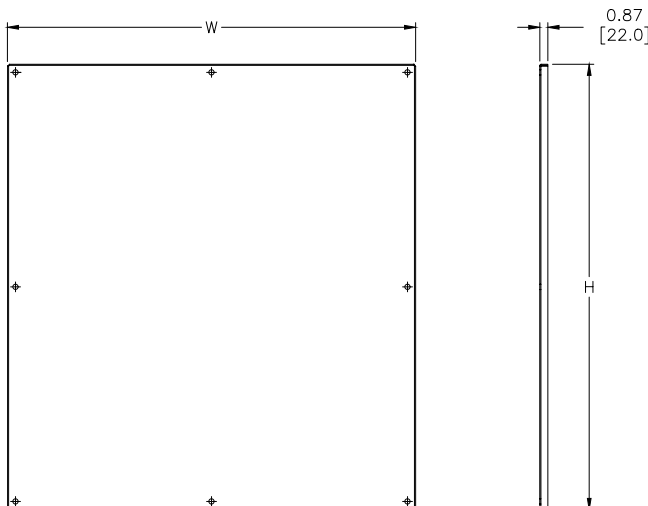

WA-F1/F2 Panels for Two-Door Freestanding Enclosures

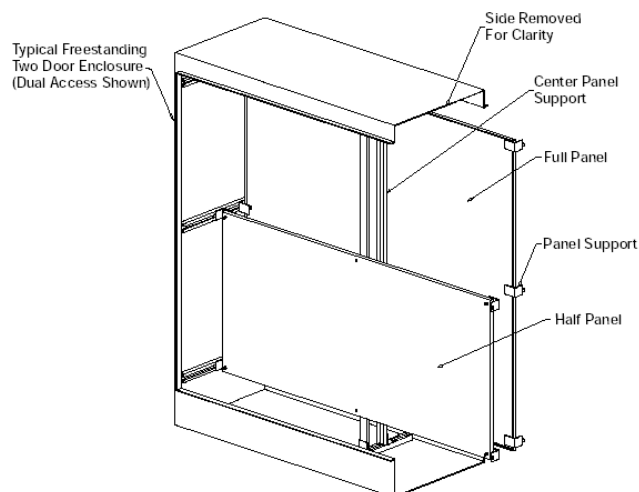


Description

- Panels for two-door single-access and two-door dual-access, freestanding NEMA 12 enclosures
- Manufactured of 10-gauge steel and can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)

Painted Steel	Price	Galvanized	Price	Panel Size AxB	Subpanel Type
WA60P48F1	\$744.00	WA60P48F1G	\$744.00	48.00 x 44.00 [1219 x 1118]	Full
WA72P48F1	\$841.00	WA72P48F1G	\$841.00	60.00 x 44.00 [1524 x 1118]	Full
WA72P60F1	\$975.00	WA72P60F1G	\$975.00	60.00 x 56.00 [1524 x 1422]	Full
WA72P72F1	\$1,108.00	—	—	68.00 x 68.00 [1727 x 1727]	Full
WA90P48F1	\$989.00	WA90P48F1G	\$1,071.00	78.00 x 44.00 [1981 x 1118]	Full
WA90P72F1	\$1,335.00	—	—	78.00 x 68.00 [1981 x 1727]	Full


Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawing.
Suffix F1 = full panel, F2 = half panel

Dimensions

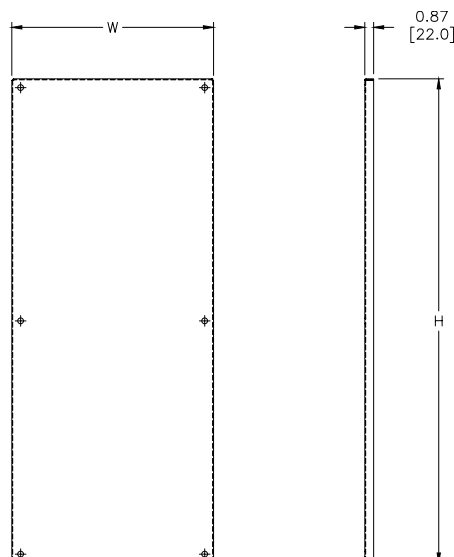

Note: Center panel support is supplied with a regular two-door enclosure panel. This support is used only as a brace. It is not intended to be used as a support for single-door subpanels, relay racks, etc. Use WA_FSCPS panel supports for this purpose.

WA-SMP Series Side-Mount Panels for Freestanding Enclosures

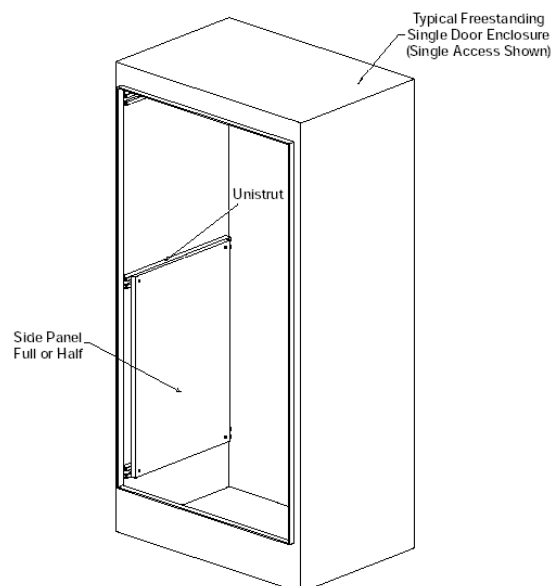

Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12-gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

Painted Steel	Price	Panel Size AxB
WA72SMP14	\$248.00	60.00 x 14.00 [1524 x 356]
WA72SMP20	\$303.00	60.00 x 20.00 [1524 x 508]

Note: Dimensions in inches [millimeters].

Dimensions

