

Enclosure Subpanels




Subpanels for Small NEMA 1, NEMA 3R and NEMA 12 Enclosures

- 14-gauge
- Painted steel and perforated subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized panels have a conductive finish (no paint)
- Panels listed fit the following enclosures:
 - NEMA 1 small (N1C)
 - NEMA 3R small (RHC)
 - NEMA 12 WA_GIE



Subpanels for Small NEMA 1, NEMA 3R and NEMA 12 Enclosures			
Painted Steel	Price	Nominal Enclosure Size HxW	Subpanel Size AxB
<u>N1P0606</u>	\$5.25	6 x 6	4.25 x 4.25 [108 x 108]
<u>N1P0608</u>	\$6.25	6 x 8	6.25 x 4.25 [159 x 108]
<u>N1P0808</u>	\$7.25	8 x 8	6.25 x 6.25 [159 x 159]
<u>N1P0810</u>	\$8.50	8 x 10	8.25 x 6.25 [210 x 159]
<u>N1P1010</u>	\$10.00	10 x 10	8.25 x 8.25 [210 x 210]
<u>N1P1012</u>	\$11.50	10 x 12	10.25 x 8.25 [260 x 210]
<u>N1P1212</u>	\$13.75	12 x 12	10.25 x 10.25 [260 x 260]
<u>N1P1214</u>	\$15.50	12 x 14	12.25 x 10.25 [311 x 260]
<u>N1P1216</u>	\$17.50	12 x 16	14.25 x 10.25 [362 x 260]
<u>N1P1220</u>	\$24.00	12 x 20	18.25 x 10.25 [464 x 260]
Notes: Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawing.			

Dimensions

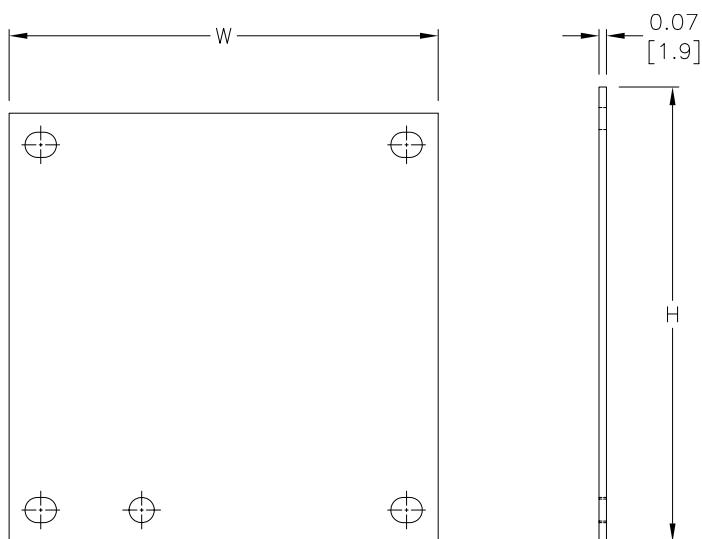

Note: Perforated panels have 0.13in [3 mm] diameter holes at 0.25in [6 mm] spacing.