

# Enclosure Subpanels




## Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles

- 12-gauge steel (perforated subpanels are 14-gauge)
- Subpanels with any side over 17 in [432 mm] have 0.25 in [6mm] flange on all sides
- Painted steel and perforated subpanels white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint) Panels listed fit the following enclosures:
- NEMA 1 large (N1C, 42 in [1067 mm] width and wider)
- NEMA 12 single door wall-mount (N12)
- NEMA 12 two-door wall-mount (WA\_WF)
- NEMA 12 single door flush wall-mount (WA\_FM)
- NEMA 4 (N4) and 4X (SSN) single door wall-mount
- NEMA 12 operator consoles (WC9)
- NEMA 12 Wall Disconnect (SDN12\_PL and ABN12)
- NEMA 4 and 4X Wall-Mount Disconnect (SSN4 and SSN4X)



Note: Use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures only. Do NOT use NPxxxx subpanels in N412 Ultimate Series enclosures with a C in the suffix.

## Dimensions

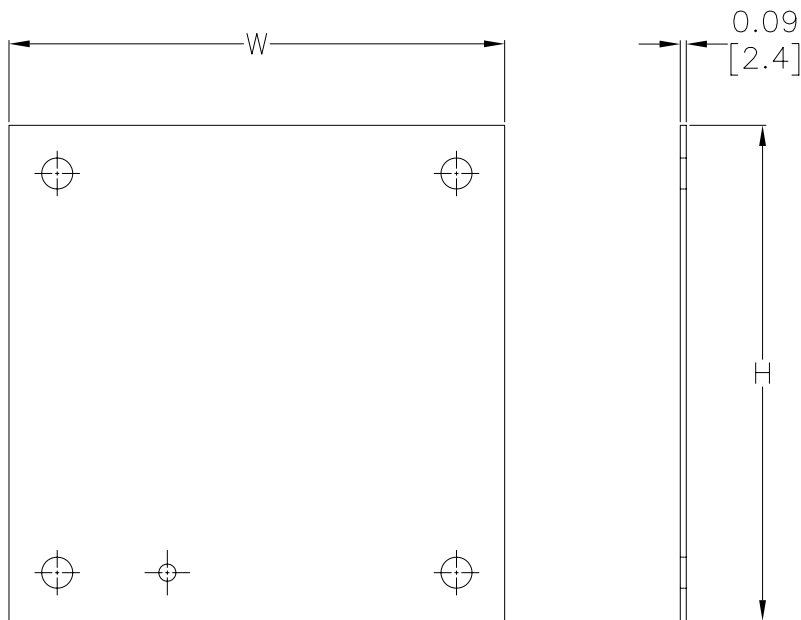

NOTE:  
SUBPANELS LARGER THAN  
20 X 20 HAVE (2) 0.31"  
GROUND HOLES.

Note: Perforated panels have 0.13in [3 mm] diameter holes at 0.25 in [6 mm] spacing.

# Enclosure Subpanels



| Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles                                                                                                                  |          |                         |          |                          |          |                            |                            |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------|-------------------------|----------|--------------------------|----------|----------------------------|----------------------------|
| Painted Steel                                                                                                                                                                                               | Price    | Galvanized              | Price    | 304 Stainless Steel      | Price    | Nominal Enclosure Size HxW | Subpanel Size AxB          |
| <a href="#">NP1212</a>                                                                                                                                                                                      | \$18.50  | —                       | —        | —                        | —        | 12 x 12                    | 9.00 x 9.00 [229 x 229]    |
| <a href="#">NP1224</a>                                                                                                                                                                                      | \$45.50  | —                       | —        | —                        | —        | 24 x 12                    | 9.00 x 21.00 [229 x 533]   |
| <a href="#">NP1612</a>                                                                                                                                                                                      | \$33.00  | —                       | —        | <a href="#">NP1612SS</a> | \$87.00  | 12 x 16<br>16 x 12         | 13.00 x 9.00 [330 x 229]   |
| <a href="#">NP1616</a>                                                                                                                                                                                      | \$40.50  | —                       | —        | <a href="#">NP1616SS</a> | \$106.00 | 16 x 16                    | 13.00 x 13.00 [330 x 330]  |
| <a href="#">NP2012</a>                                                                                                                                                                                      | \$38.00  | —                       | —        | —                        | —        | 20 x 12                    | 17.00 x 9.00 [432 x 229]   |
| <a href="#">NP2016</a>                                                                                                                                                                                      | \$48.00  | —                       | —        | <a href="#">NP2016SS</a> | \$128.00 | 20 x 16                    | 17.00 x 13.00 [432 x 330]  |
| <a href="#">NP2020</a>                                                                                                                                                                                      | \$58.00  | —                       | —        | <a href="#">NP2020SS</a> | \$165.00 | 20 x 20                    | 17.00 x 17.00 [432 x 432]  |
| <a href="#">NP2416</a>                                                                                                                                                                                      | \$56.00  | —                       | —        | <a href="#">NP2416SS</a> | \$159.00 | 24 x 16                    | 21.00 x 13.00 [533 x 330]  |
| <a href="#">NP2420</a>                                                                                                                                                                                      | \$75.00  | —                       | —        | <a href="#">NP2420SS</a> | \$200.00 | 24 x 20                    | 21.00 x 17.00 [533 x 432]  |
| <a href="#">NP2424</a>                                                                                                                                                                                      | \$86.00  | —                       | —        | <a href="#">NP2424SS</a> | \$233.00 | 24 x 24                    | 21.00 x 21.00 [533 x 533]  |
| <a href="#">NP3016</a>                                                                                                                                                                                      | \$75.00  | —                       | —        | —                        | —        | 30 x 16                    | 27.00 x 13.00 [686 x 330]  |
| <a href="#">NP3020</a>                                                                                                                                                                                      | \$90.00  | —                       | —        | <a href="#">NP3020SS</a> | \$268.00 | 30 x 20                    | 27.00 x 17.00 [686 x 432]  |
| <a href="#">NP3024</a>                                                                                                                                                                                      | \$105.00 | —                       | —        | <a href="#">NP3024SS</a> | \$283.00 | 24 x 30<br>30 x 24         | 27.00 x 21.00 [686 x 533]  |
| <a href="#">NP3030</a>                                                                                                                                                                                      | \$147.00 | —                       | —        | <a href="#">NP3030SS</a> | \$452.00 | 30 x 30                    | 27.00 x 27.00 [686 x 686]  |
| <a href="#">NP3624</a>                                                                                                                                                                                      | \$125.00 | —                       | —        | <a href="#">NP3624SS</a> | \$386.00 | 36 x 24                    | 33.00 x 21.00 [838 x 533]  |
| <a href="#">NP3630</a>                                                                                                                                                                                      | \$167.00 | —                       | —        | <a href="#">NP3630SS</a> | \$443.00 | 30 x 36<br>36 x 30         | 33.00 x 27.00 [838 x 686]  |
| <a href="#">NP3636</a>                                                                                                                                                                                      | \$196.00 | —                       | —        | <a href="#">NP3636SS</a> | \$535.00 | 36 x 36                    | 33.00 x 33.00 [838 x 838]  |
| <a href="#">NP4024</a>                                                                                                                                                                                      | \$151.00 | —                       | —        | —                        | —        | 40 x 24                    | 37.00 x 21.00 [940 x 533]  |
| <a href="#">NP4224</a>                                                                                                                                                                                      | \$144.00 | —                       | —        | —                        | —        | 42 x 24                    | 39.00 x 21.00 [991 x 533]  |
| <a href="#">NP4230</a>                                                                                                                                                                                      | \$191.00 | —                       | —        | <a href="#">NP4230SS</a> | \$563.00 | 42 x 30                    | 39.00 x 27.00 [991 x 686]  |
| <a href="#">NP4236</a>                                                                                                                                                                                      | \$225.00 | —                       | —        | <a href="#">NP4236SS</a> | \$676.00 | 42 x 36                    | 39.00 x 33.00 [991 x 838]  |
| <a href="#">NP4824</a>                                                                                                                                                                                      | \$163.00 | —                       | —        | —                        | —        | 48 x 24                    | 45.00 x 21.00 [1143 x 533] |
| <a href="#">NP4830</a>                                                                                                                                                                                      | \$215.00 | —                       | —        | —                        | —        | 48 x 30                    | 45.00 x 27.00 [1143 x 686] |
| <a href="#">NP4836</a>                                                                                                                                                                                      | \$254.00 | —                       | —        | <a href="#">NP4836SS</a> | \$731.00 | 48 x 36                    | 45.00 x 33.00 [1143 x 838] |
| <a href="#">NP6030</a>                                                                                                                                                                                      | \$263.00 | —                       | —        | —                        | —        | 60 x 30                    | 57.00 x 27.00 [1448 x 686] |
| <a href="#">NP6036</a>                                                                                                                                                                                      | \$313.00 | —                       | —        | <a href="#">NP6036SS</a> | \$965.00 | 60 x 36                    | 57.00 x 33.00 [1448 x 838] |
| <a href="#">NP7230</a>                                                                                                                                                                                      | \$302.00 | <a href="#">NP7230G</a> | \$327.00 | —                        | —        | 72 x 30                    | 69.00 x 27.00 [1753 x 686] |
| <a href="#">NP7236</a>                                                                                                                                                                                      | \$371.00 | <a href="#">NP7236G</a> | \$402.00 | —                        | —        | 72 x 36                    | 69.00 x 33.00 [1753 x 838] |
| Notes: Dimensions in inches [millimeters].<br>Letters in table correspond to letters on dimensional drawing.<br>Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table. |          |                         |          |                          |          |                            |                            |