

Enclosure Subpanels





Subpanels for Ultimate Series Wall-Mount Enclosures

- 12-gauge steel
- Subpanels with dimensions 30 x 30 in [762 x 762 mm] and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels listed fit all styles of N412 Ultimate Series wall-mount enclosures, including slope top and disconnect enclosures

Note: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.



Dimensions

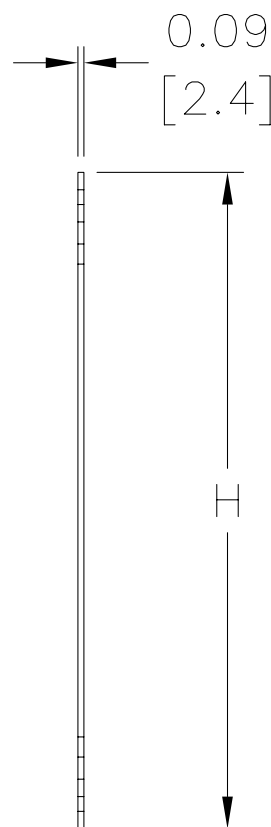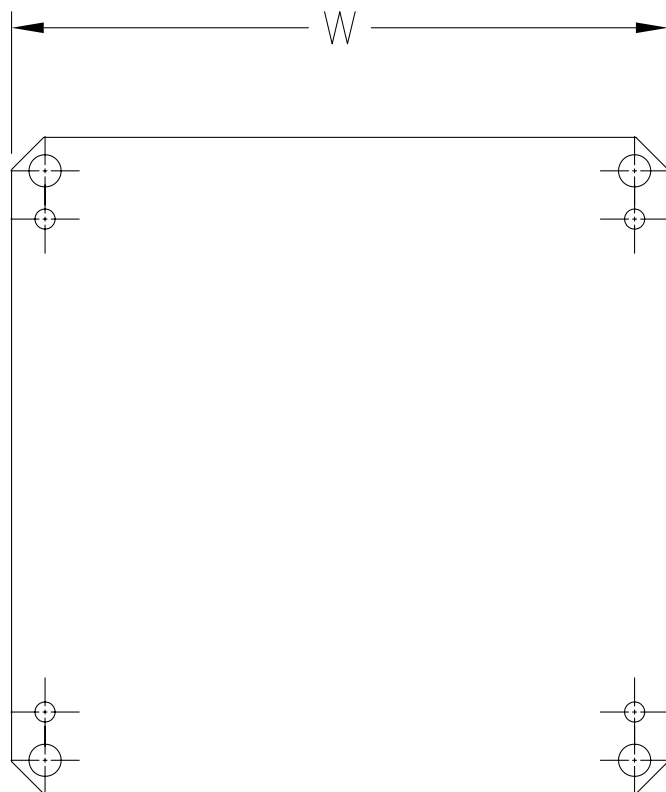

Enclosure Subpanels



Subpanels for Ultimate Series Wall-Mount Enclosures

Subpanels for Ultimate Series Wall-Mount Enclosures					
Painted Steel	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
<u>NP1212C</u>	\$16.50	—	—	12 x 12	10.20 x 10.20 [259 x 259]
<u>NP1612C</u>	\$17.75	<u>NP1612SSC</u>	\$80.00	16 x 12	14.20 x 10.20 [361 x 259]
<u>NP1616C</u>	\$42.50	<u>NP1616SSC</u>	\$97.00	16 x 16	14.20 x 14.20 [361 x 361]
<u>NP2016C</u>	\$51.00	<u>NP2016SSC</u>	\$117.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
<u>NP2020C</u>	\$61.00	<u>NP2020SSC</u>	\$151.00	20 x 20	18.20 x 18.20 [462 x 462]
<u>NP2416C</u>	\$59.00	<u>NP2416SSC</u>	\$145.00	24 x 16	22.20 x 14.20 [564 x 361]
<u>NP2420C</u>	\$59.00	<u>NP2420SSC</u>	\$183.00	24 x 20	22.20 x 18.20 [564 x 462]
<u>NP2424C</u>	\$91.00	<u>NP2424SSC</u>	\$213.00	24 x 24	22.20 x 22.20 [564 x 564]
<u>NP3020C</u>	\$95.00	—	—	30 x 20	28.20 x 18.20 [716 x 462]
<u>NP3024C</u>	\$110.00	<u>NP3024SSC</u>	\$280.00	30 x 24	28.20 x 22.20 [716 x 564]
<u>NP3030C</u>	\$155.00	<u>NP3030SSC</u>	\$382.00	30 x 30	28.20 x 28.20 [716 x 716]
<u>NP3624C</u>	\$132.00	<u>NP3624SSC</u>	\$326.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
<u>NP3630C</u>	\$175.00	<u>NP3630SSC</u>	\$405.00	36 x 30	34.20 x 28.20 [869 x 716]
<u>NP3636C</u>	\$206.00	<u>NP3636SSC</u>	\$489.00	36 x 36	34.20 x 34.20 [869 x 869]
<u>NP4224C</u>	\$256.00	—	—	24 x 42	40.20 x 22.20 [1021 x 564]
<u>NP4024C</u>	\$158.00	—	—	40 x 24	38.20 x 22.20 [970 x 564]
<u>NP4242C</u>	\$439.00	—	—	42 x 42	40.20 x 40.20 [1021 x 1021]
<u>NP4230C</u>	\$236.00	—	—	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
<u>NP4236C</u>	\$236.00	<u>NP4236SSC</u>	\$618.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
<u>NP4824C</u>	\$171.00	—	—	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
<u>NP4830C</u>	\$352.00	—	—	30 x 48	46.20 x 28.20 [1173 x 716]
<u>NP4842C</u>	\$590.00	—	—	42 x 48	46.20 x 40.20 [1173 x 1021]
<u>NP4836C</u>	\$267.00	<u>NP4836SSC</u>	\$618.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
<u>NP4848C</u>	\$656.00	—	—	48 x 48	46.20 x 46.20 [1173 x 1173]
<u>NP6030C</u>	\$468.00	—	—	30 x 60	58.20 x 28.20 [1478 x 716]
<u>NP6036C</u>	\$328.00	<u>NP6036SSC</u>	\$883.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
<u>NP6042C</u>	\$659.00	—	—	42 x 60	58.20 x 40.20 [1478 x 1021]

Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawing.
Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.