


Eclipse Series NEMA 12 Hinged Double-Door Wall-Mount with Handle

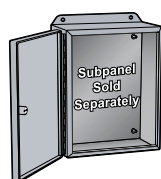

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Impressive styling features like hidden hinges and an attractive latching system make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14-gauge steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided for increased strength and rigidity – designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Oil-resistant gaskets are permanently secured.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Doors are secured with a 3-point key-lockable handle.

- Uses Eclipse 1/4 turn handles.
- Hinges are constructed from 304 stainless steel.
- Key-lockable handle is zinc diecast with black epoxy finish.
- Hinge pins are stainless steel.
- Door alignment guides provided on all doors.

Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG).

Listings

- UL 508A Type 3R, 4, and 12 [UL File E65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, and 12
 - IEC 60529, IP66




Eclipse Series NEMA 12 Hinged Double-Door Wall-Mount with Handle							
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Optional Painted Subpanel	Size HxW	Drawing Link
EN4TD24428GY	\$781.00	EN4TD24428LG	\$820.00	24.00 x 42.00 x 8.82 [610 x 1067 x 224]	EP2442	22.17 x 40.17 [563 x 1020]	PDF
EN4TD244210GY	\$819.00	EN4TD244210LG	\$860.00	24.00 x 42.00 x 10.82 [610 x 1067 x 275]	EP2442	22.17 x 40.17 [563 x 1020]	PDF
EN4TD24488GY	\$846.00	EN4TD24488LG	\$888.00	24.00 x 48.00 x 8.82 [610 x 1219 x 224]	EP2448	22.17 x 46.17 [563 x 1173]	PDF
EN4TD304210GY	\$926.00	EN4TD304210LG	\$973.00	30.00 x 42.00 x 10.82 [762 x 1067 x 275]	EP3042	28.17 x 40.17 [716 x 1020]	PDF
EN4TD30488GY	\$958.00	EN4TD30488LG	\$1,006.00	30.00 x 48.00 x 8.82 [762 x 1219 x 224]	EP3048	28.17 x 46.17 [716 x 1173]	PDF
EN4TD304810GY	\$967.00	EN4TD304810LG	\$1,015.00	30.00 x 48.00 x 10.82 [762 x 1219 x 275]	EP3048	28.17 x 46.17 [716 x 1173]	PDF
EN4TD306010GY	\$1,152.00	EN4TD306010LG	\$1,211.00	30.00 x 60.00 x 10.82 [762 x 1524 x 275]	EP3060	28.17 x 58.17 [716 x 1478]	PDF
EN4TD306012GY	\$1,235.00	EN4TD306012LG	\$1,297.00	30.00 x 60.00 x 12.82 [762 x 1524 x 326]	EP3060	28.17 x 58.17 [716 x 1478]	PDF
EN4TD364212GY	\$1,104.00	EN4TD364212LG	\$1,159.00	36.00 x 42.00 x 12.82 [914 x 1067 x 326]	EP3642	34.17 x 40.17 [868 x 1020]	PDF
EN4TD364812GY	\$1,184.00	EN4TD364812LG	\$1,243.00	36.00 x 48.00 x 12.82 [914 x 1219 x 326]	EP3648	34.17 x 46.17 [868 x 1173]	PDF
EN4TD366012GY	\$1,381.00	EN4TD366012LG	\$1,450.00	36.00 x 60.00 x 12.82 [914 x 1524 x 326]	EP3660	34.17 x 58.17 [868 x 1478]	PDF
EN4TD484812GY	\$1,490.00	EN4TD484812LG	\$1,568.00	48.00 x 48.00 x 12.82 [1219 x 1219 x 326]	EP3648	34.17 x 46.17 [868 x 1173]	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 12 Hinged Double-Door Wall-Mount with Handle



Dimensions

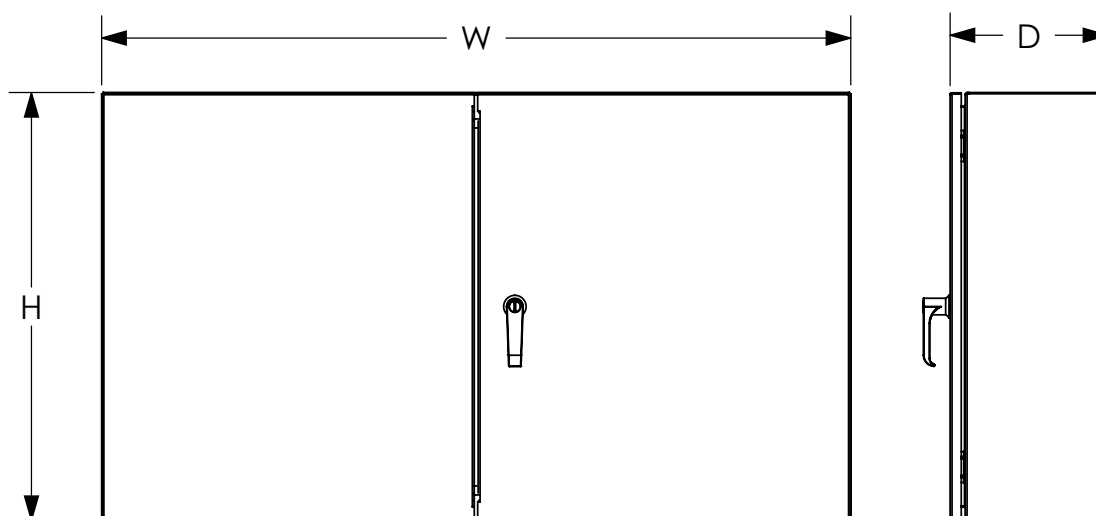

Enclosure Accessories

Locks and Latches



1/4-Turn Inserts and Keys

Features

- For Eclipse Series enclosures.
- Field installable inserts replace standard 1/4-turn slot.
- Available in square and triangle formats, as well as slotted.
- Maintains NEMA, UL and CSA 12, 4, and 4X ratings.
- Non-slot inserts provide extra security since standard screw drivers cannot open.
- Keys constructed from die-cast zinc.
- Keys sold separately from inserts.



1/4-Turn Inserts and Keys								
Latch Insert	Price	Type	Material	Finish	Drawing Link	Key	Price	Finish
2SQI7	\$18.00	square key	die-cast zinc	black matte	PDF	2SQK7	\$16.75	black matte
2TRI7	\$18.00	triangular key	die-cast zinc	black matte	PDF	2TRK7	\$16.75	natural
2SLI	\$18.00	slotted	die-cast zinc	black matte	PDF	—	—	—
2DBI3	\$18.00	3mm double-bit	die-cast zinc	black matte	PDF	PMKEY	\$16.50	black matte
2DBI3SS	\$45.00	3mm double-bit	stainless steel	natural	PDF	PMKEY	\$16.50	natural



1/4-Turn Latch Assemblies

Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on Eclipse or Eclipse Jr series.
- Maintains NEMA, UL, and CSA ratings of enclosures.
- Keylocking latch assemblies include two keys.



1/4-Turn Latch Assemblies							
Part Number	Price	Style	Security	Material	Finish	For Use With	Drawing Link
EQTRL	\$24.50	1/4-turn semi-flush	keylocking	die-cast zinc	chrome	Eclipse series swing-out panels	PDF
2QTR	\$18.25	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse series	PDF
2SSQTR	\$68.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse series	PDF
2WKL	\$99.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse series	PDF
2QPL	\$84.00	1/4-turn knob	padlocking	die-cast zinc	black matte	Eclipse series	PDF
EJQTR	\$15.00	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse Junior series	PDF
EJSSQTR	\$47.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse Junior series	PDF
EJWKL	\$46.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse Junior series	PDF
EJWKNL	\$46.00	1/4-turn wing handle	—	die-cast zinc	black matte	Eclipse Junior series	PDF