

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount



Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Impressive styling features like hidden hinges, attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14 (24 x 24 in [610 x 610 mm] and larger) or 16-gauge (24 x 20 in [610 x 508 mm] and smaller) steel.
- Smooth, continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity – designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latching: Type A has slotted 1/4-turns; Type B has handle with 3-point latching; Type C has handle with 3-point latching plus additional 1/4 turns top and bottom.
- Uses Eclipse 1/4 turn latches or handles.
- Doors may be easily removed for modifications and are interchangeable.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts, and sealing washers for wall-mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from 304 stainless steel.
- Hinge pins are 316 stainless steel.
- 1/4-turn latch and multi-point handle (key-lockable) are zinc diecast with black epoxy finish.
- Door alignment guide provided on 36 in [914 mm] wide enclosures.

Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG).

Listings

- UL 508A Type 3R, 4, and 12 [UL File E63524]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, and 12
 - IEC 60529, IP66



Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount

ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels			Drawing Link
						Painted	Galvanized	Size HxW	
EN4SD12106GY	\$248.00	EN4SD12106LG	\$260.00	12.00 x 10.00 x 6.82 [305 x 254 x 173]	A	EP1210	EPG1210	10.17 x 8.17 [258 x 208]	PDF
EN4SD12126GY	\$253.00	EN4SD12126LG	\$266.00	12.00 x 12.00 x 6.82 [305 x 305 x 173]		EP1212	EPG1212	10.17 x 10.17 [258 x 258]	PDF
EN4SD12246GY	\$259.00	EN4SD12246LG	\$272.00	12.00 x 24.00 x 6.82 [305 x 610 x 173]		EP1224	EPG1224	10.17 x 22.17 [258 x 563]	PDF
EN4SD12248GY	\$268.00	EN4SD12248LG	\$281.00	12.00 x 24.00 x 8.82 [305 x 610 x 224]		EP1224	EPG1224	10.17 x 22.17 [258 x 563]	PDF
EN4SD16126GY	\$271.00	EN4SD16126LG	\$284.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]		EP1612	EPG1612	14.17 x 10.17 [360 x 258]	PDF
EN4SD16128GY	\$284.00	EN4SD16128LG	\$297.00	16.00 x 12.00 x 8.82 [406 x 305 x 224]		EP1612	EPG1612	14.17 x 10.17 [360 x 258]	PDF
EN4SD161210GY	\$293.00	EN4SD161210LG	\$307.00	16.00 x 12.00 x 10.82 [406 x 305 x 275]		EP1612	EPG1612	14.17 x 10.17 [360 x 258]	PDF
EN4SD16166GY	\$291.00	EN4SD16166LG	\$305.00	16.00 x 16.00 x 6.82 [406 x 406 x 173]		EP1616	EPG1616	14.17 x 14.17 [360 x 360]	PDF
EN4SD16168GY	\$307.00	EN4SD16168LG	\$321.00	16.00 x 16.00 x 8.82 [406 x 406 x 224]		EP1616	EPG1616	14.17 x 14.17 [360 x 360]	PDF
EN4SD161610GY	\$313.00	EN4SD16206LG	\$327.00	16.00 x 16.00 x 10.82 [406 x 406 x 275]		EP1616	EPG1616	14.17 x 14.17 [360 x 360]	PDF
EN4SD16206GY	\$312.00	EN4SD16208LG	\$355.00	16.00 x 20.00 x 6.82 [406 x 508 x 173]		EP1620	EPG1620	14.17 x 18.17 [360 x 462]	PDF

Note: Dimensions in inches [millimeters].

Table continued on next page

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount



Table continued from previous
page

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount									
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels			Drawing Link
						Painted	Galvanized	Size HxW	
EN4SD16208GY	\$329.00	EN4SD161610LG	\$329.00	16.00 x 20.00 x 8.82 [406 x 508 x 224]	A	EP1620	EPG1620	14.17 x 18.17 [360 x 462]	PDF
EN4SD162010GY	\$336.00	EN4SD162010LG	\$353.00	16.00 x 20.00 x 10.82 [406 x 508 x 275]		EP1620	EPG1620	14.17 x 18.17 [360 x 462]	PDF
EN4SD20126GY	\$310.00	EN4SD20126LG	\$325.00	20.00 x 12.00 x 6.82 [508 x 305 x 173]		EP2012	EPG2012	18.17 x 10.17 [462 x 258]	PDF
EN4SD20128GY	\$315.00	EN4SD20128LG	\$330.00	20.00 x 12.00 x 8.82 [508 x 305 x 224]		EP2012	EPG2012	18.17 x 10.17 [462 x 258]	PDF
EN4SD20166GY	\$312.00	EN4SD20166LG	\$327.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]		EP2016	EPG2016	18.17 x 14.17 [462 x 360]	PDF
EN4SD20168GY	\$329.00	EN4SD20168LG	\$344.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]		EP2016	EPG2016	18.17 x 14.17 [462 x 360]	PDF
EN4SD201610GY	\$336.00	EN4SD201610LG	\$353.00	20.00 x 16.00 x 10.82 [508 x 406 x 275]		EP2016	EPG2016	18.17 x 14.17 [462 x 360]	PDF
EN4SD201612GY	\$410.00	EN4SD201612LG	\$430.00	20.00 x 16.00 x 12.82 [508 x 406 x 326]		EP2016	EPG2016	18.17 x 14.17 [462 x 360]	PDF
EN4SD20206GY	\$336.00	EN4SD20206LG	\$353.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]		EP2020	EPG2020	18.17 x 18.17 [462 x 462]	PDF
EN4SD20208GY	\$355.00	EN4SD20208LG	\$372.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]		EP2020	EPG2020	18.17 x 18.17 [462 x 462]	PDF
EN4SD202010GY	\$365.00	EN4SD202010LG	\$382.00	20.00 x 20.00 x 10.82 [508 x 508 x 275]		EP2020	EPG2020	18.17 x 18.17 [462 x 462]	PDF
EN4SD202012GY	\$405.00	EN4SD202012LG	\$424.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]		EP2020	EPG2020	18.17 x 18.17 [462 x 462]	PDF
EN4SD20246GY	\$380.00	EN4SD20246LG	\$398.00	20.00 x 24.00 x 6.82 [508 x 610 x 173]		EP2024	EPG2024	18.17 x 22.17 [462 x 563]	PDF
EN4SD20248GY	\$392.00	EN4SD20248LG	\$411.00	20.00 x 24.00 x 8.82 [508 x 610 x 224]		EP2024	EPG2024	18.17 x 22.17 [462 x 563]	PDF
EN4SD202410GY	\$391.00	EN4SD202410LG	\$410.00	20.00 x 24.00 x 10.82 [508 x 610 x 275]		EP2024	EPG2024	18.17 x 22.17 [462 x 563]	PDF
EN4SD24126GY	\$313.00	EN4SD24126LG	\$329.00	24.00 x 12.00 x 6.82 [610 x 305 x 173]		EP2412	EPG2412	22.17 x 10.17 [563 x 258]	PDF
EN4SD24128GY	\$338.00	EN4SD24128LG	\$354.00	24.00 x 12.00 x 8.82 [610 x 305 x 224]		EP2412	EPG2412	22.17 x 10.17 [563 x 258]	PDF
EN4SD241210GY	\$359.00	EN4SD241210LG	\$377.00	24.00 x 12.00 x 10.82 [610 x 305 x 275]		EP2412	EPG2412	22.17 x 10.17 [563 x 258]	PDF
EN4SD24166GY	\$342.00	EN4SD24166LG	\$358.00	24.00 x 16.00 x 6.82 [610 x 406 x 173]		EP2416	EPG2416	22.17 x 14.17 [563 x 360]	PDF
EN4SD24168GY	\$351.00	EN4SD24168LG	\$368.00	24.00 x 16.00 x 8.82 [610 x 406 x 224]		EP2416	EPG2416	22.17 x 14.17 [563 x 360]	PDF
EN4SD241610GY	\$360.00	EN4SD241610LG	\$378.00	24.00 x 16.00 x 10.82 [610 x 406 x 275]		EP2416	EPG2416	22.17 x 14.17 [563 x 360]	PDF
EN4SD24206GY	\$369.00	EN4SD24206LG	\$387.00	24.00 x 20.00 x 6.82 [610 x 508 x 173]		EP2420	EPG2420	22.17 x 18.17 [563 x 462]	PDF
EN4SD24208GY	\$381.00	EN4SD24208LG	\$400.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]		EP2420	EPG2420	22.17 x 18.17 [563 x 462]	PDF
EN4SD242010GY	\$391.00	EN4SD242010LG	\$410.00	24.00 x 20.00 x 10.82 [610 x 508 x 275]		EP2420	EPG2420	22.17 x 18.17 [563 x 462]	PDF
EN4SD242012GY	\$433.00	EN4SD242012LG	\$455.00	24.00 x 20.00 x 12.82 [610 x 508 x 326]		EP2420	EPG2420	22.17 x 18.17 [563 x 462]	PDF
EN4SD242016GY	\$475.00	EN4SD242016LG	\$499.00	24.00 x 20.00 x 16.82 [610 x 508 x 427]		EP2420	EPG2420	22.17 x 18.17 [563 x 462]	PDF
EN4SD24246GY	\$400.00	EN4SD24246LG	\$419.00	24.00 x 24.00 x 6.82 [610 x 610 x 173]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD24248GY	\$412.00	EN4SD24248LG	\$432.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD242410GY	\$424.00	EN4SD242410LG	\$444.00	24.00 x 24.00 x 10.82 [610 x 610 x 275]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD242412GY	\$457.00	EN4SD242412LG	\$480.00	24.00 x 24.00 x 12.82 [610 x 610 x 326]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD242416GY	\$516.00	EN4SD242416LG	\$541.00	24.00 x 24.00 x 16.82 [610 x 610 x 427]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD242420GY	\$561.00	EN4SD242420LG	\$588.00	24.00 x 24.00 x 20.82 [610 x 610 x 529]		EP2424	EPG2424	22.17 x 22.17 [563 x 563]	PDF
EN4SD24308GY	\$457.00	EN4SD24308LG	\$480.00	24.00 x 30.00 x 8.82 [610 x 762 x 224]		EP2430	EPG2430	22.17 x 28.17 [563 x 716]	PDF
EN4SD243010GY	\$467.00	EN4SD30128LG	\$430.00	24.00 x 30.00 x 10.82 [610 x 762 x 275]		EP2430	EPG2430	22.17 x 28.17 [563 x 716]	PDF
EN4SD243012GY	\$498.00	EN4SD243010LG	\$490.00	24.00 x 30.00 x 12.82 [610 x 762 x 326]		EP2430	EPG2430	22.17 x 28.17 [563 x 716]	PDF
EN4SD30128GY	\$410.00	EN4SD243012LG	\$522.00	30.00 x 12.00 x 8.82 [762 x 305 x 224]		EP3012	EPG3012	28.17 x 10.17 [716 x 258]	PDF
EN4SD30166GY	\$407.00	EN4SD30166LG	\$427.00	30.00 x 16.00 x 6.82 [762 x 406 x 173]		EP3016	EPG3016	28.17 x 14.17 [716 x 360]	PDF
EN4SD30168GY	\$413.00	EN4SD30168LG	\$433.00	30.00 x 16.00 x 8.82 [762 x 406 x 224]		EP3016	EPG3016	28.17 x 14.17 [716 x 360]	PDF
EN4SD30206GY	\$415.00	EN4SD302010LG	\$452.00	30.00 x 20.00 x 6.82 [762 x 508 x 173]		EP3020	EPG3020	28.17 x 18.17 [716 x 462]	PDF
EN4SD30208GY	\$432.00	EN4SD30206LG	\$435.00	30.00 x 20.00 x 8.82 [762 x 508 x 224]		EP3020	EPG3020	28.17 x 18.17 [716 x 462]	PDF
EN4SD302010GY	\$431.00	EN4SD30208LG	\$453.00	30.00 x 20.00 x 10.82 [762 x 508 x 275]		EP3020	EPG3020	28.17 x 18.17 [716 x 462]	PDF

Note: Dimensions in inches [millimeters].

Table continued on next page

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount



Table continued from previous page

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount									
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels			Drawing Link
						Painted	Galvanized	Size HxW	
EN4SD30246GY	\$433.00	EN4SD30246LG	\$454.00	30.00 x 24.00 x 6.82 [762 x 610 x 173]	A	EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD30248GY	\$457.00	EN4SD30248LG	\$480.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD302410GY	\$468.00	EN4SD302410LG	\$491.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD302412GY	\$506.00	EN4SD302412LG	\$531.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD302416GY	\$562.00	EN4SD302416LG	\$589.00	30.00 x 24.00 x 16.82 [762 x 610 x 427]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD302420GY	\$626.00	EN4SD302420LG	\$657.00	30.00 x 24.00 x 20.82 [762 x 610 x 529]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD302424GY	\$683.00	EN4SD302424LG	\$717.00	30.00 x 24.00 x 24.82 [762 x 610 x 630]		EP3024	EPG3024	28.17 x 22.17 [716 x 563]	PDF
EN4SD30308GY	\$509.00	EN4SD30308LG	\$534.00	30.00 x 30.00 x 8.82 [762 x 762 x 224]		EP3030	EPG3030	28.17 x 28.17 [716 x 716]	PDF
EN4SD303010GY	\$524.00	EN4SD303010LG	\$550.00	30.00 x 30.00 x 10.82 [762 x 762 x 275]		EP3030	EPG3030	28.17 x 28.17 [716 x 716]	PDF
EN4SD303012GY	\$565.00	EN4SD303012LG	\$593.00	30.00 x 30.00 x 12.82 [762 x 762 x 326]		EP3030	EPG3030	28.17 x 28.17 [716 x 716]	PDF
EN4SD30368GY	\$560.00	EN4SD30368LG	\$588.00	30.00 x 36.00 x 8.82 [762 x 914 x 224]		EP3036	EPG3036	28.17 x 34.17 [716 x 868]	PDF
EN4SD36246GY	\$501.00	EN4SD36246LG	\$526.00	36.00 x 24.00 x 6.82 [914 x 610 x 173]		EP3624	EPG3624	34.17 x 22.17 [868 x 563]	PDF
EN4SD36248GY	\$501.00	EN4SD36248LG	\$526.00	36.00 x 24.00 x 8.82 [914 x 610 x 224]		EP3624	EPG3624	34.17 x 22.17 [868 x 563]	PDF
EN4SD362410GY	\$516.00	EN4SD362410LG	\$541.00	36.00 x 24.00 x 10.82 [914 x 610 x 275]		EP3624	EPG3624	34.17 x 22.17 [868 x 563]	PDF
EN4SD362412GY	\$573.00	EN4SD362412LG	\$601.00	36.00 x 24.00 x 12.82 [914 x 610 x 326]		EP3624	EPG3624	34.17 x 22.17 [868 x 563]	PDF
EN4SD362416GY	\$634.00	EN4SD362416LG	\$666.00	36.00 x 24.00 x 16.82 [914 x 610 x 427]		EP3624	EPG3624	34.17 x 22.17 [868 x 563]	PDF
EN4SD36306GY	\$553.00	EN4SD36306LG	\$581.00	36.00 x 30.00 x 6.82 [914 x 762 x 173]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD36308GY	\$562.00	EN4SD36308LG	\$589.00	36.00 x 30.00 x 8.82 [914 x 762 x 224]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD363010GY	\$579.00	EN4SD363010LG	\$608.00	36.00 x 30.00 x 10.82 [914 x 762 x 275]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD363012GY	\$624.00	EN4SD363012LG	\$655.00	36.00 x 30.00 x 12.82 [914 x 762 x 326]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD363016GY	\$707.00	EN4SD363016LG	\$742.00	36.00 x 30.00 x 16.82 [914 x 762 x 427]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD363020GY	\$770.00	EN4SD363020LG	\$808.00	36.00 x 30.00 x 20.82 [914 x 762 x 529]		EP3630	EPG3630	34.17 x 28.17 [868 x 716]	PDF
EN4SD36368GY	\$624.00	EN4SD36368LG	\$655.00	36.00 x 36.00 x 8.82 [914 x 914 x 224]		EP3636	EPG3636	34.17 x 34.17 [868 x 868]	PDF
EN4SD363610GY	\$642.00	EN4SD363610LG	\$673.00	36.00 x 36.00 x 10.82 [914 x 914 x 275]		EP3636	EPG3636	34.17 x 34.17 [868 x 868]	PDF
EN4SD363612GY	\$712.00	EN4SD363612LG	\$747.00	36.00 x 36.00 x 12.82 [914 x 914 x 326]		EP3636	EPG3636	34.17 x 34.17 [868 x 868]	PDF
EN4SD363616GY	\$769.00	EN4SD363616LG	\$807.00	36.00 x 36.00 x 16.82 [914 x 914 x 427]		EP3636	EPG3636	34.17 x 34.17 [868 x 868]	PDF
EN4SD42248GY	\$636.00	EN4SD42248LG	\$667.00	42.00 x 24.00 x 8.82 [1067 x 610 x 224]	B	EP4224	EPG4224	40.17 x 22.17 [1020 x 563]	PDF
EN4SD422410GY	\$682.00	EN4SD422410LG	\$716.00	42.00 x 24.00 x 10.82 [1067 x 610 x 275]		EP4224	EPG4224	40.17 x 22.17 [1020 x 563]	PDF
EN4SD422412GY	\$732.00	EN4SD422412LG	\$769.00	42.00 x 24.00 x 12.84 [1067 x 610 x 326]		EP4224	EPG4224	40.17 x 22.17 [1020 x 563]	PDF
EN4SD422416GY	\$840.00	EN4SD422416LG	\$882.00	42.00 x 24.00 x 16.84 [1067 x 610 x 428]		EP4224	EPG4224	40.17 x 22.17 [1020 x 563]	PDF
EN4SD42308GY	\$695.00	EN4SD42308LG	\$729.00	42.00 x 30.00 x 8.82 [1067 x 762 x 224]		EP4230	EPG4230	40.17 x 28.17 [1020 x 716]	PDF
EN4SD423010GY	\$714.00	EN4SD423010LG	\$749.00	42.00 x 30.00 x 10.82 [1067 x 762 x 275]		EP4230	EPG4230	40.17 x 28.17 [1020 x 716]	PDF
EN4SD423012GY	\$793.00	EN4SD423012LG	\$832.00	42.00 x 30.00 x 12.82 [1067 x 762 x 326]		EP4230	EPG4230	40.17 x 28.17 [1020 x 716]	PDF
EN4SD423016GY	\$886.00	EN4SD423016LG	\$930.00	42.00 x 30.00 x 16.82 [1067 x 762 x 427]		EP4230	EPG4230	40.17 x 28.17 [1020 x 716]	PDF
EN4SD42368GY	\$711.00	EN4SD42368LG	\$747.00	42.00 x 36.00 x 8.82 [1067 x 914 x 224]		EP4236	EPG4236	40.17 x 34.17 [1020 x 868]	PDF
EN4SD423610GY	\$730.00	EN4SD423610LG	\$766.00	42.00 x 36.00 x 10.82 [1067 x 914 x 275]		EP4236	EPG4236	40.17 x 34.17 [1020 x 868]	PDF
EN4SD423612GY	\$830.00	EN4SD423612LG	\$871.00	42.00 x 36.00 x 12.82 [1067 x 914 x 326]		EP4236	EPG4236	40.17 x 34.17 [1020 x 868]	PDF

Note: Dimensions in inches [millimeters].

Table continued on next page

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount



Table continued from previous page


Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount									
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels			Drawing Link
						Painted	Galvanized	Size HxW	
EN4SD423616GY	\$878.00	EN4SD423616LG	\$922.00	42.00 x 36.00 x 16.82 [1067 x 914 x 427]	B	EP4236	EPG4236	40.17 x 34.17 [1020 x 868]	PDF
EN4SD48248GY	\$763.00	EN4SD48248LG	\$800.00	48.00 x 24.00 x 8.82 [1219 x 610 x 224]		EP4824	EPG4824	46.17 x 22.17 [1173 x 563]	PDF
EN4SD482410GY	\$772.00	EN4SD482410LG	\$811.00	48.00 x 24.00 x 10.82 [1219 x 610 x 275]		EP4824	EPG4824	46.17 x 22.17 [1173 x 563]	PDF
EN4SD482412GY	\$766.00	EN4SD482412LG	\$803.00	48.00 x 24.00 x 12.82 [1219 x 610 x 326]		EP4824	EPG4824	46.17 x 22.17 [1173 x 563]	PDF
EN4SD48308GY	\$772.00	EN4SD48308LG	\$810.00	48.00 x 30.00 x 8.82 [1219 x 762 x 224]		EP4830	EPG4830	46.17 x 28.17 [1173 x 716]	PDF
EN4SD483010GY	\$783.00	EN4SD483010LG	\$822.00	48.00 x 30.00 x 10.82 [1219 x 762 x 275]		EP4830	EPG4830	46.17 x 28.17 [1173 x 716]	PDF
EN4SD483016GY	\$913.00	EN4SD483016LG	\$958.00	48.00 x 30.00 x 16.82 [1219 x 762 x 427]		EP4830	EPG4830	46.17 x 28.17 [1173 x 716]	PDF
EN4SD48368GY	\$783.00	EN4SD48368LG	\$822.00	48.00 x 36.00 x 8.82 [1219 x 914 x 224]		EP4836	EPG4836	46.17 x 34.17 [1173 x 868]	PDF
EN4SD483610GY	\$795.00	EN4SD483610LG	\$835.00	48.00 x 36.00 x 10.82 [1219 x 914 x 275]		EP4836	EPG4836	46.17 x 34.17 [1173 x 868]	PDF
EN4SD483612GY	\$829.00	EN4SD483612LG	\$870.00	48.00 x 36.00 x 12.82 [1219 x 914 x 326]		EP4836	EPG4836	46.17 x 34.17 [1173 x 868]	PDF
EN4SD483616GY	\$909.00	EN4SD483616LG	\$954.00	48.00 x 36.00 x 16.82 [1219 x 914 x 427]		EP4836	EPG4836	46.17 x 34.17 [1173 x 868]	PDF
EN4SD483620GY	\$981.00	EN4SD483620LG	\$1,029.00	48.00 x 36.00 x 20.82 [1219 x 914 x 529]		EP4836	EPG4836	46.17 x 34.17 [1173 x 868]	PDF
EN4SD60368GY	\$886.00	EN4SD60368LG	\$930.00	60.00 x 36.00 x 8.82 [1524 x 914 x 224]		EP6036	EPG6036	58.17 x 34.17 [1478 x 868]	PDF
EN4SD603610GY	\$926.00	EN4SD603610LG	\$972.00	60.00 x 36.00 x 10.82 [1524 x 914 x 275]		EP6036	EPG6036	58.17 x 34.17 [1478 x 868]	PDF
EN4SD603612GY	\$965.00	EN4SD603612LG	\$1,014.00	60.00 x 36.00 x 12.82 [1524 x 914 x 326]		EP6036	EPG6036	58.17 x 34.17 [1478 x 868]	PDF
EN4SD603616GY	\$1,052.00	EN4SD603616LG	\$1,103.00	60.00 x 36.00 x 16.82 [1524 x 914 x 427]		EP6036	EPG6036	58.17 x 34.17 [1478 x 868]	PDF
EN4SD603620GY	\$1,180.00	EN4SD603620LG	\$1,239.00	60.00 x 36.00 x 20.82 [1524 x 914 x 529]		EP6036	EPG6036	58.17 x 34.17 [1478 x 868]	PDF
EN4SD723012GY	\$1,001.00	EN4SD723012LG	\$1,052.00	72.00 x 30.00 x 12.82 [1829 x 762 x 326]	C	EP7230	EPG7230	70.17 x 28.17 [1782 x 716]	PDF
EN4SD723016GY	\$1,099.00	EN4SD723016LG	\$1,155.00	72.00 x 30.00 x 16.82 [1829 x 762 x 427]		EP7230	EPG7230	70.17 x 28.17 [1782 x 716]	PDF
EN4SD723024GY	\$1,294.00	EN4SD723020LG	\$1,274.00	72.00 x 30.00 x 24.82 [1829 x 762 x 630]		EP7230	EPG7230	70.17 x 28.17 [1782 x 716]	PDF
EN4SD723612GY	\$1,104.00	EN4SD723024LG	\$1,360.00	72.00 x 36.00 x 12.82 [1829 x 914 x 326]		EP7236	EPG7236	70.17 x 34.17 [1782 x 868]	PDF
EN4SD723020GY	\$1,212.00	EN4SD723612LG	\$1,161.00	72.00 x 30.00 x 20.82 [1829 x 762 x 529]		EP7230	EPG7230	70.17 x 28.17 [1782 x 716]	PDF
EN4SD723616GY	\$1,186.00	EN4SD723616LG	\$1,247.00	72.00 x 36.00 x 16.82 [1829 x 914 x 427]		EP7236	EPG7236	70.17 x 34.17 [1782 x 868]	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, and 12 Single-Door Wall-Mount



Dimensions

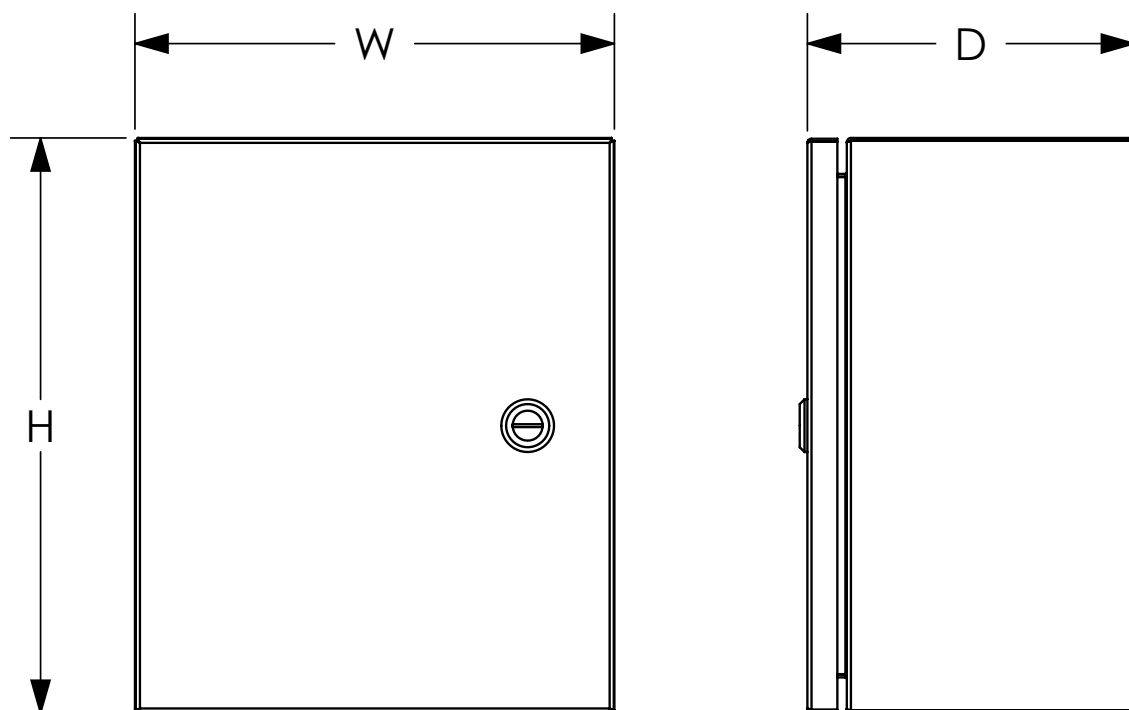

Enclosure Accessories

Locks and Latches



1/4-Turn Inserts and Keys

Features

- For Eclipse Series enclosures.
- Field installable inserts replace standard 1/4-turn slot.
- Available in square and triangle formats, as well as slotted.
- Maintains NEMA, UL and CSA 12, 4, and 4X ratings.
- Non-slot inserts provide extra security since standard screw drivers cannot open.
- Keys constructed from die-cast zinc.
- Keys sold separately from inserts.



1/4-Turn Inserts and Keys								
Latch Insert	Price	Type	Material	Finish	Drawing Link	Key	Price	Finish
2SQI7	\$18.00	square key	die-cast zinc	black matte	PDF	2SQK7	\$16.75	black matte
2TRI7	\$18.00	triangular key	die-cast zinc	black matte	PDF	2TRK7	\$16.75	natural
2SLI	\$18.00	slotted	die-cast zinc	black matte	PDF	—	—	—
2DBI3	\$18.00	3mm double-bit	die-cast zinc	black matte	PDF	PMKEY	\$16.50	black matte
2DBI3SS	\$45.00	3mm double-bit	stainless steel	natural	PDF	PMKEY	\$16.50	natural



1/4-Turn Latch Assemblies

Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on Eclipse or Eclipse Jr series.
- Maintains NEMA, UL, and CSA ratings of enclosures.
- Keylocking latch assemblies include two keys.



1/4-Turn Latch Assemblies							
Part Number	Price	Style	Security	Material	Finish	For Use With	Drawing Link
EQTRL	\$24.50	1/4-turn semi-flush	keylocking	die-cast zinc	chrome	Eclipse series swing-out panels	PDF
2QTR	\$18.25	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse series	PDF
2SSQTR	\$68.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse series	PDF
2WKL	\$99.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse series	PDF
2QPL	\$84.00	1/4-turn knob	padlocking	die-cast zinc	black matte	Eclipse series	PDF
EJQTR	\$15.00	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse Junior series	PDF
EJSSQTR	\$47.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse Junior series	PDF
EJWKL	\$46.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse Junior series	PDF
EJWKNL	\$46.00	1/4-turn wing handle	—	die-cast zinc	black matte	Eclipse Junior series	PDF

Enclosure Accessories

Locks and Latches

Eclipse Series 1-Point 1/4-Turn Handles



T-Handle



L-Handle

Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on all Eclipse series enclosures.
- Keylocking latch assemblies include two keys.
- Maintain NEMA, UL and CSA ratings of enclosure.

Eclipse Series 1-Point 1/4-Turn Handles						
Part Number	Price	Style	Security	Material	Finish	Drawing Link
<u>EHTL</u>	\$68.00	1/4-turn tee handle	keylocking	die-cast zinc	black matte	<u>PDF</u>
<u>EHLL</u>	\$69.00	1/4-turn L-handle	keylocking	die-cast zinc	black matte	<u>PDF</u>
<u>EHLNL</u>	\$69.00	1/4-turn L-handle	—	die-cast zinc	black matte	<u>PDF</u>
<u>EHLPL</u>	\$127.00	1/4-turn L-handle	padlocking	zinc plated steel	—	<u>PDF</u>
<u>EHLSS</u>	\$310.00	1/4-turn L-handle	keylocking	316 stainless steel	—	<u>PDF</u>
<u>EHLNLSS</u>	\$310.00	1/4-turn L-handle	—	316 stainless steel	—	<u>PDF</u>
<u>EHLPLSS</u>	\$310.00	1/4-turn L-handle	padlocking	316 stainless steel	—	<u>PDF</u>