


Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Two-Door Wall-Mount with 3-Point Handle

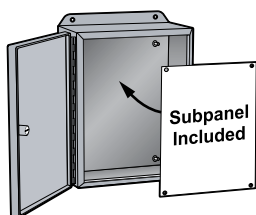

Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

Construction

- Formed 12-gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Doors are supported with heavy gauge continuous hinges.
- 3-point padlocking door handle.
- Uses 1/4 turn latch handles.
- Seamless poured-in-place gasket.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.
- Center post is removable for easy installation of the subpanel.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Two-Door Wall-Mount with 3-Point Handle


304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Subpanel HxW	Drawing Link
HN4WM24428SS	\$3,317.00	HN4WM24428S16	\$3,964.00	24.00 x 42.00 x 9.09 [610 x 1067 x 231]	39.00 x 21.00 [991 x 533]	PDF
HN4WM24488SS	\$3,579.00	HN4WM24488S16	\$4,275.00	24.00 x 48.00 x 9.09 [610 x 1219 x 231]	45.00 x 21.00 [1143 x 533]	PDF
HN4WM304210SS	\$3,890.00	HN4WM304210S16	\$4,655.00	30.00 x 42.00 x 11.09 [762 x 1067 x 282]	39.00 x 27.00 [991 x 686]	PDF
HN4WM304810SS	\$4,191.00	HN4WM304810S16	\$5,016.00	30.00 x 48.00 x 11.09 [762 x 1219 x 282]	45.00 x 27.00 [1143 x 686]	PDF
HN4WM306010SS	\$4,778.00	HN4WM306010S16	\$5,724.00	30.00 x 60.00 x 11.09 [762 x 1524 x 282]	—	PDF
HN4WM364212SS	\$4,506.00	HN4WM364212S16	\$5,394.00	36.00 x 42.00 x 13.09 [914 x 1067 x 332]	39.00 x 33.00 [991 x 838]	PDF
HN4WM366012SS	\$5,605.00	HN4WM364812S16	\$5,862.00	36.00 x 60.00 x 13.09 [914 x 1524 x 332]	45.00 x 33.00 [1143 x 838]	PDF
HN4WM364812SS	\$4,895.00	HN4WM366012S16	\$6,713.00	36.00 x 48.00 x 13.09 [914 x 1219 x 332]	57.00 x 33.00 [1448 x 838]	PDF
HN4WM424212SS	\$4,961.00	HN4WM424212S16	\$5,941.00	42.00 x 42.00 x 13.09 [1067 x 1067 x 332]	—	PDF
HN4WM424812SS	\$5,370.00	HN4WM424812S16	\$6,430.00	42.00 x 48.00 x 13.09 [1067 x 1219 x 332]	—	PDF
HN4WM426012SS	\$6,164.00	HN4WM426012S16	\$7,379.00	42.00 x 60.00 x 13.09 [1067 x 1524 x 332]	—	PDF
HN4WM484812SS	\$5,868.00	HN4WM484812S16	\$7,028.00	48.00 x 48.00 x 13.09 [1219 x 1219 x 332]	—	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Two-Door Wall-Mount with 3-Point Handle



Dimensions

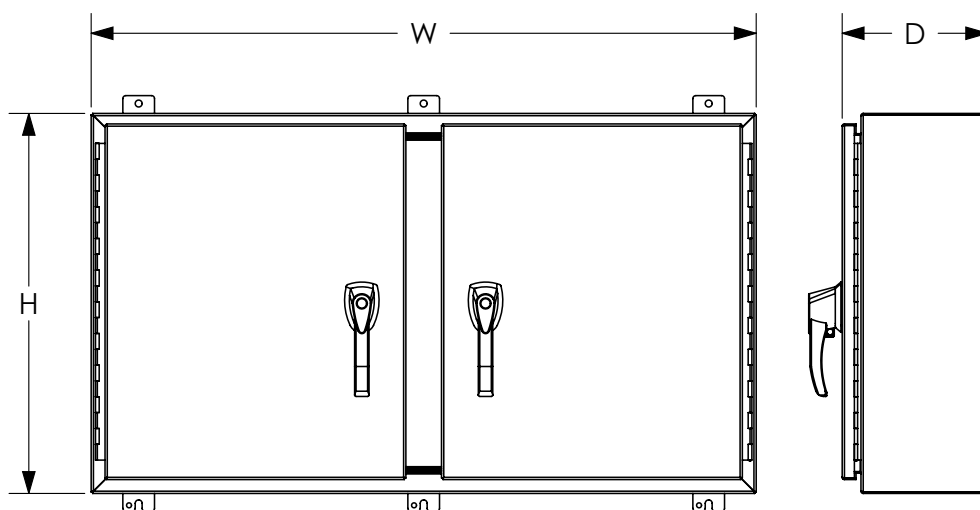

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF