


Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Single Door Wall-Mount with 3-Point Handle

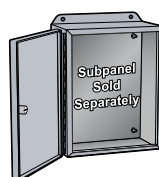

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14-gauge 304 stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity—designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Doors are secured with a padlocking 316 stainless steel 3-point handle.
- Uses 1/4 turn latch handles.
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- 316 stainless steel hinge pins and hinges.

Finish

- Cover and enclosure are finished in recoatable smooth RAL9003 white powder coating inside and out.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Single-Door Wall-Mount with 3-Point Handle


304 Stainless Steel	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
			Painted	Galvanized	
EN4SD242010SSWH	\$1,448.00	24.00 x 20.00 x 10.84 [610 x 508 x 275]	EP2420	EPG2420	PDF
EN4SD24248SSWH	\$1,270.00	24.00 x 24.00 x 8.84 [610 x 610 x 225]	EP2424	EPG2424	PDF
EN4SD242412SSWH	\$1,690.00	24.00 x 24.00 x 12.84 [610 x 610 x 326]	EP2424	EPG2424	PDF
EN4SD30248SSWH	\$1,690.00	30.00 x 24.00 x 8.84 [762 x 610 x 225]	EP3024	EPG3024	PDF
EN4SD363012SSWH	\$2,442.00	36.00 x 30.00 x 12.84 [914 x 762 x 326]	EP3630	EPG3630	PDF
EN4SD363612SSWH	\$2,743.00	36.00 x 36.00 x 12.84 [914 x 914 x 326]	EP3636	EPG3636	PDF
EN4SD423612SSWH	\$3,040.00	42.00 x 36.00 x 12.84 [1067 x 914 x 326]	EP4236	EPG4236	PDF
EN4SD483612SSWH	\$3,341.00	48.00 x 36.00 x 12.84 [1219 x 914 x 326]	EP4836	EPG4836	PDF
EN4SD483616SSWH	\$3,691.00	48.00 x 36.00 x 16.84 [1219 x 914 x 428]	EP4836	EPG4836	PDF
EN4SD603612SSWH	\$3,942.00	60.00 x 36.00 x 12.84 [1524 x 914 x 326]	EP6036	EPG6036	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Painted Stainless Steel Single Door Wall-Mount with 3-Point Handle



Dimensions

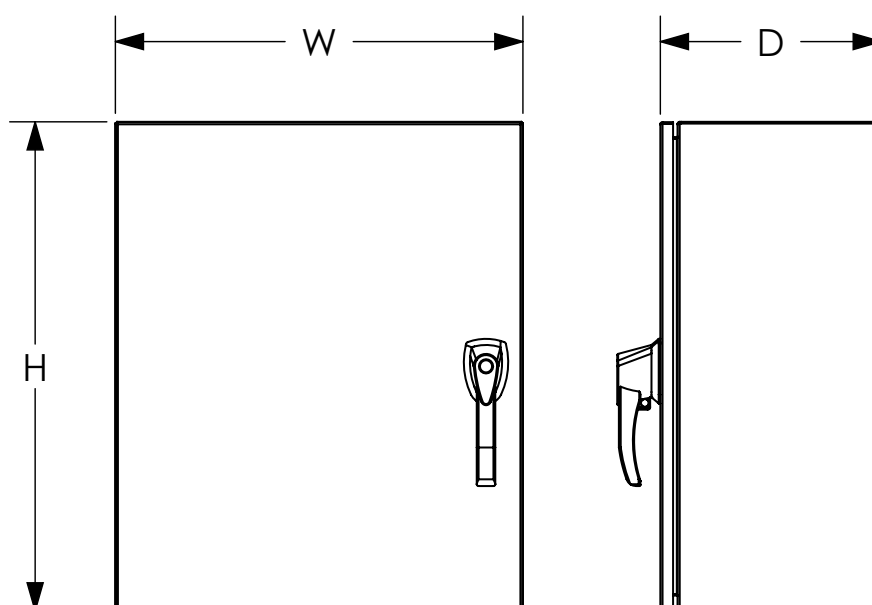

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF