

NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway



Features

- Designed to enclose and protect electrical wiring from dirt, dust, oil, and water.
- Ideal for connecting machines to control panels or power sources.



Construction

- Bodies and covers are formed from 14-gauge 304 steel with 10-gauge steel flanges.
- Continuous flange around wireway ends requires cables to be pulled through.
- Smooth continuously welded seams
- Interior surfaces are smooth to prevent wire damage during installation.
- Butt-hinged cover is secured with easily operated screw clamps.
- Solid, oil-resistant gaskets are permanently secured between flanges when sections and fittings are bolted together.
- One gasket kit, complete with hardware is provided with each straight section or fitting.
- Sections and fittings are natural stainless steel with a smooth brushed finish.

Listings

- UL 870 Type 1 (unless marked) [File E186830]
- CSA Type 1 (unless marked) [File LL21312]
- Complies with
 - NEMA Type 4, 4X, and 12
 - IEC 60529, IP66



NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway


Part Number	Price	Size HxW	Drawing Link
1487C12SS	\$357.00	4.00 x 4.00 x 12.00 [102 x 102 x 305]	PDF
1487C24SS	\$441.00	4.00 x 4.00 x 24.00 [102 x 102 x 610]	PDF
1487C36SS	\$536.00	4.00 x 4.00 x 36.00 [102 x 102 x 914]	PDF
1487C48SS	\$632.00	4.00 x 4.00 x 48.00 [102 x 102 x 1219]	PDF
1487C60SS	\$728.00	4.00 x 4.00 x 60.00 [102 x 102 x 1524]	PDF
1487C120SS	\$1,209.00	4.00 x 4.00 x 120.00 [102 x 102 x 3048]	PDF
1487D12SS	\$453.00	6.00 x 6.00 x 12.00 [152 x 152 x 305]	PDF
1487D24SS	\$592.00	6.00 x 6.00 x 24.00 [152 x 152 x 610]	PDF
1487D36SS	\$743.00	6.00 x 6.00 x 36.00 [152 x 152 x 914]	PDF
1487D48SS	\$896.00	6.00 x 6.00 x 48.00 [152 x 152 x 1219]	PDF
1487D60SS	\$1,048.00	6.00 x 6.00 x 60.00 [152 x 152 x 1524]	PDF
1487D120SS	\$1,810.00	6.00 x 6.00 x 120.00 [152 x 152 x 3048]	PDF
1487E12SS	\$499.00	8.00 x 8.00 x 12.00 [203 x 203 x 305]	PDF
1487E24SS	\$652.00	8.00 x 8.00 x 24.00 [203 x 203 x 610]	PDF
1487E36SS	\$821.00	8.00 x 8.00 x 36.00 [203 x 203 x 914]	PDF
1487E48SS	\$988.00	8.00 x 8.00 x 48.00 [203 x 203 x 1219]	PDF
1487E60SS	\$1,155.00	8.00 x 8.00 x 60.00 [203 x 203 x 1524]	PDF
1487E120SS	\$2,000.00	8.00 x 8.00 x 120.00 [203 x 203 x 3048]	PDF

Note: Dimensions in inches [millimeters].

NEMA 4, 4X, and 12 304 Stainless Steel Pull-Through Wireway Hangers



Drop Hangers			
Part Number	Price	Wireway Size	Drawing Link
<u>1487CL1SS</u>	\$71.00	4.00 x 4.00 [102 x 102]	<u>PDF</u>
<u>1487DL1SS</u>	\$98.00	6.00 x 6.00 [152 x 152]	<u>PDF</u>
<u>1487EL1SS</u>	\$105.00	8.00 x 8.00 [203 x 203]	<u>PDF</u>
Note: Dimensions in inches [millimeters].			

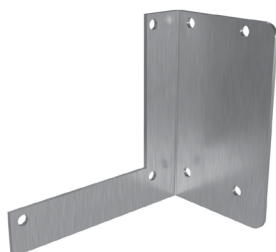

Bracket Hangers			
Part Number	Price	Wireway Size	Drawing Link
<u>1487CL2SS</u>	\$45.50	4.00 x 4.00 [102 x 102]	<u>PDF</u>
<u>1487DL2SS</u>	\$64.00	6.00 x 6.00 [152 x 152]	<u>PDF</u>
<u>1487EL2SS</u>	\$71.00	8.00 x 8.00 [203 x 203]	<u>PDF</u>
Note: Dimensions in inches [millimeters].			

NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway Fittings




Features

- Made of Carbon Steel painted ANSI 61 Gray
- Divides Wireway into two or more compartments
- Barriers are fastened to wireway sections with screws.
- Does not meet CSA or UL requirements


Partition Kit			
Part Number	Price	Wireway Size	Drawing Link
1487CB60	\$56.00	4.00 x 4.00 x 60.00 [102 x 102 x 1524]	PDF
1487DB60	\$69.00	6.00 x 6.00 x 60.00 [152 x 152 x 1524]	PDF
1487EB60	\$93.00	8.00 x 8.00 x 60.00 [203 x 203 x 1524]	PDF
Note: Dimensions in inches [millimeters].			



Nipple			
Part Number	Price	Overall Size HxWxD	Drawing Link
1487CM6SS	\$245.00	4.00 x 4.00 x 6.00 [102 x 102 x 152]	PDF
1487DM6SS	\$313.00	6.00 x 6.00 x 6.00 [152 x 152 x 152]	PDF
1487EM6SS	\$344.00	8.00 x 8.00 x 6.00 [203 x 203 x 152]	PDF
Note: Dimensions in inches [millimeters].			

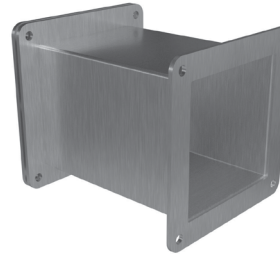

Swivel Nipple			
Part Number	Price	Size HxWxD	Drawing Link
1487CV2SS	\$359.00	4.00 x 4.00 x 2.25 [102 x 102 x 57]	PDF
1487DV2SS	\$476.00	6.00 x 6.00 x 2.25 [152 x 152 x 57]	PDF
1487EV2SS	\$526.00	8.00 x 8.00 x 2.25 [203 x 203 x 57]	PDF
Note: Dimensions in inches [millimeters].			

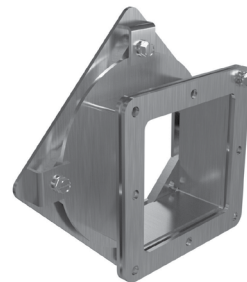

Features

- Allows for easy alignment of sections or fittings
- Metal flanges
- Flexible "bellows" middle section

Flexible Fitting			
Part Number	Price	Overall Size HxWxD	Drawing Link
1487CFFSS	\$570.00	4.00 x 4.00 [102 x 102]	PDF
1487DFFSS	\$717.00	6.00 x 6.00 [152 x 152]	PDF
1487EFFSS	\$792.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			




NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway Fittings




Features

- Allows on-site length adjustment of 1.5in [38 mm] to 13.5 in [343mm]
- Does not meet CSA or UL requirements


Adjustable Fitting			
Part Number	Price	Wireway Size	Drawing Link
1487CXSS	\$363.00	4.00 x 4.00 [102 x 102]	PDF
1487DXSS	\$442.00	6.00 x 6.00 [152 x 152]	PDF
1487EXSS	\$489.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			

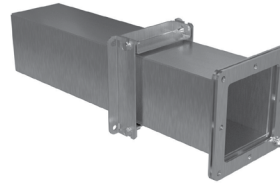


45° Elbow			
Part Number	Price	Wireway Size	Drawing Link
1487C4PSS	\$334.00	4.00 x 4.00 [102 x 102]	PDF
1487D4PSS	\$412.00	6.00 x 6.00 [152 x 152]	PDF
1487E4PSS	\$453.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			

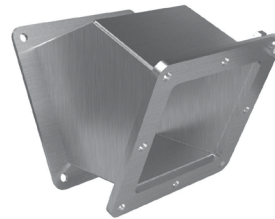

90° Elbow			
Part Number	Price	Wireway Size	Drawing Link
1487C9PSS	\$326.00	4.00 x 4.00 [102 x 102]	PDF
1487D9PSS	\$400.00	6.00 x 6.00 [152 x 152]	PDF
1487E9PSS	\$440.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			

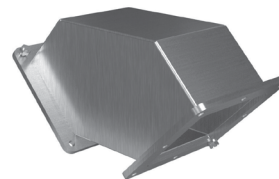

Tee Fitting			
Part Number	Price	Wireway Size	Drawing Link
1487CTSS	\$390.00	4.00 x 4.00 [102 x 102]	PDF
1487DTSS	\$556.00	6.00 x 6.00 [152 x 152]	PDF
1487ETSS	\$611.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			

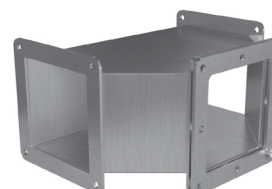

NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway Fittings



Box Connector			
Part Number	Price	Wireway Size	Drawing Link
1487CKSS	\$69.00	4.00 x 4.00 [102 x 102]	PDF
1487DKSS	\$88.00	6.00 x 6.00 [152 x 152]	PDF
1487EKSS	\$95.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			




Cover Plate			
Part Number	Price	Wireway Size	Drawing Link
1487CHSS	\$63.00	4.00 x 4.00 [102 x 102]	PDF
1487DHSS	\$76.00	6.00 x 6.00 [152 x 152]	PDF
1487EHSS	\$84.00	8.00 x 8.00 [203 x 203]	PDF
Note: Dimensions in inches [millimeters].			



NEMA 4, 4X, and 12 Stainless Steel Pull-Through Wireway Fittings and Accessories



Center Hole Reducers			
Part Number	Price	Wireway Size	Drawing Link
1487DRCSS	\$157.00	6 x 6 to 4 x 4 [152 x 152 to 102 x 102]	PDF
1487ERCCSS	\$172.00	8 x 8 to 4 x 4 [203 x 203 to 102 x 102]	PDF
1487ERCDS	\$172.00	8 x 8 to 6 x 6 [203 x 203 to 152 x 152]	PDF
Note: Dimensions in inches [millimeters].			

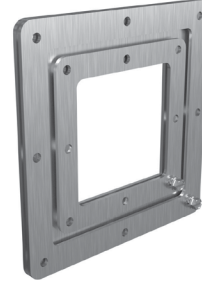

Edge Hole Wireway Reducers			
Part Number	Price	Wireway Size	Drawing Link
1487ERECSS	\$172.00	8 x 8 to 4 x 4 [203 x 203 to 102 x 102]	PDF
1487EREDSS	\$172.00	8 x 8 to 6 x 6 [203 x 203 to 152 x 152]	PDF
1487DRESS	\$157.00	6 x 6 to 4 x 4 [152 x 152 to 102 x 102]	PDF
Note: Dimensions in inches [millimeters].			



Gaskets and Screws			
Part Number	Price	Wireway Size	Drawing Link
1487CSSS	\$18.25	4.00 x 4.00 [102 x 102]	PDF
1487DSSS	\$24.00	6.00 x 6.00 [152 x 152]	PDF
1487ESSS	\$26.50	8.00 x 8.00 [203 x 203]	PDF
Notes: Does not meet CSA or UL requirements. Dimensions in inches [millimeters].			

