

# Aluminum Panels for 19-Inch Racks



## Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

## Features


- Fits standard EIA compliant rails.

## Construction

- Constructed of 8-gauge (0.125 in [3mm]) 5052-H32 aluminum.
- Finished in smooth powder coat paint or unfinished.

## Listings

- TAA compliant for GSA Schedule purchases.
- RoHS

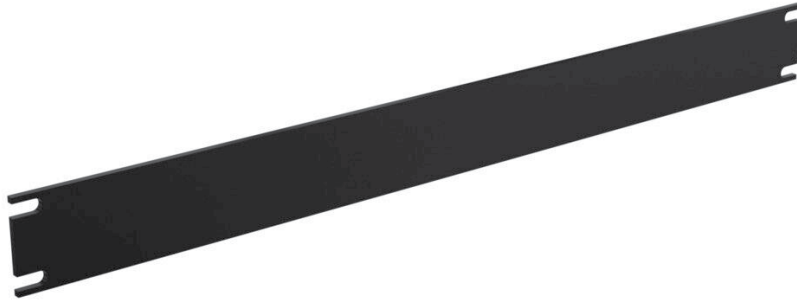

### Aluminum Panels for 19-Inch Racks

<i>Gloss Black</i>	<i>Matte Black</i>	<i>RAL7035 Gray</i>	<i>ANSI 61 Gray</i>	<i>Unfinished</i>	<i>Price</i>	<i>Rack Units</i>	<i>Panel Height</i>	<i>Drawing Link</i>
<a href="#">PBPA19001BK2</a>	<a href="#">PBPA19001BK</a>	<a href="#">PBPA19001LG2</a>	<a href="#">PBPA19001GY2</a>	<a href="#">PBPA19001UNF</a>	\$11.50	1U	1.75 [44]	<a href="#">PDF</a>
<a href="#">PBPA19003BK2</a>	<a href="#">PBPA19003BK</a>	<a href="#">PBPA19003LG2</a>	<a href="#">PBPA19003GY2</a>	<a href="#">PBPA19003UNF</a>	\$17.00	2U	3.50 [89]	<a href="#">PDF</a>
<a href="#">PBPA19005BK2</a>	<a href="#">PBPA19005BK</a>	<a href="#">PBPA19005LG2</a>	<a href="#">PBPA19005GY2</a>	<a href="#">PBPA19005UNF</a>	\$25.50	3U	5.25 [133]	<a href="#">PDF</a>
<a href="#">PBPA19007BK2</a>	<a href="#">PBPA19007BK</a>	<a href="#">PBPA19007LG2</a>	<a href="#">PBPA19007GY2</a>	<a href="#">PBPA19007UNF</a>	\$30.00	4U	7.00 [178]	<a href="#">PDF</a>
<a href="#">PBPA19008BK2</a>	—	<a href="#">PBPA19008LG2</a>	<a href="#">PBPA19008GY2</a>	<a href="#">PBPA19008UNF</a>	\$35.50	5U	8.75 [222]	<a href="#">PDF</a>
<a href="#">PBPA19010BK2</a>	—	<a href="#">PBPA19010LG2</a>	<a href="#">PBPA19010GY2</a>	<a href="#">PBPA19010UNF</a>	\$41.50	6U	10.50 [267]	<a href="#">PDF</a>
<a href="#">PBPA19012BK2</a>	—	<a href="#">PBPA19012LG2</a>	<a href="#">PBPA19012GY2</a>	<a href="#">PBPA19012UNF</a>	\$50.00	7U	12.25 [311]	<a href="#">PDF</a>
<a href="#">PBPA19014BK2</a>	—	<a href="#">PBPA19014LG2</a>	<a href="#">PBPA19014GY2</a>	<a href="#">PBPA19014UNF</a>	\$56.00	8U	14.00 [356]	<a href="#">PDF</a>
<a href="#">PBPA19015BK2</a>	—	<a href="#">PBPA19015LG2</a>	<a href="#">PBPA19015GY2</a>	<a href="#">PBPA19015UNF</a>	\$61.00	9U	15.75 [400]	<a href="#">PDF</a>
<a href="#">PBPA19017BK2</a>	—	<a href="#">PBPA19017LG2</a>	<a href="#">PBPA19017GY2</a>	<a href="#">PBPA19017UNF</a>	\$68.00	10U	17.50 [445]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].