

Flanged Steel Panels for 19-Inch Racks



Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

Features

- Fits standard EIA compliant rails.

Construction

- Constructed of 16-gauge steel.
- Finished in smooth powder coat.

Listings

- TAA compliant for GSA Schedule purchases.
- RoHS



Flanged Steel Panels for 19-Inch Racks

<i>Gloss Black</i>	<i>Matte Black</i>	<i>RAL7035 Gray</i>	<i>ANSI 61 Gray</i>	<i>Price</i>	<i>Rack Units</i>	<i>Panel Height</i>	<i>Drawing Link</i>
<u>PBFS19000BK2</u>	<u>PBFS19000BK</u>	—	—	\$9.25	1/2U	0.90 [23]	<u>PDF</u>
<u>PBFS19001BK2</u>	<u>PBFS19001BK</u>	<u>PBFS19001LG2</u>	<u>PBFS19001GY2</u>	\$12.50	1U	1.75 [44]	<u>PDF</u>
<u>PBFS19003BK2</u>	<u>PBFS19003BK</u>	<u>PBFS19003LG2</u>	<u>PBFS19003GY2</u>	\$17.50	2U	3.50 [89]	<u>PDF</u>
<u>PBFS19005BK2</u>	<u>PBFS19005BK</u>	<u>PBFS19005LG2</u>	<u>PBFS19005GY2</u>	\$19.25	3U	5.25 [133]	<u>PDF</u>
<u>PBFS19007BK2</u>	<u>PBFS19007BK</u>	<u>PBFS19007LG2</u>	<u>PBFS19007GY2</u>	\$24.00	4U	7.00 [178]	<u>PDF</u>
<u>PBFS19008BK2</u>	—	<u>PBFS19008LG2</u>	<u>PBFS19008GY2</u>	\$30.00	5U	8.75 [222]	<u>PDF</u>
<u>PBFS19010BK2</u>	—	<u>PBFS19010LG2</u>	<u>PBFS19010GY2</u>	\$33.50	6U	10.50 [267]	<u>PDF</u>
<u>PBFS19012BK2</u>	—	<u>PBFS19012LG2</u>	<u>PBFS19012GY2</u>	\$35.00	7U	12.25 [311]	<u>PDF</u>
<u>PBFS19014BK2</u>	—	<u>PBFS19014LG2</u>	<u>PBFS19014GY2</u>	\$38.50	8U	14.00 [356]	<u>PDF</u>
<u>PBFS19015BK2</u>	—	<u>PBFS19015LG2</u>	<u>PBFS19015GY2</u>	\$40.00	9U	15.75 [400]	<u>PDF</u>
<u>PBFS19017BK2</u>	—	<u>PBFS19017LG2</u>	<u>PBFS19017GY2</u>	\$46.50	10U	17.50 [445]	<u>PDF</u>

Note: Dimensions in inches [millimeters].

Flat Steel Panels for 19-Inch Racks


**HAMMOND
MANUFACTURING®**

Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

Features


- Fits standard EIA compliant rails.

Construction

- Constructed of 14-gauge steel.
- Finished in smooth powder coat.

Listings

- TAA compliant for GSA Schedule purchases.
- RoHS

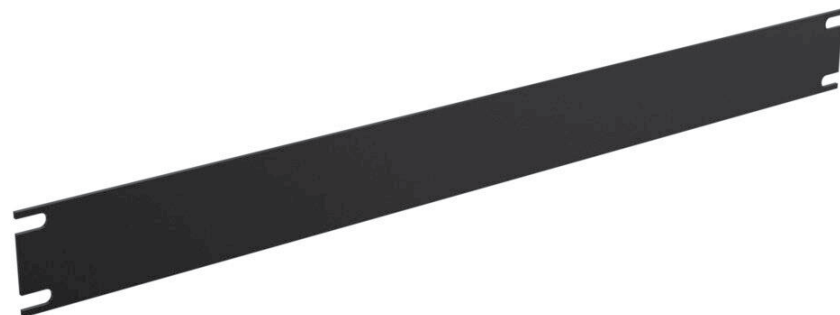

Flat Steel Panels for 19-Inch Racks							
<i>Gloss Black</i>	<i>Matte Black</i>	<i>RAL7035 Gray</i>	<i>ANSI 61 Gray</i>	<i>Price</i>	<i>Rack Units</i>	<i>Panel Height</i>	<i>Drawing Link</i>
<u>PBPS19001BK2</u>	<u>PBPS19001BK</u>	<u>PBPS19001LG2</u>	<u>PBPS19001GY2</u>	\$10.00	1U	1.75 [44]	<u>PDF</u>
<u>PBPS19003BK2</u>	<u>PBPS19003BK</u>	<u>PBPS19003LG2</u>	<u>PBPS19003GY2</u>	\$11.75	2U	3.50 [89]	<u>PDF</u>
<u>PBPS19005BK2</u>	<u>PBPS19005BK</u>	<u>PBPS19005LG2</u>	<u>PBPS19005GY2</u>	\$16.75	3U	5.25 [133]	<u>PDF</u>
<u>PBPS19007BK2</u>	<u>PBPS19007BK</u>	<u>PBPS19007LG2</u>	<u>PBPS19007GY2</u>	\$20.00	4U	7.00 [178]	<u>PDF</u>
<u>PBPS19008BK2</u>	—	<u>PBPS19008LG2</u>	<u>PBPS19008GY2</u>	\$22.50	5U	8.75 [222]	<u>PDF</u>
<u>PBPS19010BK2</u>	—	<u>PBPS19010LG2</u>	<u>PBPS19010GY2</u>	\$25.00	6U	10.50 [267]	<u>PDF</u>
<u>PBPS19012BK2</u>	—	<u>PBPS19012LG2</u>	<u>PBPS19012GY2</u>	\$30.00	7U	12.25 [311]	<u>PDF</u>
<u>PBPS19014BK2</u>	—	<u>PBPS19014LG2</u>	—	\$38.50	8U	14.00 [356]	<u>PDF</u>
<u>PBPS19015BK2</u>	—	<u>PBPS19015LG2</u>	—	\$42.50	9U	15.75 [400]	<u>PDF</u>
<u>PBPS19017BK2</u>	—	<u>PBPS19017LG2</u>	—	\$46.50	10U	17.50 [445]	<u>PDF</u>

Note: Dimensions in inches [millimeters].