

# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window




## Applications

- Designed to enclose electrical and/or electronic equipment in wall-mount applications where viewing of component operation is necessary while maintaining protection ratings.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

## Construction

- Formed 14-gauge (24 x 24 in [610 x 610 mm] and larger) or 16-gauge (24 x 20 in [508 mm] [610 x 508 mm] and smaller) stainless steel.
- Full view UV-resistant polycarbonate window allows maximum viewing area of subpanel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity – designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Uses Eclipse 1/4 turn latches or handles.
- Doors may be easily removed for modifications and are interchangeable.

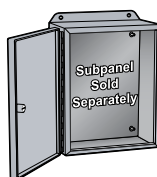

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

## Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 4X, 12, and 13
  - IEC 60529, IP66




Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window					
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
			Painted	Galvanized	
<a href="#">EN4SD12126WSS</a>	\$928.00	12.00 x 12.00 x 6.82 [305 x 305 x 173]	<a href="#">EP1212</a>	<a href="#">EPG1212</a>	<a href="#">PDF</a>
<a href="#">EN4SD16126WSS</a>	\$1,027.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]	<a href="#">EP1612</a>	<a href="#">EPG1612</a>	<a href="#">PDF</a>
<a href="#">EN4SD161210WSS</a>	\$1,246.00	16.00 x 12.00 x 10.82 [406 x 305 x 275]	<a href="#">EP1612</a>	<a href="#">EPG1612</a>	<a href="#">PDF</a>
<a href="#">EN4SD20166WSS</a>	\$1,249.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">EN4SD20168WSS</a>	\$1,331.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">EN4SD20206WSS</a>	\$1,365.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">EN4SD201610WSS</a>	\$1,448.00	20.00 x 16.00 x 10.82 [508 x 406 x 275]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">EN4SD20208WSS</a>	\$1,469.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">EN4SD202010WSS</a>	\$1,567.00	20.00 x 20.00 x 10.82 [508 x 508 x 275]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">EN4SD24208WSS</a>	\$1,617.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]	<a href="#">EP2420</a>	<a href="#">EPG2420</a>	<a href="#">PDF</a>
<a href="#">EN4SD242010WSS</a>	\$1,684.00	24.00 x 20.00 x 10.82 [610 x 508 x 275]	<a href="#">EP2420</a>	<a href="#">EPG2420</a>	<a href="#">PDF</a>
<a href="#">EN4SD202012WSS</a>	\$1,730.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">EN4SD24248WSS</a>	\$1,767.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">EN4SD242410WSS</a>	\$1,817.00	24.00 x 24.00 x 10.82 [610 x 610 x 275]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">EN4SD30248WSS</a>	\$2,018.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">EN4SD302410WSS</a>	\$2,020.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">EN4SD302412WSS</a>	\$2,234.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window



## Dimensions

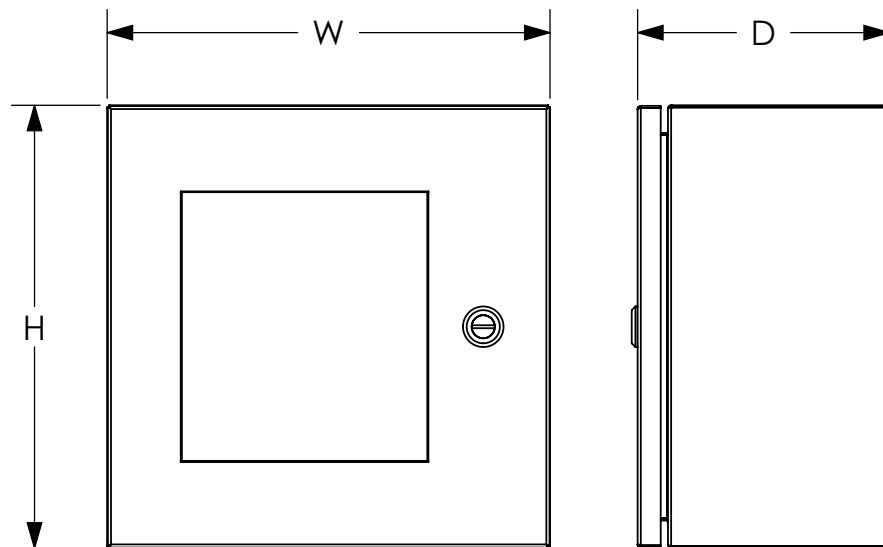

# Enclosure Accessories

## Locks and Latches



### 1/4-Turn Inserts and Keys

#### Features

- For Eclipse Series enclosures.
- Field installable inserts replace standard 1/4-turn slot.
- Available in square and triangle formats, as well as slotted.
- Maintains NEMA, UL and CSA 12, 4, and 4X ratings.
- Non-slot inserts provide extra security since standard screw drivers cannot open.
- Keys constructed from die-cast zinc.
- Keys sold separately from inserts.



1/4-Turn Inserts and Keys								
Latch Insert	Price	Type	Material	Finish	Drawing Link	Key	Price	Finish
<a href="#">2SQI7</a>	\$18.00	square key	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">2SQK7</a>	\$16.75	black matte
<a href="#">2TRI7</a>	\$18.00	triangular key	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">2TRK7</a>	\$16.75	natural
<a href="#">2SLI</a>	\$18.00	slotted	die-cast zinc	black matte	<a href="#">PDF</a>	—	—	—
<a href="#">2DBI3</a>	\$18.00	3mm double-bit	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">PMKEY</a>	\$16.50	black matte
<a href="#">2DBI3SS</a>	\$45.00	3mm double-bit	stainless steel	natural	<a href="#">PDF</a>	<a href="#">PMKEY</a>	\$16.50	natural



### 1/4-Turn Latch Assemblies

#### Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on Eclipse or Eclipse Jr series.
- Maintains NEMA, UL, and CSA ratings of enclosures.
- Keylocking latch assemblies include two keys.



1/4-Turn Latch Assemblies							
Part Number	Price	Style	Security	Material	Finish	For Use With	Drawing Link
<a href="#">EQTRL</a>	\$24.50	1/4-turn semi-flush	keylocking	die-cast zinc	chrome	Eclipse series swing-out panels	<a href="#">PDF</a>
<a href="#">2QTR</a>	\$18.25	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">2SSQTR</a>	\$68.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse series	<a href="#">PDF</a>
<a href="#">2WKL</a>	\$99.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">2QPL</a>	\$84.00	1/4-turn knob	padlocking	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">EJQTR</a>	\$15.00	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJSSQTR</a>	\$47.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJWKL</a>	\$46.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJWKNL</a>	\$46.00	1/4-turn wing handle	—	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>

# Enclosure Accessories

## Locks and Latches



### Eclipse Series 1-Point 1/4-Turn Handles



T-Handle



L-Handle

#### Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on all Eclipse series enclosures.
- Keylocking latch assemblies include two keys.
- Maintain NEMA, UL and CSA ratings of enclosure.

Eclipse Series 1-Point 1/4-Turn Handles						
Part Number	Price	Style	Security	Material	Finish	Drawing Link
<a href="#"><u>EHTL</u></a>	\$68.00	1/4-turn tee handle	keylocking	die-cast zinc	black matte	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHL</u></a>	\$69.00	1/4-turn L-handle	keylocking	die-cast zinc	black matte	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHLNL</u></a>	\$69.00	1/4-turn L-handle	—	die-cast zinc	black matte	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHLPL</u></a>	\$127.00	1/4-turn L-handle	padlocking	zinc plated steel	—	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHLSS</u></a>	\$310.00	1/4-turn L-handle	keylocking	316 stainless steel	—	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHLNLSS</u></a>	\$310.00	1/4-turn L-handle	—	316 stainless steel	—	<a href="#"><u>PDF</u></a>
<a href="#"><u>EHLPLSS</u></a>	\$310.00	1/4-turn L-handle	padlocking	316 stainless steel	—	<a href="#"><u>PDF</u></a>