

# NEMA 12 and 13 22 mm Pushbutton Wall-Mount



## Applications

- Designed to accept 22 mm [0.87in] miniature oil-tight pushbuttons, switches and pilot lights.
- Provides protection from dirt, dust, oil, and water.

## Construction

- Smooth continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Captive cover screws thread into sealed wells.
- Larger enclosures provide internally hinged removable covers, designed to hold the cover open during wiring (see table).
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door, and a grounding stud is provided on the enclosure.

## Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray or RAL7035 light gray powder coating.

## Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 12 and 13
  - IEC 60529, IP54
- All appropriate components are required to maintain these standards.

 



| NEMA 12 and 13 22 mm [0.87in] Pushbutton Wall-Mount |         |          |                                       |              |         |             |        |
|---|---------|----------|---------------------------------------|--------------|---------|-------------|--------|
| ANSI 61   | RAL7035 | Price    | Size HxWxD                            | Drawing Link | # Holes | Steel Gauge | Hinged |
| MPB1  | MPB1LG  | \$81.00  | 3.56 x 3.06 x 3.66 [90 x 78 x 93]     | PDF          | 1       | 16          | No     |
| MPB2  | MPB2LG  | \$93.00  | 5.44 x 3.06 x 3.67 [138 x 78 x 93]    | PDF          | 2       | 14          |        |
| MPB3  | MPB3LG  | \$102.00 | 7.31 x 3.06 x 3.67 [186 x 78 x 93]    | PDF          | 3       |             |        |
| MPB4  | MPB4LG  | \$113.00 | 9.19 x 3.06 x 3.67 [233 x 78 x 93]    | PDF          | 4       |             |        |
| MPB6  | MPB6LG  | \$144.00 | 8.81 x 5.31 x 4.47 [224 x 135 x 114]  | PDF          | 6       |             | Yes    |
| MPB9  | MPB9LG  | \$158.00 | 8.81 x 6.81 x 4.47 [224 x 173 x 114]  | PDF          | 9       |             |        |
| MPB12   | MPB12LG | \$176.00 | 10.69 x 6.81 x 4.47 [272 x 173 x 114] | PDF          | 12      |             |        |
| Note: Dimensions in inches [millimeters].           |         |          |                                       |              |         |             |        |


# NEMA 12 and 13 22 mm Pushbutton Wall-Mount




## Dimensions

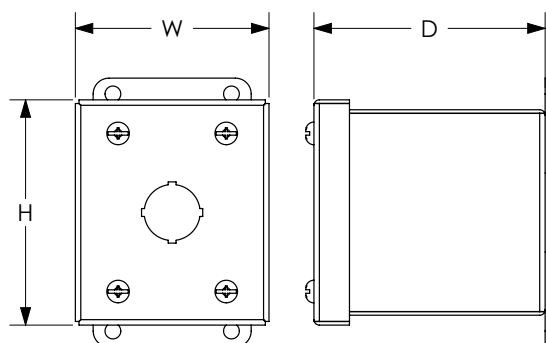


1

 


2

 


3

 


4

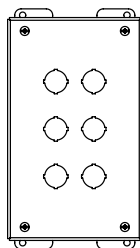

6

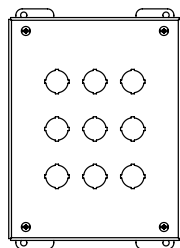

9

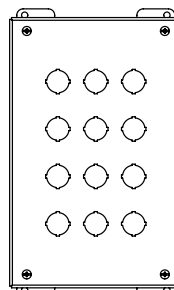

12