

NEMA 12 and 13 Operator Consolets



Applications

- Designed for use as electric, hydraulic or pneumatic control and instrument enclosures.
- Ideal for flat surface mounting or pedestal mounting to provide the necessary 30° or 60° control slope.
- Provides protection from dirt, dust, oil, and water.

Construction

- Formed 14-gauge steel.
- Smooth, continuously welded seams.
- Construction provides either 30° or 60° slope on front cover depending on mounting position.
- Continuously hinged cover may be removed by pulling the hinge pin.
- Captive cover screws thread into sealed wells.
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door and a ground stud is provided on the enclosure.

Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating.

Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 12 and 13
 - IEC 60529, IP54




NEMA 12 and 13 Operator Consolets			
Part Number	Price	Console Size HxWxD	Drawing Link
1488EE7	\$169.00	8.05 x 8.34 x 7.41 [204 x 212 x 188]	PDF
1488EH7	\$187.00	8.05 x 12.34 x 7.41 [204 x 313 x 188]	PDF
1488EJ7	\$205.00	8.05 x 16.34 x 7.41 [204 x 415 x 188]	PDF
1488EL7	\$227.00	8.05 x 20.34 x 7.41 [204 x 517 x 188]	PDF
1488HH9	\$218.00	11.51 x 12.34 x 9.37 [292 x 313 x 238]	PDF
1488HJ9	\$241.00	11.51 x 16.34 x 9.37 [292 x 415 x 238]	PDF
1488HL9	\$274.00	11.51 x 20.34 x 9.37 [292 x 517 x 238]	PDF
1488HN9	\$298.00	11.51 x 24.34 x 9.37 [292 x 618 x 238]	PDF
1488JJ11	\$279.00	14.98 x 16.34 x 11.37 [380 x 415 x 289]	PDF
1488JL11	\$311.00	14.97 x 20.34 x 11.37 [380 x 517 x 289]	PDF
1488JN11	\$342.00	14.97 x 24.34 x 11.37 [380 x 618 x 289]	PDF
1488JQ11	\$400.00	14.97 x 30.34 x 11.37 [380 x 771 x 289]	PDF
1488JS11	\$450.00	14.97 x 36.34 x 11.37 [380 x 923 x 289]	PDF
1488LL13	\$367.00	18.44 x 20.34 x 13.37 [468 x 517 x 340]	PDF
1488LN13	\$409.00	18.44 x 24.34 x 13.37 [468 x 618 x 340]	PDF
1488LQ13	\$454.00	18.44 x 30.34 x 13.37 [468 x 771 x 340]	PDF
Dimensions in inches [millimeters].			

NEMA 12 and 13 Operator Consolets



Dimensions

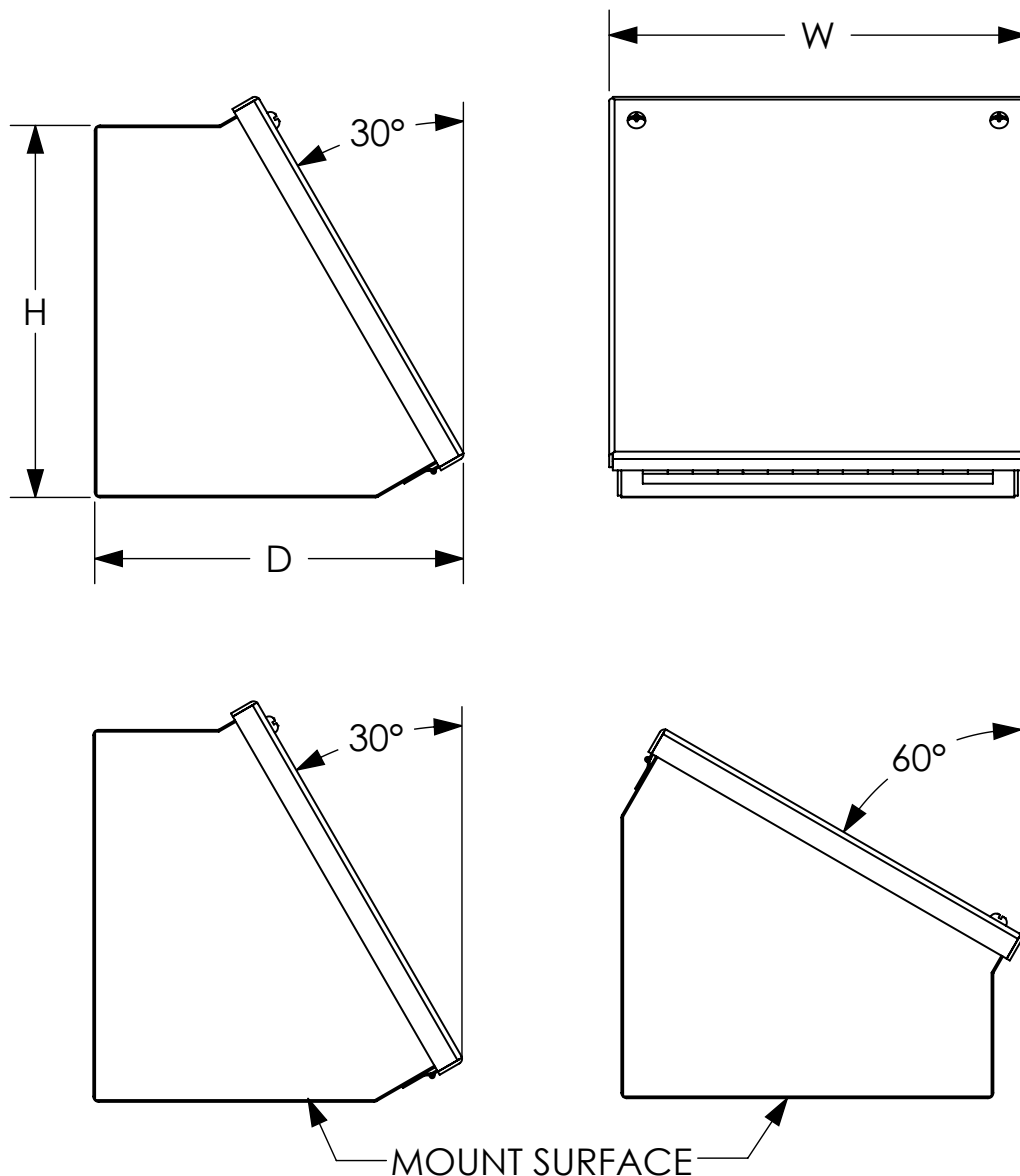

CONSOLE CAN BE POSITIONED AT 30° OR 60° ANGLE