


# NEMA 12 Double-Door Wall-Mount

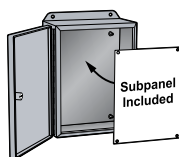

## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides some protection from falling dirt, dust, oil, and water.

## Construction

- Enclosures are formed 14-gauge steel with 12-gauge steel subpanels. Exceptions are 42 x 60 in [1067 x 1524 mm] and 48 x 48 in [1219 x 1219 mm] which are formed 12-gauge steel with 10-gauge steel subpanels.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Body stiffeners are provided in enclosures 30 in [762 mm] high or more for extra rigidity.
- 14-gauge welded mounting brackets
- Gasketed overlapping doors eliminate the need for a center post.
- Continuously hinged doors may be removed by pulling the hinge pin.
- Doors are secured with a 3-point latch and operated with a key locking automotive type handle.
- Latch rods are equipped with rollers for easier door closing.
- Oil-resistant gaskets are permanently secured.
- Collar studs are provided for mounting subpanels.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.
- A literature pocket is provided for the inside of the door.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating on the inside and outside.
- Removable subpanel is finished in RAL9003 white powder coating.

## Listings

- UL 508A Type 12 [UL File E65324]
- CSA Type 12 [CSA File LR21001]
- Complies with
  - NEMA Type 12
  - IEC 60529, IP54



## NEMA 12 Double-Door Wall-Mount

Part Number	Price	Enclosure Size HxWxD	Optional Subpanels					Drawing Link
			Painted (included)	Aluminum	Galvanized	Stainless	Dimensions	
<a href="#">1422P8</a>	1,062.00	24.00 x 42.00 x 9.21 [610 x 1067 x 234]	<a href="#">18P3921</a>	—	<a href="#">18G3921</a>	—	39.00 x 21.00 [991 x 533]	<a href="#">PDF</a>
<a href="#">1422P10</a>	1,274.00	24.00 x 42.00 x 11.21 [610 x 1067 x 285]	<a href="#">18P3921</a>	—	<a href="#">18G3921</a>	—	39.00 x 21.00 [991 x 533]	<a href="#">PDF</a>
<a href="#">1422PW8</a>	1,161.00	24.00 x 48.00 x 9.21 [610 x 1219 x 234]	<a href="#">18P4521</a>	—	<a href="#">18G4521</a>	—	45.00 x 21.00 [1143 x 533]	<a href="#">PDF</a>
<a href="#">1422R10</a>	1,281.00	30.00 x 42.00 x 11.21 [762 x 1067 x 285]	<a href="#">18P3927</a>	—	<a href="#">18G3927</a>	<a href="#">18P3927S16</a>	39.00 x 27.00 [991 x 686]	<a href="#">PDF</a>
<a href="#">1422RW10</a>	1,401.00	30.00 x 48.00 x 11.21 [762 x 1219 x 285]	<a href="#">18P4527</a>	—	<a href="#">18G4527</a>	—	45.00 x 27.00 [1143 x 686]	<a href="#">PDF</a>
<a href="#">1422RX10</a>	1,678.00	30.00 x 60.00 x 11.21 [762 x 1524 x 285]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">1422UV12</a>	1,537.00	36.00 x 42.00 x 13.21 [914 x 1067 x 336]	<a href="#">18P3933</a>	—	<a href="#">18G3933</a>	<a href="#">18P3933S16</a>	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">1422UW12</a>	1,642.00	36.00 x 48.00 x 13.21 [914 x 1219 x 336]	<a href="#">18P4533</a>	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1422UX12</a>	1,928.00	36.00 x 60.00 x 13.21 [914 x 1524 x 336]	<a href="#">18P5733</a>	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">1422VV12</a>	1,699.00	42.00 x 42.00 x 13.21 [1067 x 1067 x 336]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">1422VW12</a>	1,869.00	42.00 x 48.00 x 13.21 [1067 x 1219 x 336]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">1422VX12</a>	2,169.00	42.13 x 60.06 x 13.85 [1070 x 1526 x 352]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">1422WW12</a>	2,027.00	48.13 x 48.06 x 13.85 [1223 x 1221 x 352]	—	—	—	—	—	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 12 Double-Door Wall-Mount



## Dimensions

