

NEMA 1 Steel Three-Piece Wall-Mount



Applications

- Designed for indoor use to enclose controls, instruments, and components which do not require oil-tight or dust-tight protection.
- Ideal for applications where components may be easily mounted and wired prior to installation of wrapper and door.

Construction

- Three-piece assembly consisting of a base, wrapper, and door.
- Components are attached and secured with metal screws.
- 14-gauge reverse formed base acts as mounting surface (no separate subpanel) and provides clearance for mounting hardware.
- Wrapper is available in three depths: 4 in [102 mm], 6 in [152 mm], and 8 in [203 mm]
- Wrapper is formed from 16-gauge steel, with no knock-outs in the sides.
- Door assembly formed from 16-gauge steel.
- Removable door is mounted on slip hinges.
- A bonding stud is provided on the door, and a grounding screw is provided for the enclosure.
- Door is fastened with a slotted 1/4-turn latch.
- Uses N1JLK 1/4 turn latch.

Finish

- Base, wrapper and door are finished in ANSI 61 gray powder coating.

Listings

- UL 50 Type 1
- CSA Type 1
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



NEMA 1 Steel Three-Piece Wall-Mount


Part Number	Price	Enclosure Size HxWxD	Drawing Link
N1WS864	\$114.00	8.28 x 6.28 x 4.16 [210 x 160 x 106]	PDF
N1WS866	\$122.00	8.28 x 6.28 x 6.16 [210 x 160 x 156]	PDF
N1WS868	\$134.00	8.28 x 6.28 x 8.16 [210 x 160 x 207]	PDF
N1WS1084	\$133.00	10.28 x 8.28 x 4.16 [261 x 210 x 106]	PDF
N1WS1086	\$125.00	10.28 x 8.28 x 6.16 [261 x 210 x 156]	PDF
N1WS1088	\$149.00	10.28 x 8.28 x 8.16 [261 x 210 x 207]	PDF
N1WS12104	\$136.00	12.28 x 10.28 x 4.16 [312 x 261 x 106]	PDF
N1WS12106	\$146.00	12.28 x 10.28 x 6.16 [312 x 261 x 156]	PDF
N1WS12108	\$161.00	12.28 x 10.28 x 8.16 [312 x 261 x 207]	PDF
N1WS16124	\$157.00	16.28 x 12.28 x 4.16 [414 x 312 x 106]	PDF
N1WS16126	\$176.00	16.28 x 12.28 x 6.16 [414 x 312 x 156]	PDF
N1WS16128	\$192.00	16.28 x 12.28 x 8.16 [414 x 312 x 207]	PDF
N1WS20164	\$244.00	20.28 x 16.28 x 4.16 [515 x 414 x 106]	PDF
N1WS20166	\$247.00	20.28 x 16.28 x 6.16 [515 x 414 x 156]	PDF
N1WS20168	\$268.00	20.28 x 16.28 x 8.16 [515 x 414 x 207]	PDF
N1WS24204	\$270.00	24.28 x 20.28 x 4.16 [617 x 515 x 106]	PDF
N1WS24206	\$280.00	24.28 x 20.28 x 6.16 [617 x 515 x 156]	PDF
N1WS24208	\$299.00	24.28 x 20.28 x 8.16 [617 x 515 x 207]	PDF

Note: Dimensions in inches [millimeters].

NEMA 1 Steel Three-Piece Wall-Mount



Dimensions

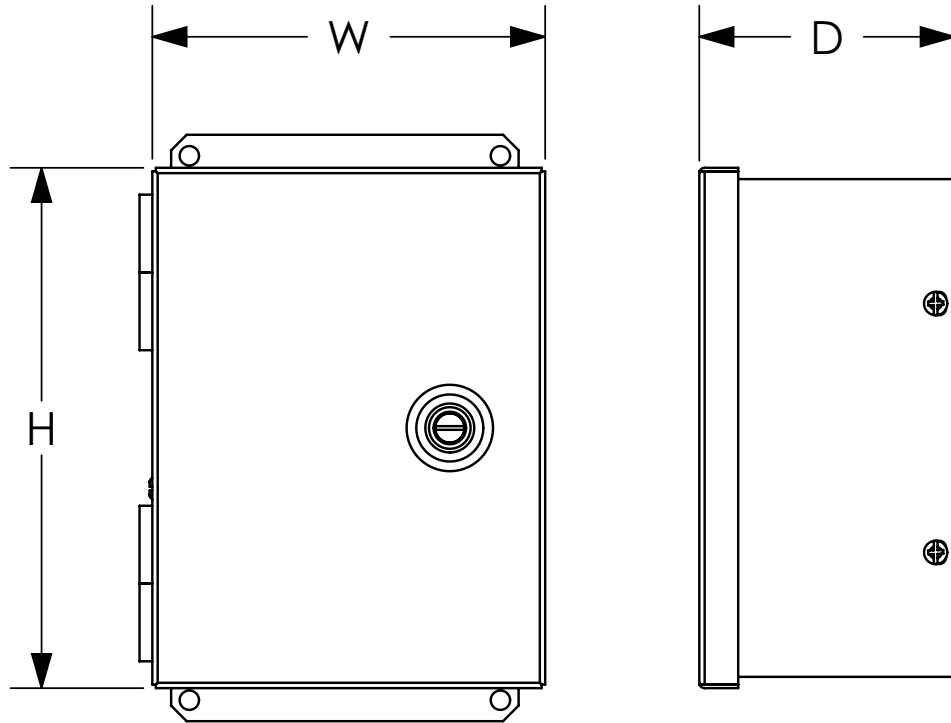

Enclosure Accessories

Locks and Latches



Padlock Kit



Features

- Field installed kit requires drilling of only 4 holes.
- Compatible with 1414 and HJ enclosures.
- Only available in 316 stainless steel.
- Includes mounting hardware.
- Sold Individually.
- Installation instructions provided.

Padlock Kit		
Part Number	Price	Drawing Link
14PLKS16	\$23.50	PDF

NEMA 1 Lock Kits



Features

- Keylocking, 1-point, 1/4-turn, flush-mount latch.
- Installs in place of the existing slotted latch, or in cutout hole provided.
- Reversible cam position for other applications.
- Maintains NEMA 1 rating.

NEMA 1 Lock Kit				
Part Number	Price	Fits Enclosures	Material	Drawing Link
1427LKN1	\$36.00	1420 and N1A	plated steel	PDF
N1JLK	\$9.50	N1J, CHKO, N1WS, N1WF, and SWB	polyamide	PDF

Padlock Adaptor

EJ Series



Features

- For use with Eclipse Junior (EJ) Series enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 2mm thick 14-gauge stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4, and 4X rating.

Padlock Adaptor Eclipse and Series 2000		
Part Number	Price	Drawing Link
EJPA	\$23.50	PDF

Padlock Adaptor

Eclipse and Series 2000



Features

- For use with EN4SD /S2000 Series Enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 14-gauge 304 stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4 and 4X rating.

Padlock Adaptor EJ Series		
Part Number	Price	Drawing Link
EPA	\$25.00	PDF