

NEMA 1 Galvanized Steel Screw Cover Wall-Mount with Knockouts



Applications

- Designed for general purpose indoor commercial use as a junction, pull or switch box.

Construction

- Formed and spot welded from 16- or 14-gauge steel depending on size.
- Flat steel covers fastened with plated steel screws.
- Keyhole slots permit cover to be lifted off without removing screws entirely.
- Easily removed knockouts on all four sides (see drawings for sizes and locations).
- Through holes in back for wall-mounting.
- Grounding location embossed in body.

Finish

- Enclosure and cover are unpainted galvanized steel.

Listings

- UL-50 Type 1 [UL File E63524]
- CSA Type 1 [CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20




NEMA 1 Galvanized Steel Screw Cover Wall-Mount with Knockouts					
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Side Pattern	Top and Bottom Pattern
CSKOG664	\$12.50	6.00 x 6.00 x 4.06 [152 x 152 x 103]	PDF	Z-X-Z	Z-X-Z
CSKOG666	\$16.25	6.00 x 6.00 x 6.06 [152 x 152 x 154]	PDF	Z-X-Z	Z-X-Z
CSKOG884	\$17.75	8.00 x 8.00 x 4.06 [203 x 203 x 103]	PDF	X-Z-X-Z	X-Z-X-Z
CSKOG886	\$22.00	8.00 x 8.00 x 6.06 [203 x 203 x 154]	PDF	X-Z-X-Z	X-Z-X-Z
CSKOG10104	\$24.50	10.00 x 10.00 x 4.06 [254 x 254 x 103]	PDF	X-Z-X-Z	X-Z-Y-Z-X
CSKOG10106	\$28.50	10.00 x 10.00 x 6.06 [254 x 254 x 154]	PDF	X-Z-X-Z	X-Z-Y-Z-X
CSKOG12124	\$29.50	12.00 x 12.00 x 4.06 [305 x 305 x 103]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKOG12126	\$36.50	12.00 x 12.00 x 6.06 [305 x 305 x 154]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKOG12128	\$46.00	12.00 x 12.00 x 8.06 [305 x 305 x 205]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKOG16166	\$64.00	16.00 x 16.00 x 6.06 [406 x 406 x 154]	PDF	Z-X-Z-Y-Z-X-Z	Z-X-Z-Y-Z-X-Z
CSKOG16168	\$80.00	16.00 x 16.00 x 8.06 [406 x 406 x 205]	PDF	Z-X-Z-Y-Z-X-Z	Z-X-Z-Y-Z-X-Z
CSKOG18124	\$47.50	18.00 x 12.00 x 4.06 [457 x 305 x 103]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-Y-Z-X


Note: Dimensions in inches [millimeters].

NEMA 1 Galvanized Steel Screw Cover
Wall-Mount with Knockouts

Dimensions

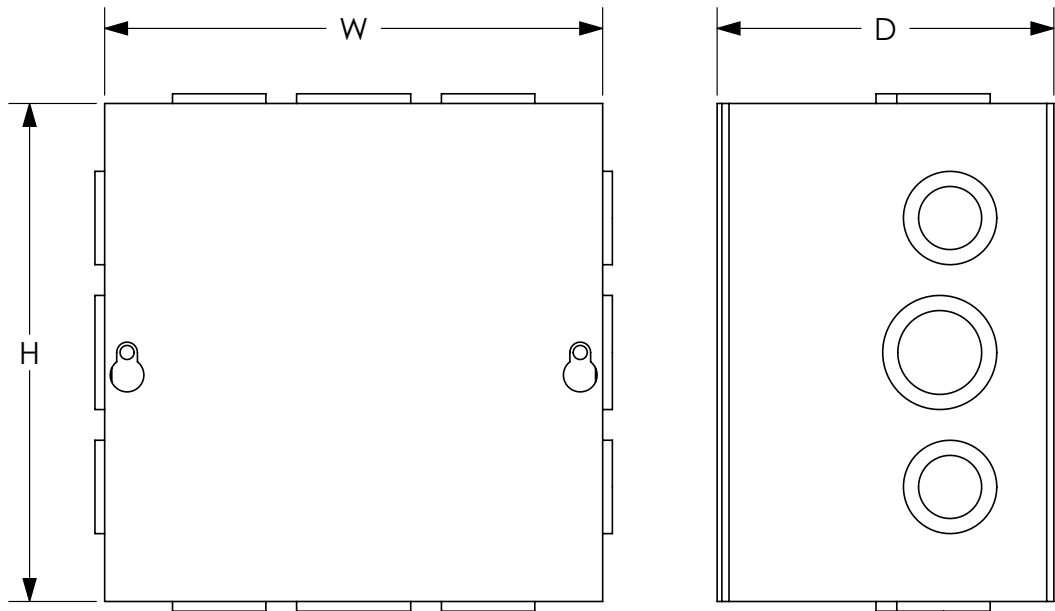

TYPICAL SIZES AND SPACING

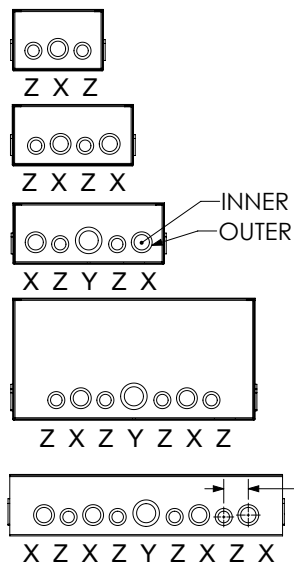

SIZE & DISTANCE INFORMATION			
ID	INNER KNOCK-OUT	OUTER KNOCK-OUT	☒ DISTANCE
X	1.00 ϕ	1.38 ϕ	1.62 TYPICAL
Y	1.23 ϕ	1.75 ϕ	
Z	0.73 ϕ	1.13 ϕ	

Enclosure Accessories

Flush Covers for CS and CSKO Enclosures



Application

- Oversized covers for CS/CSKO screw cover enclosures
- Designed for flush mount installation requirements
- 1.5 in [38mm] taller and wider than standard covers
- Constructed of 16- or 14-gauge steel
- Painted ANSI 61 gray
- Note: Enclosures sold separately

Flush Covers

Part Number	Price	Actual Size HxW	For Use with Screw Cover Enclosures HxW	Cover Thickness	Drawing Link
CSFC66	\$3.00	7.50 x 7.50 [191 x 191]	6.00 x 6.00 [152 x 152]	16 gauge	PDF
CSFC86	\$3.75	9.50 x 7.50 [241 x 191]	8.00 x 6.00 [203 x 152]		PDF
CSFC88	\$4.50	9.50 x 9.50 [241 x 241]	8.00 x 8.00 [203 x 203]		PDF
CSFC108	\$5.50	11.50 x 9.50 [292 x 241]	10.00 x 8.00 [254 x 203]		PDF
CSFC1010	\$6.25	11.50 x 11.50 [292 x 292]	10.00 x 10.00 [254 x 254]		PDF
CSFC128	\$6.00	13.50 x 9.50 [343 x 241]	12.00 x 8.00 [305 x 203]		PDF
CSFC1212	\$8.50	13.50 x 13.50 [343 x 343]	12.00 x 12.00 [305 x 305]		PDF
CSFC1616	\$10.25	17.50 x 17.50 [445 x 445]	16.00 x 16.00 [406 x 406]		PDF
CSFC1812	\$11.00	19.50 x 13.50 [495 x 343]	18.00 x 12.00 [457 x 305]		PDF
CSFC1818	\$15.25	19.50 x 19.50 [495 x 495]	18.00 x 18.00 [457 x 457]		PDF
CSFC2418	\$19.75	25.50 x 19.50 [648 x 495]	24.00 x 18.00 [610 x 457]	14 gauge	PDF
CSFC2424	\$25.00	25.50 x 25.50 [648 x 648]	24.00 x 24.00 [610 x 610]		PDF

Note: Dimensions in inches [millimeters].