


NEMA 1 Large Single-Door Wall-Mount with 1/4-Turn Latch

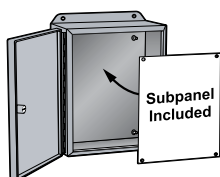

Applications

- Designed for indoor use to house controls, instruments and components not requiring oil-tight or dust-tight protection.

Construction

- Enclosure is formed and spot welded from 12- or 14-gauge steel.
- Removable 12- or 14-gauge subpanel is mounted in the rear of the enclosure on collar studs.
- Door is fastened with a slotted 1/4-turn latch.
- A bonding stud is provided on the door, and a grounding stud is provided in the box.
- Mounting holes are provided in the rear of the enclosure.
- Uses N1JLK 1/4 turn latch.

Finish


- Enclosure and door are finished in ANSI 61 gray powder coating.
- Subpanel is finished in RAL9003 white powder coating

Listings

- 50 Type 1 [UL File E65324]
- CSA Type 1 [CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



Dimensions

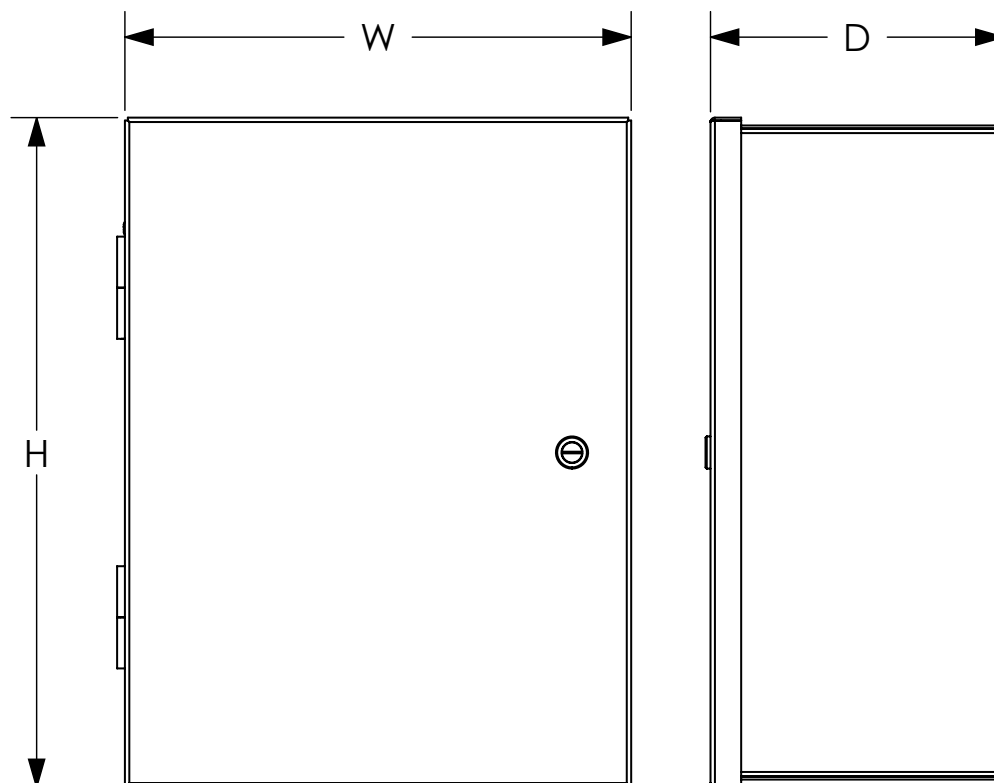

NEMA 1 Large Single-Door Wall-Mount with 1/4-Turn Latch



NEMA 1 Large Single-Door Wall-Mount with 1/4-Turn Latch							
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Included Subpanel	Subpanel Dimensions	Optional Perforated Subpanel	Hinge Type
N1A16127	\$200.00	16.38 x 12.38 x 7.18 [416 x 314 x 182]	PDF	AP1612	13.00 x 10.50 [330 x 267]	AP1612PP	slip hinges
N1A16129	\$216.00	16.38 x 12.38 x 9.18 [416 x 314 x 233]	PDF	AP1612	13.00 x 10.50 [330 x 267]	AP1612PP	
N1A16167	\$226.00	16.38 x 16.38 x 7.18 [416 x 416 x 182]	PDF	AP1616	13.00 x 14.50 [330 x 368]	AP1616PP	
N1A16207	\$251.00	16.38 x 20.38 x 7.18 [416 x 518 x 182]	PDF	AP1620	13.00 x 18.50 [330 x 470]	AP1620PP	
N1A20167	\$251.00	20.38 x 16.38 x 7.18 [518 x 416 x 182]	PDF	AP2016	17.00 x 14.50 [432 x 368]	AP2016PP	
N1A20169	\$273.00	20.38 x 16.38 x 9.18 [518 x 416 x 233]	PDF	AP2016	17.00 x 14.50 [432 x 368]	AP2016PP	
N1A20207	\$283.00	20.38 x 20.38 x 7.18 [518 x 518 x 182]	PDF	AP2020	17.00 x 18.50 [432 x 470]	AP2020PP	
N1A20209	\$307.00	20.38 x 20.38 x 9.18 [518 x 518 x 233]	PDF	AP2020	17.00 x 18.50 [432 x 470]	AP2020PP	
N1A20249	\$340.00	20.38 x 24.38 x 9.18 [518 x 619 x 233]	PDF	AP2024	17.00 x 22.50 [432 x 572]	AP2024PP	
N1A24167	\$278.00	24.38 x 16.38 x 7.18 [619 x 416 x 182]	PDF	AP2416	21.00 x 14.50 [533 x 368]	AP2416PP	
N1A24207	\$313.00	24.38 x 20.38 x 7.18 [619 x 518 x 182]	PDF	AP2420	21.00 x 18.50 [533 x 470]	AP2420PP	
N1A24209	\$339.00	24.38 x 20.38 x 9.18 [619 x 518 x 233]	PDF	AP2420	21.00 x 18.50 [533 x 470]	AP2420PP	
N1A242012	\$364.00	24.38 x 20.38 x 12.18 [619 x 518 x 309]	PDF	AP2420	21.00 x 18.50 [533 x 470]	AP2420PP	
N1A24247	\$351.00	24.38 x 24.38 x 7.18 [619 x 619 x 182]	PDF	AP2424	21.00 x 22.50 [533 x 572]	AP2424PP	
N1A24249	\$379.00	24.38 x 24.38 x 9.18 [619 x 619 x 233]	PDF	AP2424	21.00 x 22.50 [533 x 572]	AP2424PP	
N1A242412	\$434.00	24.38 x 24.38 x 12.18 [619 x 619 x 309]	PDF	AP2424	21.00 x 22.50 [533 x 572]	AP2424PP	
N1A30207	\$360.00	30.38 x 20.38 x 7.18 [772 x 518 x 182]	PDF	AP3020	26.00 x 18.50 [660 x 470]	AP3020PP	
N1A30209	\$408.00	30.38 x 20.38 x 9.18 [772 x 518 x 233]	PDF	AP3020	26.00 x 18.50 [660 x 470]	AP3020PP	
N1A30247	\$407.00	30.38 x 24.38 x 7.18 [772 x 619 x 182]	PDF	AP3024	26.00 x 22.50 [660 x 572]	AP3024PP	
N1A30249	\$439.00	30.38 x 24.38 x 9.18 [772 x 619 x 233]	PDF	AP3024	26.00 x 22.50 [660 x 572]	AP3024PP	
N1A302412	\$501.00	30.38 x 24.38 x 12.18 [772 x 619 x 309]	PDF	AP3024	26.00 x 22.50 [660 x 572]	AP3024PP	
N1A30309	\$505.00	30.38 x 30.38 x 9.18 [772 x 772 x 233]	PDF	AP3030	26.00 x 28.50 [660 x 724]	AP3030PP	
N1A36247	\$458.00	36.38 x 24.38 x 7.18 [924 x 619 x 182]	PDF	AP3624	32.00 x 22.50 [813 x 572]	AP3624PP	
N1A36249	\$493.00	36.38 x 24.38 x 9.18 [924 x 619 x 233]	PDF	AP3624	32.00 x 22.50 [813 x 572]	AP3624PP	
N1A36307	\$538.00	36.38 x 30.38 x 7.18 [924 x 772 x 182]	PDF	AP3630	32.00 x 28.50 [813 x 724]	AP3630PP	
N1A36309	\$575.00	36.38 x 30.38 x 9.18 [924 x 772 x 233]	PDF	AP3630	32.00 x 28.50 [813 x 724]	AP3630PP	
N1A363012	\$652.00	36.43 x 30.51 x 12.22 [925 x 775 x 310]	PDF	AP3630	32.00 x 28.50 [813 x 724]	AP3630PP	
N1A42249	\$549.00	42.38 x 24.38 x 9.18 [1076 x 619 x 233]	PDF	AP4224	38.00 x 22.50 [965 x 572]	AP4224PP	continuous hinge
N1A423012*	\$1,025.00	42.43 x 30.51 x 12.22 [1078 x 775 x 310]	PDF	AP4230	38.00 x 28.50 [965 x 724]	—	
N1A423612*	\$1,168.00	42.43 x 36.51 x 12.22 [1078 x 927 x 310]	PDF	AP4236	38.00 x 34.50 [965 x 876]	—	
N1A483612*	\$1,238.00	48.43 x 36.51 x 12.22 [1230 x 927 x 310]	PDF	AP4836	44.00 x 34.50 [1118 x 876]	—	

Notes: Dimensions in inches [millimeters].

*12-gauge construction

Enclosure Accessories

Locks and Latches



Padlock Kit



Features

- Field installed kit requires drilling of only 4 holes.
- Compatible with 1414 and HJ enclosures.
- Only available in 316 stainless steel.
- Includes mounting hardware.
- Sold Individually.
- Installation instructions provided.

Padlock Kit		
Part Number	Price	Drawing Link
14PLKS16	\$23.50	PDF

NEMA 1 Lock Kits



Features

- Keylocking, 1-point, 1/4-turn, flush-mount latch.
- Installs in place of the existing slotted latch, or in cutout hole provided.
- Reversible cam position for other applications.
- Maintains NEMA 1 rating.

NEMA 1 Lock Kit				
Part Number	Price	Fits Enclosures	Material	Drawing Link
1427LKN1	\$36.00	1420 and N1A	plated steel	PDF
N1JLK	\$9.50	N1J, CHKO, N1WS, N1WF, and SWB	polyamide	PDF

Padlock Adaptor

EJ Series



Features

- For use with Eclipse Junior (EJ) Series enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 2mm thick 14-gauge stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4, and 4X rating.

Padlock Adaptor Eclipse and Series 2000		
Part Number	Price	Drawing Link
EJPA	\$23.50	PDF

Padlock Adaptor

Eclipse and Series 2000



Features

- For use with EN4SD /S2000 Series Enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 14-gauge 304 stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4 and 4X rating.

Padlock Adaptor EJ Series		
Part Number	Price	Drawing Link
EPA	\$25.00	PDF