

NEMA 1 Screw Cover Wall-Mount



Applications

- Designed for general purpose indoor commercial use as a junction, pull or switch box.

Construction

- Formed and spot welded from 16- or 14-gauge steel depending on size.
- Flat steel covers fastened with plated steel screws.
- Keyhole slots permit cover to be lifted off without removing screws entirely.
- Through holes in back for wall-mounting.
- Grounding location embossed in body.

Finish


- Enclosure and cover are finished in ANSI 61 gray powder coating.

Listings

- UL-50 Type 1
[UL File E65324]
- CSA Type 1
[CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



Dimensions

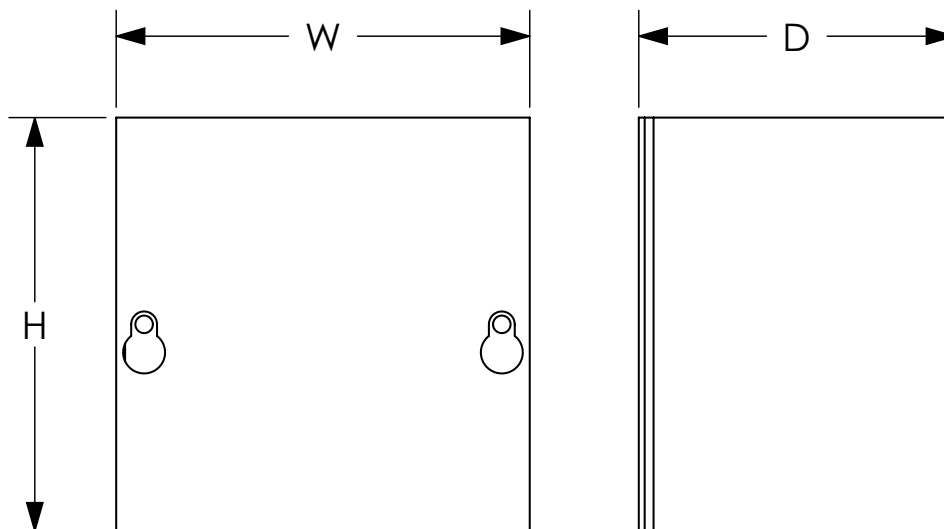

NEMA 1 Screw Cover Wall-Mount



NEMA 1 Screw Cover Wall-Mount			
Part Number	Price	Enclosure Size HxWxD	Drawing Link
CS443	\$13.25	4.00 x 4.00 x 3.06 [102 x 102 x 78]	PDF
CS444	\$11.75	4.00 x 4.00 x 4.06 [102 x 102 x 103]	PDF
CS644	\$13.00	6.00 x 4.00 x 4.06 [152 x 102 x 103]	PDF
CS663	\$19.00	6.00 x 6.00 x 3.06 [152 x 152 x 78]	PDF
CS664	\$13.25	6.00 x 6.00 x 4.06 [152 x 152 x 103]	PDF
CS666	\$17.00	6.00 x 6.00 x 6.06 [152 x 152 x 154]	PDF
CS863	\$22.50	8.00 x 6.00 x 3.06 [203 x 152 x 78]	PDF
CS864	\$15.75	8.00 x 6.00 x 4.06 [203 x 152 x 103]	PDF
CS884	\$18.75	8.00 x 8.00 x 4.06 [203 x 203 x 103]	PDF
CS886	\$23.00	8.00 x 8.00 x 6.06 [203 x 203 x 154]	PDF
CS1084	\$23.00	10.00 x 8.00 x 4.06 [254 x 203 x 103]	PDF
CS1086	\$28.50	10.00 x 8.00 x 6.06 [254 x 203 x 154]	PDF
CS10104	\$25.50	10.00 x 10.00 x 4.06 [254 x 254 x 103]	PDF
CS10106	\$30.00	10.00 x 10.00 x 6.06 [254 x 254 x 154]	PDF
CS1284	\$26.00	12.00 x 8.00 x 4.06 [305 x 203 x 103]	PDF
CS12104	\$33.00	12.00 x 10.00 x 4.06 [305 x 254 x 103]	PDF
CS12106	\$41.00	12.00 x 10.00 x 6.06 [305 x 254 x 154]	PDF
CS12124	\$31.00	12.00 x 12.00 x 4.06 [305 x 305 x 103]	PDF
CS12126	\$38.50	12.00 x 12.00 x 6.06 [305 x 305 x 154]	PDF
CS12128	\$48.00	12.00 x 12.00 x 8.06 [305 x 305 x 205]	PDF
CS16124	\$39.50	16.00 x 12.00 x 4.06 [406 x 305 x 103]	PDF
CS16126	\$49.50	16.00 x 12.00 x 6.06 [406 x 305 x 154]	PDF
CS16143	\$56.00	16.00 x 14.00 x 3.06 [406 x 356 x 78]	PDF
CS16166	\$54.00	16.00 x 16.00 x 6.06 [406 x 406 x 154]	PDF
CS16168	\$80.00	16.00 x 16.00 x 8.06 [406 x 406 x 205]	PDF
CS18124	\$47.50	18.00 x 12.00 x 4.06 [457 x 305 x 103]	PDF
CS18126	\$53.00	18.00 x 12.00 x 6.06 [457 x 305 x 154]	PDF
CS18143	\$77.00	18.00 x 14.00 x 3.06 [457 x 356 x 78]	PDF
CS18184	\$68.00	18.00 x 18.00 x 4.06 [457 x 457 x 103]	PDF
CS18186	\$70.00	18.00 x 18.00 x 6.06 [457 x 457 x 154]	PDF
CS18188	\$92.00	18.00 x 18.00 x 8.06 [457 x 457 x 205]	PDF
CS20143	\$61.00	20.00 x 14.00 x 3.06 [508 x 356 x 78]	PDF
CS202010	\$224.00	20.00 x 20.00 x 10.06 [508 x 508 x 256]	PDF
CS24186	\$107.00	24.00 x 18.00 x 6.06 [610 x 457 x 154]	PDF
CS242410	\$194.00	24.00 x 24.00 x 10.06 [610 x 610 x 256]	PDF
CS24244	\$137.00	24.00 x 24.00 x 4.06 [610 x 610 x 103]	PDF
CS24246	\$136.00	24.00 x 24.00 x 6.06 [610 x 610 x 154]	PDF
CS24248	\$169.00	24.00 x 24.00 x 8.06 [610 x 610 x 205]	PDF
CS302010	\$296.00	30.00 x 20.00 x 10.06 [762 x 508 x 256]	PDF
CS30246	\$177.00	30.00 x 24.00 x 6.06 [762 x 610 x 154]	PDF
CS362410	\$300.00	36.00 x 24.00 x 10.07 [914 x 610 x 256]	PDF
CS36246	\$229.00	36.00 x 24.00 x 6.07 [914 x 610 x 154]	PDF
CS36248	\$257.00	36.00 x 24.00 x 8.07 [914 x 610 x 205]	PDF
CS36366	\$411.00	36.00 x 36.00 x 6.10 [914 x 914 x 155]	PDF
CS363612	\$538.00	36.00 x 36.00 x 12.10 [914 x 914 x 307]	PDF
Note: Dimensions in inches [millimeters].			