

NEMA 1 Screw Cover Wall-Mount with Knockouts



Applications

- Designed for general purpose indoor commercial use as a junction, pull or switch box.

Construction

- Formed and spot welded from 16- or 14-gauge steel depending on size.
- Flat steel covers fastened with plated steel screws.
- Keyhole slots permit cover to be lifted off without removing screws entirely.
- Easily removed knockouts on all four sides. See drawings for sizes and locations.
- Through holes in back for wall-mounting.
- Grounding location embossed in body.

Finish


- Enclosure and cover are finished in ANSI 61 gray powder coating.

Listings


- UL-50 Type 1 [UL File E65324]
- CSA Type 1 [CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



Dimensions

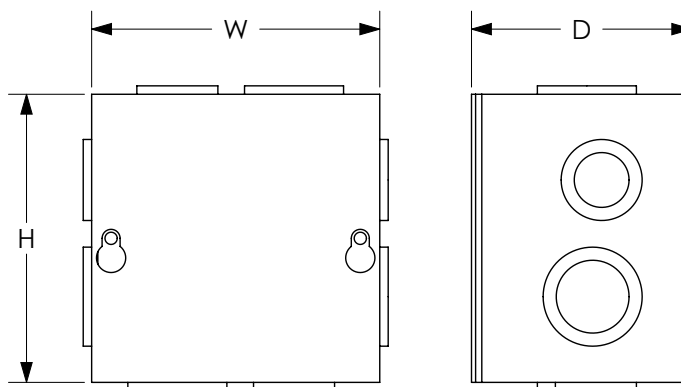

TYPICAL SIZES AND SPACING

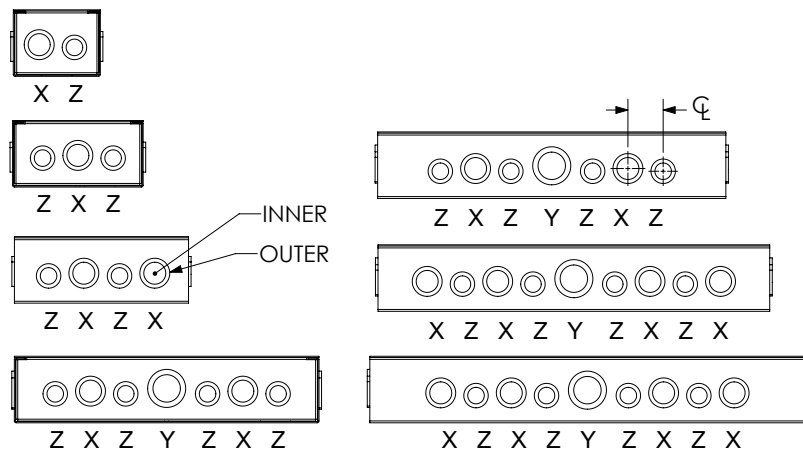

NEMA 1 Screw Cover Wall-Mount with Knockouts



NEMA 1 Screw Cover Wall-Mount with Knockouts					
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Side Pattern	Top and Bottom Pattern
CSKO443	\$13.25	4.00 x 4.00 x 3.06 [102 x 102 x 78]	PDF	X-Z	X-Z
CSKO444	\$11.75	4.00 x 4.00 x 4.06 [102 x 102 x 103]	PDF	X-Z	X-Z
CSKO644	\$13.00	6.00 x 4.00 x 4.06 [152 x 102 x 103]	PDF	Z-X-Z	X-Z
CSKO663	\$19.00	6.00 x 6.00 x 3.06 [152 x 152 x 78]	PDF	Z-X-Z	Z-X-Z
CSKO664	\$13.25	6.00 x 6.00 x 4.06 [152 x 152 x 103]	PDF	X-Z-X-Z	Z-X-Z
CSKO666	\$17.00	6.00 x 6.00 x 6.06 [152 x 152 x 154]	PDF	Z-X-Z	Z-X-Z
CSKO863	\$22.50	8.00 x 6.00 x 3.06 [203 x 152 x 78]	PDF	X-Z-X-Z	Z-X-Z
CSKO864	\$15.75	8.00 x 6.00 x 4.06 [203 x 152 x 103]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO884	\$18.75	8.00 x 8.00 x 4.06 [203 x 203 x 103]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO886	\$23.00	8.00 x 8.00 x 6.06 [203 x 203 x 154]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO10104	\$25.50	10.00 x 10.00 x 4.06 [254 x 254 x 103]	PDF	X-Z-X-Z	X-Z-Y-Z-X
CSKO10106	\$30.00	10.00 x 10.00 x 6.06 [254 x 254 x 154]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO1084	\$23.00	10.00 x 8.00 x 4.06 [254 x 203 x 103]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO1086	\$28.50	10.00 x 8.00 x 6.06 [254 x 203 x 154]	PDF	X-Z-X-Z	X-Z-X-Z
CSKO1284	\$26.00	12.00 x 8.00 x 4.06 [305 x 203 x 103]	PDF	X-Z-Y-Z-X	X-Z-X-Z
CSKO12104	\$33.00	12.00 x 10.00 x 4.06 [305 x 254 x 103]	PDF	X-Z-Y-Z-X	X-Z-X-Z
CSKO12106	\$41.00	12.00 x 10.00 x 6.06 [305 x 254 x 154]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKO12124	\$31.00	12.00 x 12.00 x 4.06 [305 x 305 x 103]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKO12126	\$38.50	12.00 x 12.00 x 6.06 [305 x 305 x 154]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKO12128	\$48.00	12.00 x 12.00 x 8.06 [305 x 305 x 205]	PDF	X-Z-Y-Z-X	X-Z-Y-Z-X
CSKO16124	\$37.50	16.00 x 12.00 x 4.06 [406 x 305 x 103]	PDF	Z-X-Z-Y-Z-X-Z	X-Z-Y-Z-X
CSKO16126	\$47.00	16.00 x 12.00 x 6.06 [406 x 305 x 154]	PDF	Z-X-Z-Y-Z-X-Z	X-Z-Y-Z-X
CSKO16143	\$56.00	16.00 x 14.00 x 3.06 [406 x 356 x 78]	PDF	Z-X-Z-Y-Z-X-Z	Z-X-Z-Y-Z-X-Z
CSKO16166	\$64.00	16.00 x 16.00 x 6.06 [406 x 406 x 154]	PDF	Z-X-Z-Y-Z-X-Z	Z-X-Z-Y-Z-X-Z
CSKO16168	\$80.00	16.00 x 16.00 x 8.06 [406 x 406 x 205]	PDF	Z-X-Z-Y-Z-X-Z	Z-X-Z-Y-Z-X-Z
CSKO18124	\$47.50	18.00 x 12.00 x 4.06 [457 x 305 x 103]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-Y-Z-X
CSKO18126	\$53.00	18.00 x 12.00 x 6.06 [457 x 305 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-Y-Z-X
CSKO18143	\$61.00	18.00 x 14.00 x 3.06 [457 x 356 x 78]	PDF	X-Z-X-Z-Y-Z-X-Z-X	Z-X-Z-Y-Z-X-Z
CSKO18184	\$68.00	18.00 x 18.00 x 4.06 [457 x 457 x 103]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO18186	\$70.00	18.00 x 18.00 x 6.06 [457 x 457 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO20143	\$64.00	20.00 x 14.00 x 3.06 [508 x 356 x 78]	PDF	X-Z-X-Z-Y-Z-X-Z-X	Z-X-Z-Y-Z-X-Z
CSKO202010	\$224.00	20.00 x 20.00 x 10.06 [508 x 508 x 256]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO24186	\$107.00	24.00 x 18.00 x 6.06 [610 x 457 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO24244	\$137.00	24.00 x 24.00 x 4.06 [610 x 610 x 103]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO24246	\$136.00	24.00 x 24.00 x 6.06 [610 x 610 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO24248	\$169.00	24.00 x 24.00 x 8.06 [610 x 610 x 205]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO242410	\$194.00	24.00 x 24.00 x 10.06 [610 x 610 x 256]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO302010	\$296.00	30.00 x 20.00 x 10.06 [762 x 508 x 256]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO30246	\$177.00	30.00 x 24.00 x 6.06 [762 x 610 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO362410	\$402.00	36.00 x 24.00 x 10.07 [914 x 610 x 256]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X
CSKO36246	\$265.00	36.00 x 24.00 x 6.06 [914 x 610 x 154]	PDF	X-Z-X-Z-Y-Z-X-Z-X	X-Z-X-Z-Y-Z-X-Z-X

Note: Dimensions in inches [millimeters].

Enclosure Accessories

Flush Covers for CS and CSKO Enclosures



Application

- Oversized covers for CS/CSKO screw cover enclosures
- Designed for flush mount installation requirements
- 1.5 in [38mm] taller and wider than standard covers
- Constructed of 16- or 14-gauge steel
- Painted ANSI 61 gray
- Note: Enclosures sold separately

Flush Covers						
Part Number	Price	Actual Size HxW	For Use with Screw Cover Enclosures HxW	Cover Thickness	Drawing Link	
CSFC66	\$3.00	7.50 x 7.50 [191 x 191]	6.00 x 6.00 [152 x 152]	16 gauge	PDF	
CSFC86	\$3.75	9.50 x 7.50 [241 x 191]	8.00 x 6.00 [203 x 152]		PDF	
CSFC88	\$4.50	9.50 x 9.50 [241 x 241]	8.00 x 8.00 [203 x 203]		PDF	
CSFC108	\$5.50	11.50 x 9.50 [292 x 241]	10.00 x 8.00 [254 x 203]		PDF	
CSFC1010	\$6.25	11.50 x 11.50 [292 x 292]	10.00 x 10.00 [254 x 254]		PDF	
CSFC128	\$6.00	13.50 x 9.50 [343 x 241]	12.00 x 8.00 [305 x 203]		PDF	
CSFC1212	\$8.50	13.50 x 13.50 [343 x 343]	12.00 x 12.00 [305 x 305]		PDF	
CSFC1616	\$10.25	17.50 x 17.50 [445 x 445]	16.00 x 16.00 [406 x 406]		PDF	
CSFC1812	\$11.00	19.50 x 13.50 [495 x 343]	18.00 x 12.00 [457 x 305]		PDF	
CSFC1818	\$15.25	19.50 x 19.50 [495 x 495]	18.00 x 18.00 [457 x 457]		PDF	
CSFC2418	\$19.75	25.50 x 19.50 [648 x 495]	24.00 x 18.00 [610 x 457]	14 gauge	PDF	
CSFC2424	\$25.00	25.50 x 25.50 [648 x 648]	24.00 x 24.00 [610 x 610]		PDF	

Note: Dimensions in inches [millimeters].