


# NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch

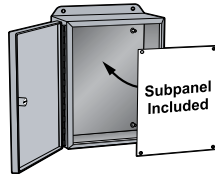

## Applications

- Designed for indoor use to house controls, instruments and components not requiring oil-tight or dust-tight protection.

## Construction

- Formed and spot welded from 16-gauge steel.
- Formed steel covers close by use of slotted 1/4-turn latch.
- Full swing door using butt hinges.
- Through holes in back for wall-mounting.
- Bonding stud is provided on the door and a grounding stud is provided on the box.
- Includes 14-gauge steel subpanel.
- Uses N1JLK 1/4 turn latch.

## Finish

- Enclosure and cover are finished in ANSI 61 gray powder coating.
- Subpanel is finished in RAL9003 white powder coating

## Listings

- UL-50 Type 1  
[UL File E65324]
- CSA Type 1  
[CSA File LR21001]
- Complies with
  - NEMA Type 1
  - IEC 60529, IP20



## NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch


Part Number	Price	Enclosure Size HxWxD	Drawing Link	Included Subpanel	Subpanel Dimensions	Optional Subpanel Perforated
<a href="#">N1J664</a>	\$61.00	6.38 x 6.30 x 4.12 [162 x 160 x 105]	<a href="#">PDF</a>	<a href="#">N1JP66</a>	4.25 x 4.25 [108 x 108]	<a href="#">N1JP66PP</a>
<a href="#">N1J864</a>	\$67.00	8.38 x 6.30 x 4.12 [213 x 160 x 105]	<a href="#">PDF</a>	<a href="#">N1JP86</a>	6.25 x 4.25 [159 x 108]	<a href="#">N1JP86PP</a>
<a href="#">N1J884</a>	\$74.00	8.38 x 8.30 x 4.12 [213 x 211 x 105]	<a href="#">PDF</a>	<a href="#">N1JP88</a>	6.25 x 6.25 [159 x 159]	<a href="#">N1JP88PP</a>
<a href="#">N1J886</a>	\$83.00	8.38 x 8.30 x 6.12 [213 x 211 x 155]	<a href="#">PDF</a>	<a href="#">N1JP88</a>	6.25 x 6.25 [159 x 159]	<a href="#">N1JP88PP</a>
<a href="#">N1J1084</a>	\$82.00	10.38 x 8.30 x 4.12 [264 x 211 x 105]	<a href="#">PDF</a>	<a href="#">N1JP108</a>	8.25 x 6.25 [210 x 159]	<a href="#">N1JP108PP</a>
<a href="#">N1J1086</a>	\$92.00	10.38 x 8.30 x 6.12 [264 x 211 x 155]	<a href="#">PDF</a>	<a href="#">N1JP108</a>	8.25 x 6.25 [210 x 159]	<a href="#">N1JP108PP</a>
<a href="#">N1J10104</a>	\$91.00	10.38 x 10.30 x 4.12 [264 x 262 x 105]	<a href="#">PDF</a>	<a href="#">N1JP1010</a>	8.25 x 8.25 [210 x 210]	<a href="#">N1JP1010PP</a>
<a href="#">N1J10106</a>	\$103.00	10.38 x 10.30 x 6.12 [264 x 262 x 155]	<a href="#">PDF</a>	<a href="#">N1JP1010</a>	8.25 x 8.25 [210 x 210]	<a href="#">N1JP1010PP</a>
<a href="#">N1J12104</a>	\$102.00	12.38 x 10.30 x 4.12 [314 x 262 x 105]	<a href="#">PDF</a>	<a href="#">N1JP1210</a>	10.25 x 8.25 [260 x 210]	<a href="#">N1JP1210PP</a>
<a href="#">N1J12106</a>	\$113.00	12.38 x 10.30 x 6.12 [314 x 262 x 155]	<a href="#">PDF</a>	<a href="#">N1JP1210</a>	10.25 x 8.25 [260 x 210]	<a href="#">N1JP1210PP</a>
<a href="#">N1J12124</a>	\$112.00	12.38 x 12.30 x 4.12 [314 x 312 x 105]	<a href="#">PDF</a>	<a href="#">N1JP1212</a>	10.25 x 10.25 [260 x 260]	<a href="#">N1JP1212PP</a>
<a href="#">N1J12126</a>	\$126.00	12.38 x 12.30 x 6.12 [314 x 312 x 155]	<a href="#">PDF</a>	<a href="#">N1JP1212</a>	10.25 x 10.25 [260 x 260]	<a href="#">N1JP1212PP</a>
<a href="#">N1J12128</a>	\$139.00	12.38 x 12.30 x 8.12 [314 x 312 x 206]	<a href="#">PDF</a>	<a href="#">N1JP1212</a>	10.25 x 10.25 [260 x 260]	<a href="#">N1JP1212PP</a>
<a href="#">N1J14124</a>	\$124.00	14.38 x 12.30 x 4.12 [365 x 312 x 105]	<a href="#">PDF</a>	<a href="#">N1JP1412</a>	12.25 x 10.25 [311 x 260]	<a href="#">N1JP1412PP</a>
<a href="#">N1J14126</a>	\$138.00	14.38 x 12.30 x 6.12 [365 x 312 x 155]	<a href="#">PDF</a>	<a href="#">N1JP1412</a>	12.25 x 10.25 [311 x 260]	<a href="#">N1JP1412PP</a>
<a href="#">N1J14128</a>	\$152.00	14.38 x 12.30 x 8.12 [365 x 312 x 206]	<a href="#">PDF</a>	<a href="#">N1JP1412</a>	12.25 x 10.25 [311 x 260]	<a href="#">N1JP1412PP</a>
<a href="#">N1J16126</a>	\$149.00	16.38 x 12.30 x 6.12 [416 x 312 x 155]	<a href="#">PDF</a>	<a href="#">N1JP1612</a>	14.25 x 10.25 [362 x 260]	<a href="#">N1JP1612PP</a>
<a href="#">N1J20126</a>	\$172.00	20.38 x 12.30 x 6.12 [518 x 312 x 155]	<a href="#">PDF</a>	<a href="#">N1JP2012</a>	18.25 x 10.25 [464 x 260]	<a href="#">N1JP2012PP</a>

Note: Dimensions in inches [millimeters].

# NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch



## Dimensions

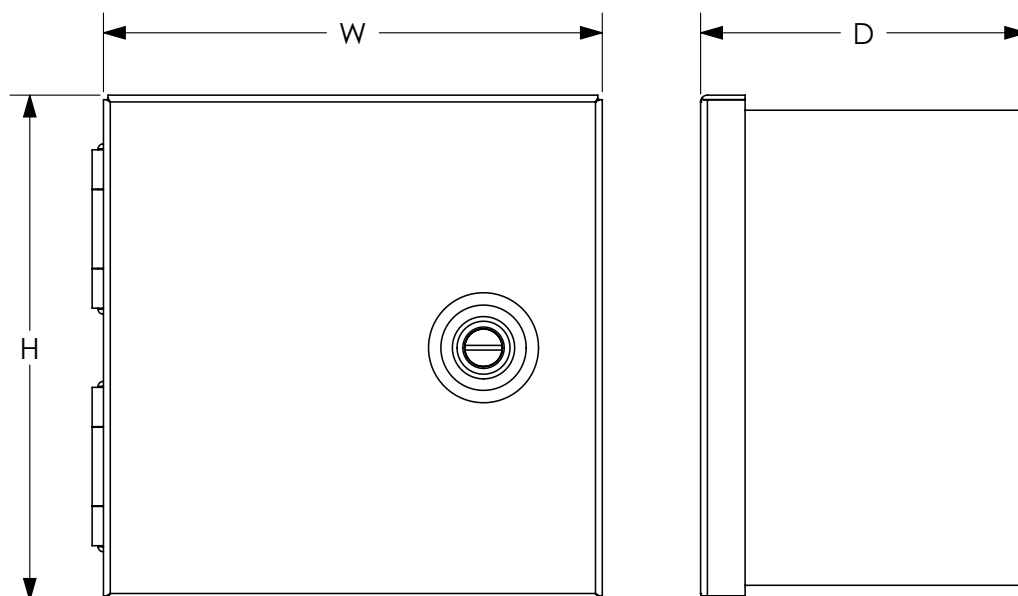

# Enclosure Accessories

## Locks and Latches



### Padlock Kit



#### Features

- Field installed kit requires drilling of only 4 holes.
- Compatible with 1414 and HJ enclosures.
- Only available in 316 stainless steel.
- Includes mounting hardware.
- Sold Individually.
- Installation instructions provided.

Padlock Kit		
Part Number	Price	Drawing Link
<a href="#">14PLKS16</a>	\$23.50	<a href="#">PDF</a>

### NEMA 1 Lock Kits



#### Features

- Keylocking, 1-point, 1/4-turn, flush-mount latch.
- Installs in place of the existing slotted latch, or in cutout hole provided.
- Reversible cam position for other applications.
- Maintains NEMA 1 rating.

NEMA 1 Lock Kit				
Part Number	Price	Fits Enclosures	Material	Drawing Link
<a href="#">1427LKN1</a>	\$36.00	1420 and N1A	plated steel	<a href="#">PDF</a>
<a href="#">N1JLK</a>	\$9.50	N1J, CHKO, N1WS, N1WF, and SWB	polyamide	<a href="#">PDF</a>

### Padlock Adaptor

#### EJ Series



#### Features

- For use with Eclipse Junior (EJ) Series enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 2mm thick 14-gauge stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4, and 4X rating.

Padlock Adaptor Eclipse and Series 2000		
Part Number	Price	Drawing Link
<a href="#">EJPA</a>	\$23.50	<a href="#">PDF</a>

### Padlock Adaptor

#### Eclipse and Series 2000



#### Features

- For use with EN4SD /S2000 Series Enclosures.
- Padlock adaptor fits directly over the slotted quarter turn preventing access.
- 14-gauge 304 stainless steel.
- Stainless steel mounting hardware provided.
- Once installed, the bolts cannot be removed without the door open.
- Easy installed in the field.
- Padlock not included.
- Maintains UL/CSA Type 4 and 4X rating.

Padlock Adaptor EJ Series		
Part Number	Price	Drawing Link
<a href="#">EPA</a>	\$25.00	<a href="#">PDF</a>