

NEMA 3, 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 3-Point Handle



Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Provides high level of protection where equipment is hosed down or otherwise be exposed to wet conditions where corrosion is a serious problem.
- Ideal for processing plants, utility, outdoor municipal, or petro chemical locations where easy yet secure access is required.

Construction

- Formed 14-gauge 304 or 316 stainless steel.
- Continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- 316 stainless pad lockable handle with 3-point roller latching system secures door.
- Uses 1/4 turn latch handles.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.

- Bonding stud provided on door, and grounding stud installed in enclosure.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



NEMA 3, 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 3-Point Handle




NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 3-Point Handle					
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Drawing Link
HW24168SSHK	\$1,242.00	HW24168GYHK	\$549.00	24.00 x 16.00 x 9.21 [610 x 406 x 234]	PDF
HW24206SSHK	\$1,261.00	HW24206GYHK	\$564.00	24.00 x 20.00 x 7.21 [610 x 508 x 183]	PDF
HW24208SSHK	\$1,353.00	HW24208GYHK	\$592.00	24.00 x 20.00 x 9.21 [610 x 508 x 234]	PDF
HW242010SSHK	\$1,448.00	HW242010GYHK	\$621.00	24.00 x 20.00 x 11.21 [610 x 508 x 285]	PDF
HW24246SSHK	\$1,398.00	HW24246GYHK	\$609.00	24.00 x 24.00 x 7.21 [610 x 610 x 183]	PDF
HW24248SSHK	\$1,489.00	HW24248GYHK	\$639.00	24.00 x 24.00 x 9.21 [610 x 610 x 234]	PDF
HW242412SSHK	\$1,690.00	HW242412GYHK	\$701.00	24.00 x 24.00 x 13.21 [610 x 610 x 336]	PDF
HW24308SSHK	\$1,864.00	HW24308GYHK	\$715.00	24.00 x 30.00 x 9.21 [610 x 762 x 234]	PDF
HW30208SSHK	\$1,553.00	HW30208GYHK	\$678.00	30.00 x 20.00 x 9.21 [762 x 508 x 234]	PDF
HW30248SSHK	\$1,690.00	HW30248GYHK	\$715.00	30.00 x 24.00 x 9.21 [762 x 610 x 234]	PDF
HW302410SSHK	\$1,899.00	HW302410GYHK	\$750.00	30.00 x 24.00 x 11.21 [762 x 610 x 285]	PDF
HW302412SSHK	\$1,915.00	HW302412GYHK	\$784.00	30.00 x 24.00 x 13.21 [762 x 610 x 336]	PDF
HW302416SSHK	\$2,237.00	HW302416GYHK	\$875.00	30.00 x 24.00 x 17.21 [762 x 610 x 437]	PDF
HW30308SSHK	\$1,928.00	HW30308GYHK	\$799.00	30.00 x 30.00 x 9.21 [762 x 762 x 234]	PDF
HW36248SSHK	\$1,890.00	HW36248GYHK	\$786.00	36.00 x 24.00 x 9.21 [914 x 610 x 234]	PDF
HW362410SSHK	\$2,064.00	HW362410GYHK	\$824.00	36.00 x 24.00 x 11.21 [914 x 610 x 285]	PDF
HW36308SSHK	\$2,165.00	HW36308GYHK	\$883.00	36.00 x 30.00 x 9.21 [914 x 762 x 234]	PDF
HW363010SSHK	\$2,300.00	HW363010GYHK	\$926.00	36.00 x 30.00 x 11.21 [914 x 762 x 285]	PDF
HW363012SSHK	\$2,442.00	HW363012GYHK	\$968.00	36.00 x 30.00 x 13.21 [914 x 762 x 336]	PDF
HW363016SSHK	\$2,796.00	HW363016GYHK	\$1,083.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]	PDF
HW363612SSHK	\$2,743.00	HW363612GYHK	\$1,089.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]	PDF
HW423010SSHK	\$2,514.00	HW423010GYHK	\$1,044.00	42.00 x 30.00 x 11.21 [1067 x 762 x 285]	PDF
HW42368SSHK	\$3,131.00	HW42368GYHK	\$996.00	42.00 x 36.00 x 9.21 [1067 x 914 x 234]	PDF
HW423612SSHK	\$3,040.00	HW423612GYHK	\$1,196.00	42.00 x 36.00 x 13.21 [1067 x 914 x 336]	PDF
HW48368SSHK	\$2,988.00	HW48368GYHK	\$1,178.00	48.00 x 36.00 x 9.21 [1219 x 914 x 234]	PDF
HW483610SSHK	\$3,331.00	HW483610GYHK	\$1,232.00	48.00 x 36.00 x 11.21 [1219 x 914 x 285]	PDF
HW483612SSHK	\$3,341.00	HW483612GYHK	\$1,287.00	48.00 x 36.00 x 13.21 [1219 x 914 x 336]	PDF
HW483616SSHK	\$3,691.00	HW483616GYHK	\$1,397.00	48.00 x 36.00 x 17.21 [1219 x 914 x 437]	PDF
HW603612SSHK	\$3,942.00	HW603612GYHK	\$1,517.00	60.00 x 36.00 x 13.21 [1524 x 914 x 336]	PDF
HW603616SSHK	\$4,548.00	HW603616GYHK	\$1,685.00	60.00 x 36.00 x 17.21 [1524 x 914 x 437]	PDF

Note: Dimensions in inches [millimeters].

NEMA 3, 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 3-Point Handle



Dimensions

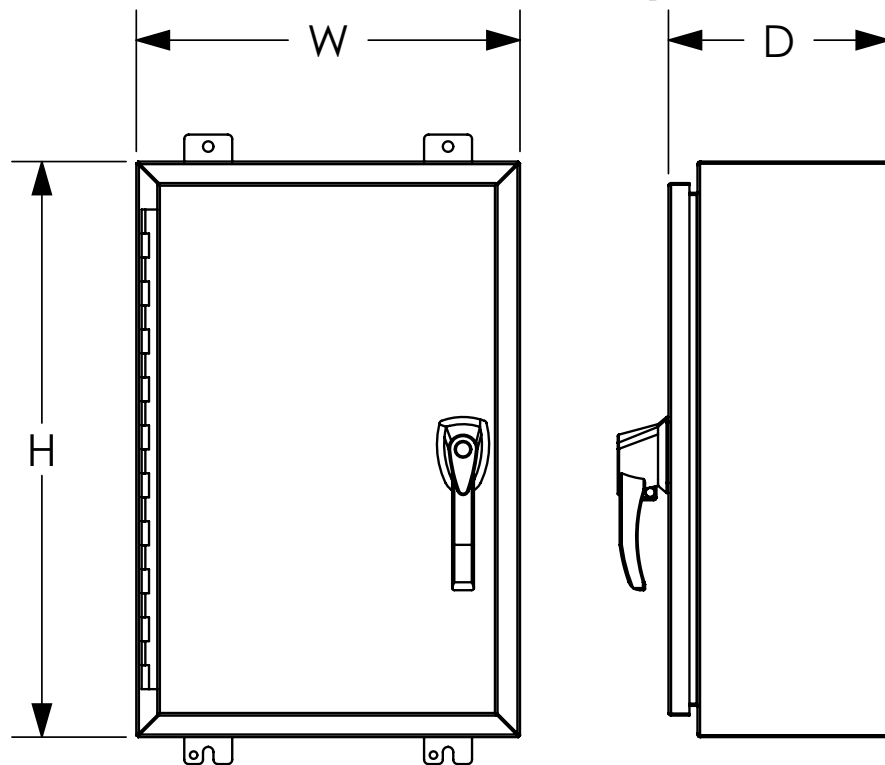

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF