

# NEMA 3R, 4, and 12 Two-Door Floor-Mount with 3-Point Handle



## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

## Construction

- Enclosures are formed steel — 12-gauge (60 in [1524 mm] high) or combination 10/12-gauge ( 72 in [1829 mm] high).
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Lifting eyes provide for easy enclosure handling.
- Doors are supported with heavy gauge continuous hinges.
- 3-point padlocking door handle.
- Uses 1/4 turn latch handles.
- Seamless poured-in-place gasket.
- Provision for light kit mounting.
- A grounding stud is provided in the enclosure and a bonding stud is provided on the door.
- Center post is removable for easy installation of the subpanel.
- 12 in [305 mm] floor stands are welded to the enclosure.
- Body stiffeners are provided in the larger enclosures for extra rigidity.
- Formed lip on door and top of enclosure opening exclude flowing liquids and contaminants.
- A removable 10-gauge subpanel is included.
- Panel supports are provided for easy panel installation.
- Collar studs are provided for mounting subpanels.
- A literature pocket is provided for the inside of the door.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

## Listings

- UL 508A Type 3R, 4, and 12 [UL File E63424]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3, 3R, 4, and 12
  - IEC 60529, IP66



## NEMA 3R, 4, and 12 Two-Door Floor-Mount with 3-Point Handle


| Part Number                 | Price      | Enclosure Size HxWxD                      | Subpanel Size HxW           | Drawing Link        |
|-----------------------------|------------|---|-----------------------------|---------------------|
| <a href="#">HN4FM604810</a> | \$3,761.00 | 60.13 x 48.06 x 11.88 [1527 x 1221 x 302] | 56.00 x 44.00 [1422 x 1118] | <a href="#">PDF</a> |
| <a href="#">HN4FM604818</a> | \$4,125.00 | 60.13 x 48.06 x 19.88 [1527 x 1221 x 505] | 56.00 x 44.00 [1422 x 1118] | <a href="#">PDF</a> |
| <a href="#">HN4FM606012</a> | \$4,386.00 | 60.13 x 60.06 x 13.88 [1527 x 1526 x 353] | 56.00 x 56.00 [1422 x 1422] | <a href="#">PDF</a> |
| <a href="#">HN4FM606018</a> | \$4,751.00 | 60.13 x 60.06 x 19.88 [1527 x 1526 x 505] | 56.00 x 56.00 [1422 x 1422] | <a href="#">PDF</a> |
| <a href="#">HN4FM726012</a> | \$4,910.00 | 72.13 x 60.06 x 13.88 [1832 x 1526 x 353] | 68.00 x 56.00 [1727 x 1422] | <a href="#">PDF</a> |
| <a href="#">HN4FM726018</a> | \$5,275.00 | 72.13 x 60.06 x 19.88 [1832 x 1526 x 505] | 68.00 x 56.00 [1727 x 1422] | <a href="#">PDF</a> |
| <a href="#">HN4FM727212</a> | \$5,523.00 | 72.13 x 72.06 x 13.88 [1832 x 1830 x 353] | 68.00 x 68.00 [1727 x 1727] | <a href="#">PDF</a> |
| <a href="#">HN4FM727218</a> | \$5,887.00 | 72.13 x 72.06 x 19.88 [1832 x 1830 x 505] | 68.00 x 68.00 [1727 x 1727] | <a href="#">PDF</a> |
| <a href="#">HN4FM727224</a> | \$6,340.00 | 72.13 x 72.06 x 26.12 [1832 x 1830 x 663] | 68.00 x 68.00 [1727 x 1727] | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, and 12 Two-Door Floor-Mount with 3-Point Handle



## Dimensions

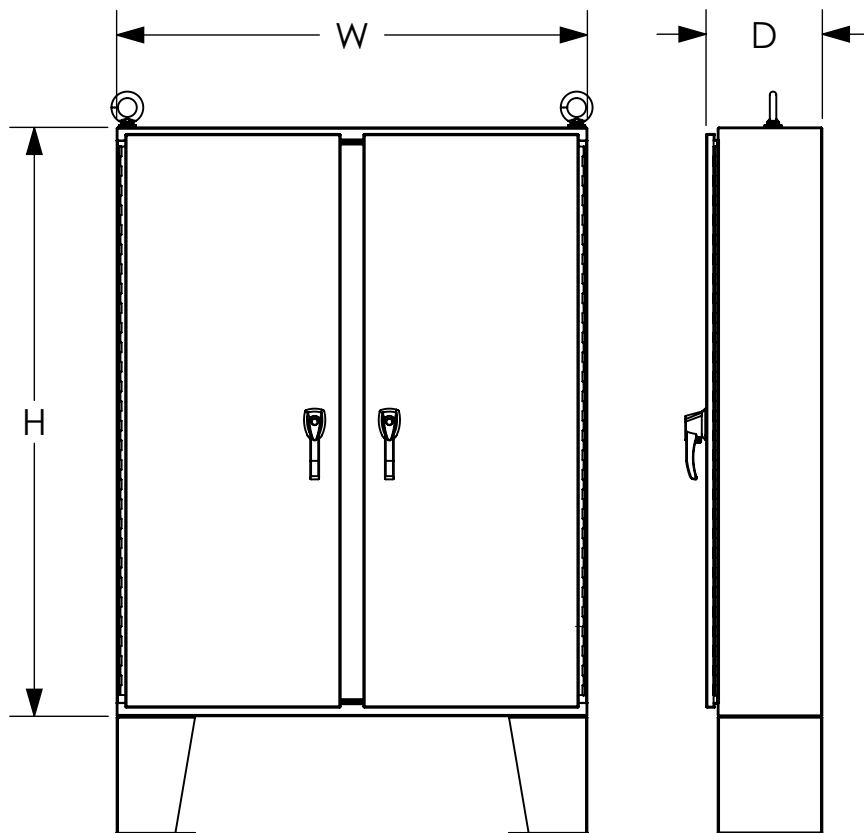

# Enclosure Accessories

## Locks and Latches



### 1/4-Turn Latch Handles



#### Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

| 1/4-Turn Latch Handles  |          |                                       |              |                     |             |  |                     |
|-------------------------|----------|---------------------------------------|--------------|---------------------|-------------|--|---------------------|
| Part Number             | Price    | Security Type                         | Latch Points | Material            | Finish      | For Use With These Hammond Enclosures Only | Drawing Link        |
| <a href="#">MHK1</a>    | \$127.00 | padlocking                            | 1            | die-cast zinc       | black matte | single-door NEMA 4 and NEMA 12             | <a href="#">PDF</a> |
| <a href="#">MHKD1</a>   | \$133.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL1</a>   | \$144.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHK2</a>    | \$217.00 | padlocking                            | 3            | die-cast zinc       | black matte | less than 60in (H) NEMA 4 and NEMA 12      | <a href="#">PDF</a> |
| <a href="#">MHKD2</a>   | \$228.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL2</a>   | \$246.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHK3</a>    | \$221.00 | padlocking                            | 3            | die-cast zinc       | black matte | 60in (H) or greater NEMA 4 and NEMA 12     | <a href="#">PDF</a> |
| <a href="#">MHKD3</a>   | \$232.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL3</a>   | \$251.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHK1SS</a>  | \$234.00 | padlocking                            | 1            | 316 stainless steel | #4 brush    | single-door NEMA 4X                        | <a href="#">PDF</a> |
| <a href="#">MHKD1SS</a> | \$258.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL1SS</a> | \$258.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHK2SS</a>  | \$249.00 | padlocking                            | 3            | 316 stainless steel | #4 brush    | less than 60in (H) NEMA 4X                 | <a href="#">PDF</a> |
| <a href="#">MHKD2SS</a> | \$274.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL2SS</a> | \$274.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHK3SS</a>  | \$362.00 | padlocking                            | 3            | 316 stainless steel | #4 brush    | 60in (H) or greater NEMA 4X                | <a href="#">PDF</a> |
| <a href="#">MHKD3SS</a> | \$398.00 | padlocking with defeater              |              |                     |             |  | <a href="#">PDF</a> |
| <a href="#">MHKL3SS</a> | \$398.00 | combination keylocking/<br>padlocking |              |                     |             |  | <a href="#">PDF</a> |