
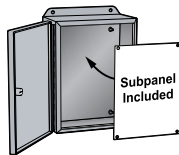


NEMA 3R, 4, and 12 Two-Door Wall-Mount

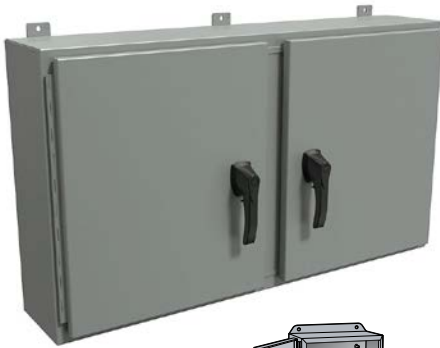

Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

Construction

- Formed 12-gauge steel
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Doors are supported with heavy gauge continuous hinges.
- 3-point padlocking door handle.
- Uses 1/4 turn latch handles.
- Seamless poured-in-place gasket.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.
- Center post is removable for easy installation of the subpanel.

Finish

- Cover and enclosure are phosphatized and finished in recoatable smooth ANSI 61 gray powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 3R, 4, and 12 [UL File E65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 12, and 13
 - IEC 60529, IP66



NEMA 3R, 4, and 12 Two-Door Wall-Mount


Part Number	Price	Enclosure Size HxWxD	Optional Subpanels					Drawing Link
			Painted (included)	Aluminum	Galvanized	Stainless	Size HxW	
HN4WM24428GY	\$1,468.00	24.00 x 42.00 x 9.09 [610 x 1067 x 231]	18P3921	—	18G3921	—	39.00 x 21.00 [991 x 533]	PDF
HN4WM24488GY	\$1,601.00	24.00 x 48.00 x 9.09 [610 x 1219 x 231]	18P4521	—	18G4521	—	45.00 x 21.00 [1143 x 533]	PDF
HN4WM304210GY	\$1,780.00	30.00 x 42.00 x 11.09 [762 x 1067 x 282]	18P3927	—	18G3927	18P3927S16	39.00 x 27.00 [991 x 686]	PDF
HN4WM304810GY	\$1,946.00	30.00 x 48.00 x 11.09 [762 x 1219 x 282]	18P4527	—	18G4527	—	45.00 x 27.00 [1143 x 686]	PDF
HN4WM306010GY	\$2,334.00	30.00 x 60.00 x 11.09 [762 x 1524 x 282]	—	—	—	—	—	PDF
HN4WM364212GY	\$2,136.00	36.00 x 42.00 x 13.09 [914 x 1067 x 332]	18P3933	—	18G3933	18P3933S16	39.00 x 33.00 [991 x 838]	PDF
HN4WM364812GY	\$2,286.00	36.00 x 48.00 x 13.09 [914 x 1219 x 332]	18P4533	18A4533	18G4533	18P4533S16	45.00 x 33.00 [1143 x 838]	PDF
HN4WM366012GY	\$2,683.00	36.00 x 60.00 x 13.09 [914 x 1524 x 332]	18P5733	18A5733	18G5733	18P5733S16	57.00 x 33.00 [1448 x 838]	PDF
HN4WM424212GY	\$2,367.00	42.00 x 42.00 x 13.09 [1067 x 1067 x 332]	—	—	—	—	—	PDF
HN4WM424812GY	\$2,599.00	42.00 x 48.00 x 13.09 [1067 x 1219 x 332]	—	—	—	—	—	PDF
HN4WM426012GY	\$3,017.00	42.00 x 60.00 x 13.09 [1067 x 1524 x 332]	—	—	—	—	—	PDF
HN4WM484812GY	\$2,820.00	48.00 x 48.00 x 13.09 [1219 x 1219 x 332]	—	—	—	—	—	PDF

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, and 12 Two-Door Wall-Mount



Dimensions

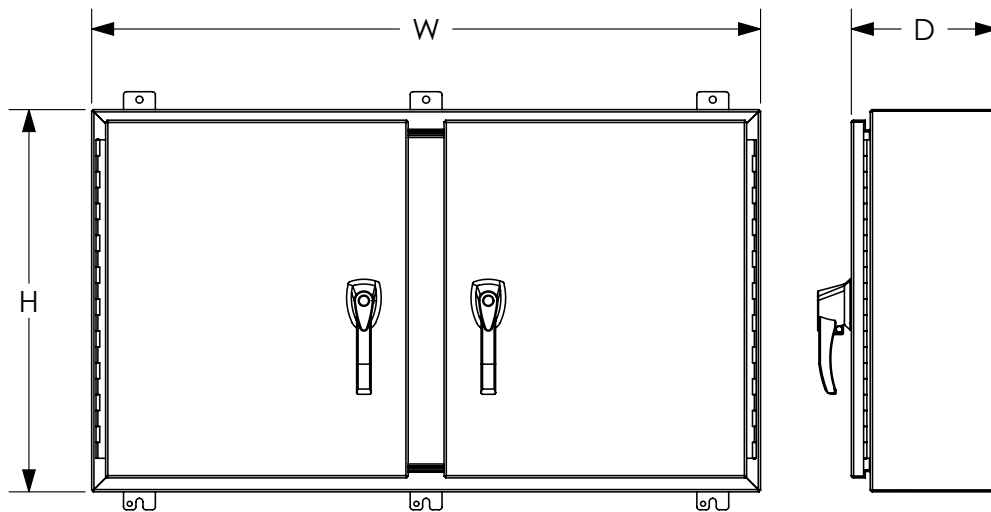

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF