


NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle

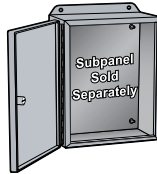

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.
- Ideal for processing plants, utility, outdoor municipal, or petro chemical locations where easy yet secure access is required.

Construction

- Formed 14-gauge steel bodies and doors.
- Continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Powder coated black zinc diecast padlockable handle with 3-point roller latching system secures door.
- Uses 1/4 turn latch handles.
- Door may be removed by pulling the stainless steel hinge pin.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Bonding stud provided on door and grounding stud installed in enclosure.

Finish


- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating interior and exterior.

Listings

- UL 508A Type 3R, 4, and 12 [UL File E63524]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 12, and 13
 - IEC 60529, IP66



Dimensions

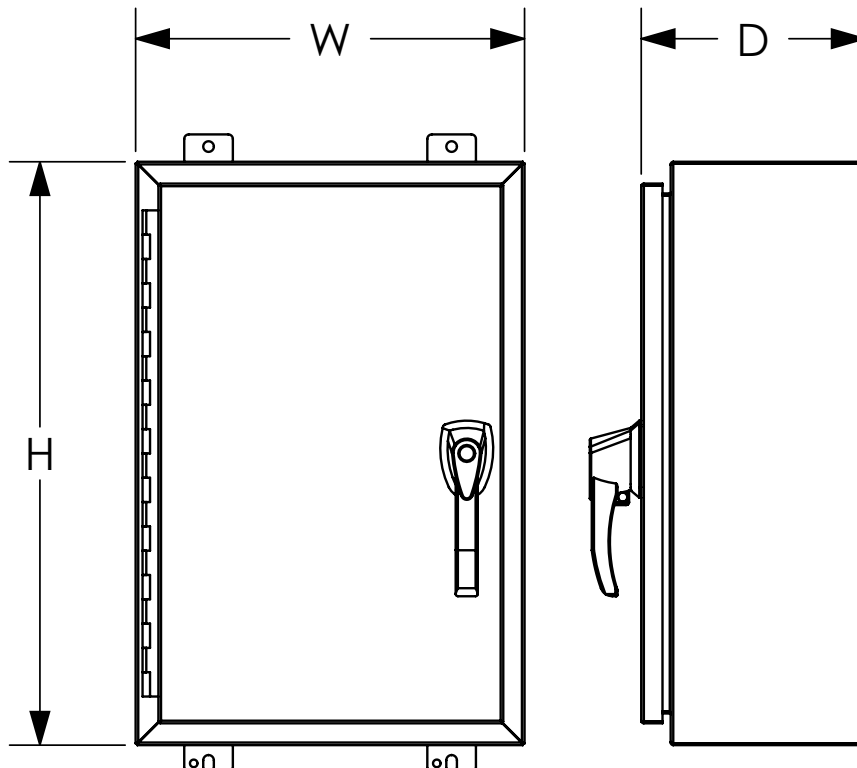

NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle



NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle									
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels					Size HxW	Drawing Link
			Painted	Perforated	Aluminum	Galvanized	Stainless		
HW24168GYHK	\$549.00	24.00 x 16.00 x 9.21 [610 x 406 x 234]	18P2113	—	—	18G2113	18P2113S16	21.00 x 13.00 [533 x 330]	PDF
HW24206GYHK	\$564.00	24.00 x 20.00 x 7.21 [610 x 508 x 183]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00 [533 x 432]	PDF
HW24208GYHK	\$592.00	24.00 x 20.00 x 9.21 [610 x 508 x 234]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00 [533 x 432]	PDF
HW242010GYHK	\$621.00	24.00 x 20.00 x 11.21 [610 x 508 x 285]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00 [533 x 432]	PDF
HW24246GYHK	\$609.00	24.00 x 24.00 x 7.21 [610 x 610 x 183]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF
HW24248GYHK	\$639.00	24.00 x 24.00 x 9.21 [610 x 610 x 234]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF
HW242412GYHK	\$701.00	24.00 x 24.00 x 13.21 [610 x 610 x 336]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF
HW24308GYHK	\$715.00	24.00 x 30.00 x 9.21 [610 x 762 x 234]	18P2721	18P2721PP	18A2721	18G2121	18P2721S16	27.00 x 21.00 [686 x 533]	PDF
HW30208GYHK	\$678.00	30.00 x 20.00 x 9.21 [762 x 508 x 234]	18P2717	—	—	18G2717	18P2717S16	27.00 x 17.00 [686 x 432]	PDF
HW30248GYHK	\$715.00	30.00 x 24.00 x 9.21 [762 x 610 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF
HW302410GYHK	\$750.00	30.00 x 24.00 x 11.21 [762 x 610 x 285]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF
HW302412GYHK	\$784.00	30.00 x 24.00 x 13.21 [762 x 610 x 336]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF
HW302416GYHK	\$875.00	30.00 x 24.00 x 17.21 [762 x 610 x 437]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF
HW30308GYHK	\$799.00	30.00 x 30.00 x 9.21 [762 x 762 x 234]	18P2727	18P2727PP	—	18G2727	18P2727S16	27.00 x 27.00 [686 x 686]	PDF
HW36248GYHK	\$786.00	36.00 x 24.00 x 9.21 [914 x 610 x 234]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00 [838 x 533]	PDF
HW362410GYHK	\$824.00	36.00 x 24.00 x 11.21 [914 x 610 x 285]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00 [838 x 533]	PDF
HW36308GYHK	\$883.00	36.00 x 30.00 x 9.21 [914 x 762 x 234]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00 [838 x 686]	PDF
HW363010GYHK	\$926.00	36.00 x 30.00 x 11.21 [914 x 762 x 285]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00 [838 x 686]	PDF
HW363012GYHK	\$968.00	36.00 x 30.00 x 13.21 [914 x 762 x 336]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00 [838 x 686]	PDF
HW363016GYHK	\$1,083.00	36.00 x 30.00 x 17.21 [914 x 762 x 437]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00 [838 x 686]	PDF
HW363612GYHK	\$1,089.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]	18P3333	18P3333PP	—	18G3333	18P3333S16	33.00 x 33.00 [838 x 838]	PDF
HW423010GYHK	\$1,044.00	42.00 x 30.00 x 11.21 [1067 x 762 x 285]	18P3927	—	—	18G3927	18P3927S16	39.00 x 27.00 [991 x 686]	PDF
HW42368GYHK	\$996.00	42.00 x 36.00 x 9.21 [1067 x 914 x 234]	18P3933	—	—	18G3933	18P3933S16	39.00 x 33.00 [991 x 838]	PDF
HW423612GYHK	\$1,196.00	42.00 x 36.00 x 13.21 [1067 x 914 x 336]	18P3933	—	—	18G3933	18P3933S16	39.00 x 33.00 [991 x 838]	PDF
HW48368GYHK	\$1,178.00	48.00 x 36.00 x 9.21 [1219 x 914 x 234]	18P4533	—	18A4533	18G4533	18P4533S16	45.00 x 33.00 [1143 x 838]	PDF
HW483610GYHK	\$1,232.00	48.00 x 36.00 x 11.21 [1219 x 914 x 285]	18P4533	—	18A4533	18G4533	18P4533S16	45.00 x 33.00 [1143 x 838]	PDF
HW483612GYHK	\$1,287.00	48.00 x 36.00 x 13.21 [1219 x 914 x 336]	18P4533	—	18A4533	18G4533	18P4533S16	45.00 x 33.00 [1143 x 838]	PDF
HW483616GYHK	\$1,397.00	48.00 x 36.00 x 17.21 [1219 x 914 x 437]	18P4533	—	18A4533	18G4533	18P4533S16	45.00 x 33.00 [1143 x 838]	PDF
HW603612GYHK	\$1,517.00	60.00 x 36.00 x 13.21 [1524 x 914 x 336]	18P5733	—	18A5733	18G5733	18P5733S16	57.00 x 33.00 [1448 x 838]	PDF
HW603616GYHK	\$1,685.00	60.00 x 36.00 x 17.21 [1524 x 914 x 437]	18P5733	—	18A5733	18G5733	18P5733S16	57.00 x 33.00 [1448 x 838]	PDF

Note: Dimensions in inches [millimeters].

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF