


# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

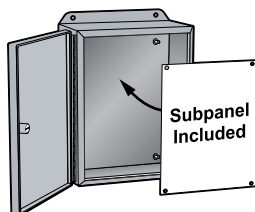

## Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion may be a problem.

## Construction

- Formed from 14-gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Continuous stainless steel hinged cover is secured with stainless steel clamps and screws.
- Seamless poured-in-place gasket.
- All models include a removable 14-gauge subpanel.
- Tapped studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is finished in RAL9003 white powder coating.

## Listings

- UL 508A Type 3R, 4, 4X, 12, and 13 [UL File E65324]
- CSA Type 3R, 4, 4X, 12, and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 4X, 12, and 13
  - IEC 60529, IP66



## NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

| 304 Stainless Steel           | Price    | 316 Stainless Steel            | Price    | Enclosure Size HxWxD                    | Included Subpanel       | Subpanel HxW              | Drawing Link        |
|-------------------------------|----------|--------------------------------|----------|-----------------------------------------|-------------------------|---------------------------|---------------------|
| <a href="#">1414N4PHSSC4</a>  | \$227.00 | <a href="#">1414N4PHS16C4</a>  | \$279.00 | 6.31 x 4.31 x 4.20 [160 x 109 x 107]    | <a href="#">14R0503</a> | 4.88 x 2.88 [124 x 73]    | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSE</a>   | \$248.00 | <a href="#">1414N4PHS16E</a>   | \$313.00 | 6.31 x 6.31 x 4.20 [160 x 160 x 107]    | <a href="#">14R0505</a> | 4.88 x 4.88 [124 x 124]   | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSG</a>   | \$278.00 | <a href="#">1414N4PHS16G</a>   | \$347.00 | 8.31 x 6.31 x 3.70 [211 x 160 x 94]     | <a href="#">14R0705</a> | 6.75 x 4.88 [171 x 124]   | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSG4</a>  | \$282.00 | <a href="#">1414N4PHS16G4</a>  | \$355.00 | 8.31 x 6.31 x 4.20 [211 x 160 x 107]    | <a href="#">14R0705</a> | 6.75 x 4.88 [171 x 124]   | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSI</a>   | \$340.00 | <a href="#">1414N4PHS16I</a>   | \$430.00 | 10.31 x 8.31 x 4.20 [262 x 211 x 107]   | <a href="#">14R0907</a> | 8.75 x 6.88 [222 x 175]   | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSK</a>   | \$473.00 | <a href="#">1414N4PHS16K</a>   | \$600.00 | 12.31 x 10.31 x 5.20 [313 x 262 x 132]  | <a href="#">14R1109</a> | 10.75 x 8.88 [273 x 226]  | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSK6</a>  | \$474.00 | <a href="#">1414N4PHS16K6</a>  | \$602.00 | 12.31 x 10.31 x 6.20 [313 x 262 x 157]  | <a href="#">14R1109</a> | 10.75 x 8.88 [273 x 226]  | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSL6</a>  | \$523.00 | <a href="#">1414N4PHS16L6</a>  | \$664.00 | 12.31 x 12.31 x 6.20 [313 x 313 x 157]  | <a href="#">14R1111</a> | 10.75 x 10.88 [273 x 276] | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSM6</a>  | \$590.00 | <a href="#">1414N4PHS16M6</a>  | \$729.00 | 14.31 x 12.31 x 6.20 [363 x 313 x 157]  | <a href="#">14R1311</a> | 12.75 x 10.88 [324 x 276] | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSM8</a>  | \$617.00 | <a href="#">1414N4PHS16M8</a>  | \$745.00 | 14.31 x 12.31 x 8.20 [363 x 313 x 208]  | <a href="#">14R1311</a> | 12.75 x 10.88 [324 x 276] | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSO6</a>  | \$683.00 | <a href="#">1414N4PHS16O6</a>  | \$867.00 | 16.31 x 14.31 x 6.20 [414 x 363 x 157]  | <a href="#">14R1513</a> | 14.75 x 12.88 [375 x 327] | <a href="#">PDF</a> |
| <a href="#">1414N4PHSSO10</a> | \$770.00 | <a href="#">1414N4PHS16O10</a> | \$947.00 | 16.31 x 14.31 x 10.20 [414 x 363 x 259] | <a href="#">14R1513</a> | 14.75 x 12.88 [375 x 327] | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



## Dimensions

