

NEMA 3R Painted Galvanized Steel Screw Cover Wall-Mount with Knockouts



Applications

- Designed for use as a wiring/junction box.
- Provides protection against rain, sleet, snow and dripping water.

Construction

- Formed and spot welded from 16- or 14-gauge galvanized steel.
- Drip-shield top and seam-free sides, front and back.
- Slip-on removable cover fastened with plated steel screws.
- Embossed mounting holes on back of enclosure.
- Easily removed knockouts on bottom of enclosure. See drawings for sizes and locations.
- Padlocking hasp.

Finish

- Enclosure and cover are finished in ANSI 61 gray powder coating.

Listings

- UL-50 Type 3R [UL File E65324]
- CSA Type 3R [CSA File LR21001]
- Complies with
 - NEMA Type 3R
 - IEC 60529, IP24



NEMA 3R Painted Galvanized Steel Screw Cover Wall-Mount with Knockouts					
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Bottom Knockout Pattern	Door Handles
C3R444SC	\$21.50	4.12 x 4.49 x 4.28 [105 x 114 x 109]	PDF	Y-Z	No
C3R644SC	\$26.00	6.12 x 4.49 x 4.28 [155 x 114 x 109]	PDF	Y-Z	
C3R664SC	\$25.00	6.12 x 6.49 x 4.28 [155 x 165 x 109]	PDF	Y-Z-Y	
C3R666SC	\$32.00	6.12 x 6.49 x 6.28 [155 x 165 x 160]	PDF	Y-Z-Y	
C3R864SC	\$30.50	8.12 x 6.49 x 4.28 [206 x 165 x 109]	PDF	Y-Z-Y	
C3R884SC	\$35.00	8.12 x 8.49 x 4.28 [206 x 216 x 109]	PDF	Y-Z-Y-Z	
C3R886SC	\$39.50	8.12 x 8.49 x 6.28 [206 x 216 x 160]	PDF	Y-Z-Y-Z	
C3R888SC	\$51.50	8.12 x 8.49 x 8.28 [206 x 216 x 210]	PDF	Y-Z-Y-Z	
C3R10104SC	\$43.50	10.12 x 10.49 x 4.28 [257 x 266 x 109]	PDF	Y-Z-Y-Z	
C3R10106SC	\$50.50	10.12 x 10.49 x 6.28 [257 x 266 x 160]	PDF	Y-Z-Y-Z	
C3R1084SC	\$42.00	10.12 x 8.49 x 4.28 [257 x 216 x 109]	PDF	Z-Y-Z-Y-Z	
C3R1086SC	\$50.00	10.12 x 8.49 x 6.28 [257 x 216 x 160]	PDF	Y-Z-Y-Z	
C3R1244SC	\$38.00	12.12 x 4.49 x 4.28 [308 x 114 x 109]	PDF	Y-Z	
C3R1284SC	\$49.50	12.12 x 8.49 x 4.28 [308 x 216 x 109]	PDF	Y-Z-Y-Z	
C3R1286SC	\$56.00	12.12 x 8.49 x 6.28 [308 x 216 x 160]	PDF	Y-Z-Y-Z	
C3R12104SC	\$55.00	12.12 x 10.49 x 4.28 [308 x 266 x 109]	PDF	Z-Y-Z-Y-Z	
C3R12106SC	\$64.00	12.12 x 10.49 x 6.28 [308 x 266 x 160]	PDF	Z-Y-Z-Y-Z	
C3R12124SC	\$54.00	12.12 x 12.49 x 4.28 [308 x 317 x 109]	PDF	Z-Y-Z-Y-Z	
C3R12126SC	\$65.00	12.12 x 12.49 x 6.28 [308 x 317 x 160]	PDF	Z-Y-Z-Y-Z	
C3R12128SC	\$82.00	12.12 x 12.49 x 8.28 [308 x 317 x 210]	PDF	Z-Y-Z-Y-Z	
C3R15126SC	\$89.00	15.12 x 12.49 x 6.28 [384 x 317 x 160]	PDF	Z-Y-Z-Y-Z	
C3R15128SC	\$94.00	15.12 x 12.49 x 8.28 [384 x 317 x 210]	PDF	Z-Y-Z-Y-Z	
C3R16126SC	\$94.00	16.12 x 12.49 x 6.28 [409 x 317 x 160]	PDF	Z-Y-Z-Y-Z	

Note: Dimensions in inches [millimeters].

Table continued on next page

NEMA 3R Painted Galvanized Steel Screw Cover Wall-Mount with Knockouts



Table continued from previous page


NEMA 3R Painted Galvanized Steel Screw Cover Wall-Mount with Knockouts					
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Bottom Knockout Pattern	Door Handles
C3R1866SC	\$85.00	18.12 x 6.49 x 6.28 [460 x 165 x 160]	PDF	Z-Y-Z-Y-Z	No
C3R18124SC	\$88.00	18.12 x 12.49 x 4.28 [460 x 317 x 109]	PDF	Z-Y-Z-Y-Z	
C3R18126SC	\$89.00	18.12 x 12.49 x 6.28 [460 x 317 x 160]	PDF	Y-Z-Y	
C3R18128SC	\$106.00	18.12 x 12.49 x 8.28 [460 x 317 x 210]	PDF	Z-Y-Z-Y-Z	
C3R18184SC	\$125.00	18.12 x 18.49 x 4.28 [460 x 470 x 109]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R18186SC	\$136.00	18.12 x 18.49 x 6.28 [460 x 470 x 160]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R18188SC	\$172.00	18.12 x 18.49 x 8.28 [460 x 470 x 210]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R181810SC	\$174.00	18.17 x 18.52 x 10.32 [462 x 470 x 262]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	Yes
C3R2488SC	\$120.00	24.12 x 8.49 x 8.28 [613 x 216 x 210]	PDF	Y-Z-Y-Z	No
C3R24126SC	\$142.00	24.12 x 12.49 x 6.28 [613 x 317 x 160]	PDF	Z-Y-Z-Y-Z	
C3R24168SC	\$186.00	24.12 x 16.49 x 8.28 [613 x 419 x 210]	PDF	Z-Y-Z-Y-Z	
C3R24186SC	\$181.00	24.12 x 18.49 x 6.28 [613 x 470 x 160]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R24188SC	\$204.00	24.12 x 18.49 x 8.28 [613 x 470 x 210]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R241810SC	\$215.00	24.17 x 18.52 x 10.32 [614 x 470 x 262]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R24208SC	\$213.00	24.12 x 20.49 x 8.28 [613 x 520 x 210]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R24246SC	\$217.00	24.12 x 24.49 x 6.28 [613 x 622 x 160]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	Yes
C3R24248SC	\$237.00	24.17 x 24.52 x 8.32 [614 x 623 x 211]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R242410SC	\$311.00	24.17 x 24.52 x 10.32 [614 x 623 x 262]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R242412SC	\$287.00	24.17 x 24.52 x 12.32 [614 x 623 x 313]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R30248SC	\$287.00	30.17 x 24.52 x 8.32 [766 x 623 x 211]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R302410SC	\$305.00	30.17 x 24.52 x 10.32 [766 x 623 x 262]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R303012SC	\$520.00	30.17 x 30.52 x 12.32 [766 x 775 x 313]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R303016SC	\$536.00	30.17 x 30.52 x 16.32 [766 x 775 x 415]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R363012SC	\$540.00	36.17 x 30.52 x 12.32 [919 x 775 x 313]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	Yes
C3R363612SC	\$684.00	36.17 x 36.52 x 12.32 [919 x 928 x 313]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R48368SC	\$449.00	48.17 x 36.52 x 8.32 [1224 x 928 x 211]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	
C3R483616SC	\$899.00	48.17 x 36.52 x 16.32 [1224 x 928 x 415]	PDF	Z-Y-Z-Y-Z-Y-Z-Y-Z	

Note: Dimensions in inches [millimeters].

NEMA 3R Painted Galvanized Steel Screw Cover Wall-Mount with Knockouts



Dimensions

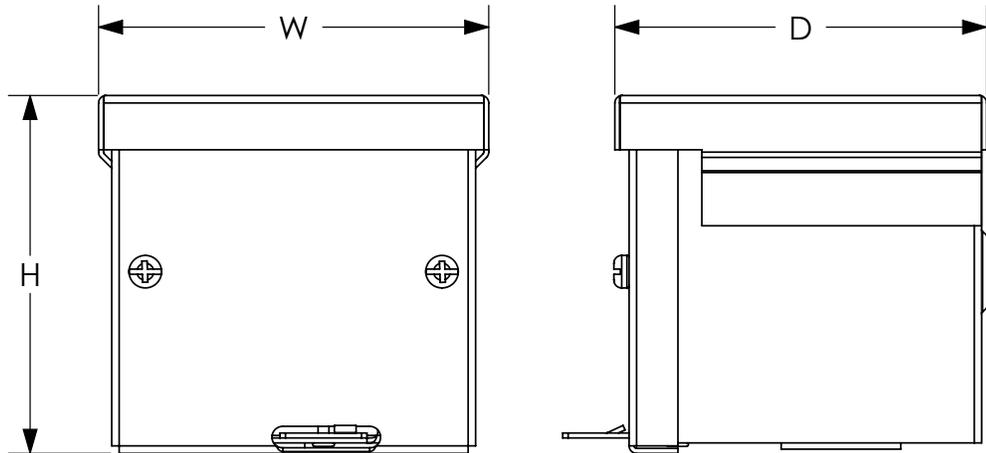

TYPICAL SIZES AND SPACING

SIZE & DISTANCE INFORMATION			
ID	INNER KNOCK-OUT	OUTER KNOCK-OUT	☒ DISTANCE
Y	0.88 ϕ	1.13 ϕ	1.88 TYPICAL
Z	1.13 ϕ	1.38 ϕ	

