


NEMA 4 and 12 Single-Door Wall-Mount

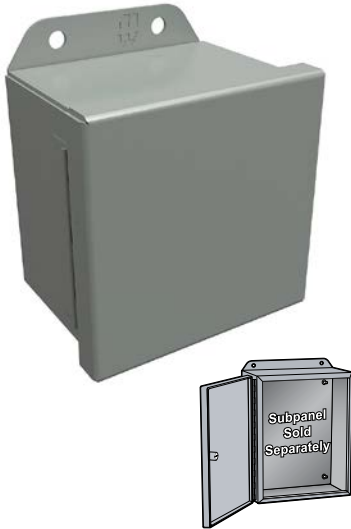

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

Construction

- Body formed from 16-gauge or 14-gauge steel. Covers are formed from 14-gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- 14-gauge welded mounting brackets
- Continuous hinged cover is secured with stainless steel clamps and screws.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin.
- Seamless poured-in-place gasket.
- Internal threaded weld studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

Finish


- Cover and enclosure are phosphatized and finished in smooth ANSI 61 gray recoatable powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 3R, 4, 12, and 13 [UL File E65324]
- CSA Type 3R, 4, 12, and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 12, and 13
 - IEC 60529, IP66 IEC 60529, IP66



Dimensions

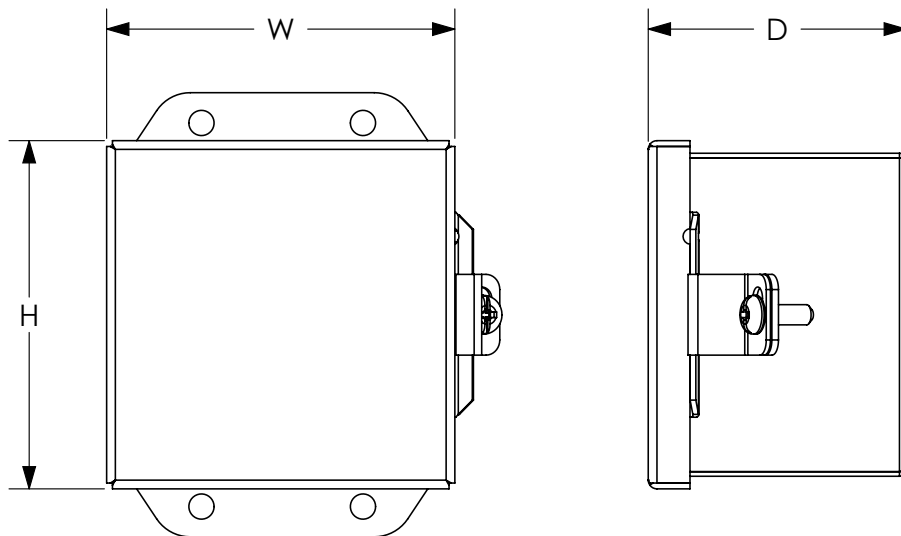

NEMA 4 and 12 Single-Door Wall-Mount



NEMA 4 and 12 Single-Door Wall-Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Drawing Link
			Painted	Aluminum	Galvanized	Stainless	Size HxW	
HJ443HLP	\$55.00	4.31 x 4.31 x 3.20 [109 x 109 x 81]	—	—	—	—	—	PDF
HJ444HLP	\$57.00	4.31 x 4.31 x 4.20 [109 x 109 x 107]	—	—	—	—	—	PDF
HJ643HLP	\$63.00	6.31 x 4.31 x 3.20 [160 x 109 x 81]	14R0503	14A0503	14G0503	14R0503SS	4.88 x 2.88 [124 x 73]	PDF
HJ644HLP	\$67.00	6.31 x 4.31 x 4.20 [160 x 109 x 107]	14R0503	14A0503	14G0503	14R0503SS	4.88 x 2.88 [124 x 73]	PDF
HJ664HLP	\$71.00	6.31 x 6.31 x 4.20 [160 x 160 x 107]	14R0505	14A0505	14G0505	14R0505SS	4.88 x 4.88 [124 x 124]	PDF
HJ683HLP	\$76.00	6.31 x 8.31 x 3.70 [160 x 211 x 94]	14R0705	14A0705	14G0705	14R0705SS	6.75 x 4.88 [171 x 124]	PDF
HJ863HLP	\$76.00	8.31 x 6.31 x 3.70 [211 x 160 x 94]	14R0705	14A0705	14G0705	14R0705SS	6.75 x 4.88 [171 x 124]	PDF
HJ884HLP	\$87.00	8.31 x 8.31 x 4.20 [211 x 211 x 107]	14R0707	14A0707	14G0707	14R0707SS	6.75 x 6.88 [171 x 175]	PDF
HJ866HLP	\$91.00	8.31 x 6.31 x 6.20 [211 x 160 x 157]	14R0705	14A0705	14G0705	14R0705SS	6.75 x 4.88 [171 x 124]	PDF
HJ1084HLP	\$96.00	10.31 x 8.31 x 4.20 [262 x 211 x 107]	14R0907	14A0907	14G0907	14R0907SS	8.75 x 6.88 [222 x 175]	PDF
HJ1264HLP	\$96.00	12.31 x 6.31 x 4.20 [313 x 160 x 107]	14R1105	14A1105	14G1105	—	10.75 x 4.88 [273 x 124]	PDF
HJ8104HLP	\$95.00	8.31 x 10.31 x 4.20 [211 x 262 x 107]	14R0907	14A0907	14G0907	14R0907SS	8.75 x 6.88 [222 x 175]	PDF
HJ1086HLP	\$110.00	10.31 x 8.31 x 6.20 [262 x 211 x 157]	14R0907	14A0907	14G0907	14R0907SS	8.75 x 6.88 [222 x 175]	PDF
HJ10106HLP	\$119.00	10.31 x 10.31 x 6.20 [262 x 262 x 157]	14R0909	14A0909	14G0909	14R0909SS	8.75 x 8.88 [222 x 226]	PDF
HJ10125HLP	\$122.00	10.31 x 12.31 x 5.20 [262 x 313 x 132]	14R1109	14A1109	14G1109	14R1109SS	10.75 x 8.88 [273 x 226]	PDF
HJ12105HLP	\$123.00	12.31 x 10.31 x 5.20 [313 x 262 x 132]	14R1109	14A1109	14G1109	14R1109SS	10.75 x 8.88 [273 x 226]	PDF
HJ1486HLP	\$131.00	14.31 x 8.31 x 6.20 [363 x 211 x 157]	14R1307	14A1307	14G1307	—	12.75 x 6.88 [324 x 175]	PDF
HJ12126HLP	\$143.00	12.31 x 12.31 x 6.20 [313 x 313 x 157]	14R1111	14A1111	14G1111	14R1111SS	10.75 x 10.88 [273 x 276]	PDF
HJ12108HLP	\$150.00	12.31 x 10.31 x 8.20 [313 x 262 x 208]	14R1109	14A1109	14G1109	14R1109SS	10.75 x 8.88 [273 x 226]	PDF
HJ12146HLP	\$153.00	12.31 x 14.31 x 6.20 [313 x 363 x 157]	14R1311	14A1311	14G1311	14R1311SS	12.75 x 10.88 [324 x 276]	PDF
HJ14126HLP	\$154.00	14.31 x 12.31 x 6.20 [363 x 313 x 157]	14R1311	14A1311	14G1311	14R1311SS	12.75 x 10.88 [324 x 276]	PDF
HJ16106HLP	\$156.00	16.31 x 10.31 x 6.20 [414 x 262 x 157]	14R1509	14A1509	14G1509	—	14.75 x 8.88 [375 x 226]	PDF
HJ14128HLP	\$176.00	14.31 x 12.31 x 8.20 [363 x 313 x 208]	14R1311	14A1311	14G1311	14R1311SS	12.75 x 10.88 [324 x 276]	PDF
HJ14166HLP	\$180.00	14.31 x 16.31 x 6.20 [363 x 414 x 157]	14R1513	14A1513	14G1513	14R1513SS	14.75 x 12.88 [375 x 327]	PDF
HJ16146HLP	\$182.00	16.31 x 14.31 x 6.20 [414 x 363 x 157]	14R1513	14A1513	14G1513	14R1513SS	14.75 x 12.88 [375 x 327]	PDF
HJ16148HLP	\$201.00	16.31 x 14.31 x 8.20 [414 x 363 x 208]	14R1513	14A1513	14G1513	14R1513SS	14.75 x 12.88 [375 x 327]	PDF
HJ161410HLP	\$227.00	16.31 x 14.31 x 10.20 [414 x 363 x 259]	14R1513	14A1513	14G1513	14R1513SS	14.75 x 12.88 [375 x 327]	PDF

Note: Dimensions in inches [millimeters].