

# NEMA 4 and 4X Stainless Steel Pushbutton Wall-Mount



## Applications

- Designed to accept standard heavy duty oil-tight pushbuttons, switches and pilot lights.
- Provides protection from dirt, dust, oil and large amounts of water from any angle, or where highly corrosive conditions exist.

## Construction

- Smooth continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Captive stainless steel cover screws thread into sealed wells.
- Larger enclosures provide internally hinged removable covers, designed to hold the cover open during wiring.
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door, and a grounding stud is provided on the enclosure.

## Finish

- Natural stainless steel with a #4 smooth brushed finish.

## Listings

- UL 508A Type 4 and 4X [UL File E65324]
- CSA Type 4 and 4X [CSA File R21001]
- Complies with
  - NEMA Type 3R, 4 and 4X
  - IEC 60529, IP66
- All appropriate components are required to maintain these standards.





NEMA 4 and 4X Stainless Steel Pushbutton Wall-Mount												
304 Stainless Steel				316 Stainless Steel				Size HxWxD	Drawing Link	# Holes	Steel Gauge	Hinged
22 mm	Price	30 mm	Price	22 mm	Price	30 mm	Price					
<a href="#">1435MSSA</a>	\$176.00	<a href="#">1435SSA</a>	\$173.00	<a href="#">1435MS16A</a>	\$220.00	<a href="#">1435S16A</a>	\$218.00	3.81 x 3.56 x 2.91 [97 x 90 x 74]	<a href="#">PDF</a>	1	16	No
<a href="#">1435MSSB</a>	\$207.00	<a href="#">1435SSB</a>	\$204.00	<a href="#">1435MS16B</a>	\$260.00	<a href="#">1435S16B</a>	\$258.00	6.06 x 3.56 x 2.91 [154 x 90 x 74]	<a href="#">PDF</a>	2		
<a href="#">1435MSSC</a>	\$240.00	<a href="#">1435SSC</a>	\$235.00	<a href="#">1435MS16C</a>	\$301.00	<a href="#">1435S16C</a>	\$297.00	8.31 x 3.56 x 2.92 [211 x 90 x 74]	<a href="#">PDF</a>	3		
<a href="#">1435MSSD</a>	\$271.00	<a href="#">1435SSD</a>	\$274.00	<a href="#">1435MS16D</a>	\$341.00	<a href="#">1435S16D</a>	\$337.00	10.56 x 3.56 x 2.92 [268 x 90 x 74]	<a href="#">PDF</a>	4		
<a href="#">1435MSSH</a>	\$364.00	<a href="#">1435SSH</a>	\$359.00	<a href="#">1435MS16H</a>	\$450.00	<a href="#">1435S16H</a>	\$444.00	9.81 x 6.56 x 3.22 [249 x 167 x 82]	<a href="#">PDF</a>	6	14	Yes
<a href="#">1435MSSK</a>	\$430.00	<a href="#">1435SSK</a>	\$424.00	<a href="#">1435MS16K</a>	\$534.00	<a href="#">1435S16K</a>	\$527.00	9.81 x 8.81 x 3.22 [249 x 224 x 82]	<a href="#">PDF</a>	9		
<a href="#">1435MSSO</a>	\$492.00	<a href="#">1435SSO</a>	\$486.00	<a href="#">1435MS16O</a>	\$611.00	<a href="#">1435S16O</a>	\$602.00	12.06 x 8.81 x 3.22 [306 x 224 x 82]	<a href="#">PDF</a>	12		
Note: Dimensions in inches [millimeters].												

# NEMA 4 and 4X Stainless Steel Pushbutton Wall-Mount



## Dimensions


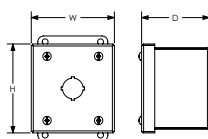
 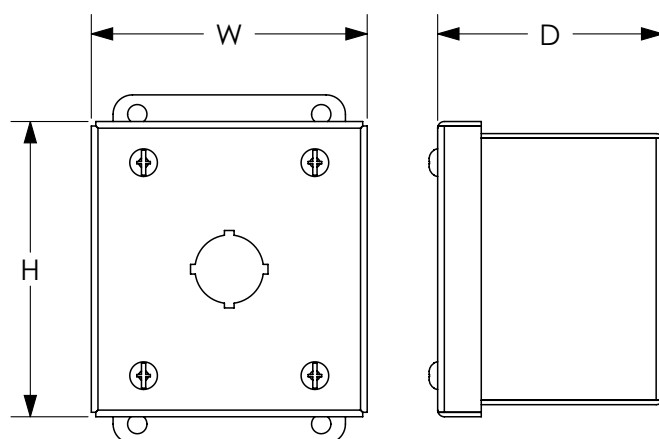


1

2

3

4

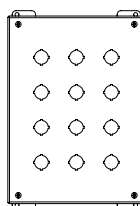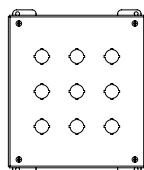

6

9

12