





# Potable Water Push-to-Connect Fittings

HydroMode push-to-connect union straight reducer fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

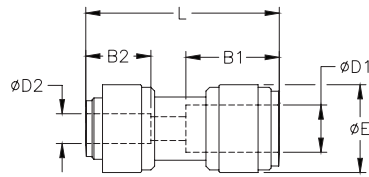

| HydroMode™ Union Straight Reducer                                  |         |                    |            |            |      |      |      |      |                      |               |
|--------------------------------------------------------------------|---------|--------------------|------------|------------|------|------|------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |         |                    |            |            |      |      |      |      |                      |               |
| Part No.                                                           | Price   | Size (inch)        | ØD1 (inch) | ØD2 (inch) | B1   | B2   | ØE   | L    | Package Weight (lbs) | Qty. per pack |
| <a href="#">UR516-14-P</a>                                         | \$8.50  | 5/16 in. x 1/4 in. | 5/16       | 1/4        | 17.5 | 16.9 | 17.6 | 36.8 | 0.1                  | 5             |
| <a href="#">UR38-14-P</a>                                          | \$11.00 | 3/8 in. x 1/4 in.  | 3/8        | 1/4        | 20.2 | 16.9 | 20.0 | 42.1 | 0.1                  | 5             |
| <a href="#">UR38-516-P</a>                                         | \$10.00 | 3/8 in. x 5/16 in. | 3/8        | 5/16       | 20.2 | 17.5 | 20.0 | 42.5 | 0.1                  | 5             |
| <a href="#">UR12-516-P</a>                                         | \$11.50 | 1/2 in. x 5/16 in. | 1/2        | 5/16       | 25.1 | 17.5 | 23.6 | 52.0 | 0.2                  | 5             |
| <a href="#">UR12-38-P</a>                                          | \$12.00 | 1/2 in. x 3/8 in.  | 1/2        | 3/8        | 25.1 | 25.1 | 23.6 | 52.4 | 0.2                  | 5             |

HydroMode push-to-connect union cap fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

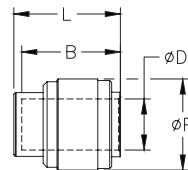

| HydroMode™ Union Cap                                               |        |             |           |      |      |      |                      |               |
|--------------------------------------------------------------------|--------|-------------|-----------|------|------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |        |             |           |      |      |      |                      |               |
| Part No.                                                           | Price  | Size (inch) | ØD (inch) | ØP   | B    | L    | Package Weight (lbs) | Qty. per pack |
| <a href="#">UC14-P</a>                                             | \$8.25 | 1/4 in.     | 1/4       | 15.5 | 16.9 | 18.9 | 0.1                  | 5             |
| <a href="#">UC516-P</a>                                            | \$8.25 | 5/16 in.    | 5/16      | 17.6 | 17.5 | 19.5 | 0.1                  | 5             |
| <a href="#">UC38-P</a>                                             | \$8.50 | 3/8 in.     | 3/8       | 20.0 | 20.2 | 22.2 | 0.1                  | 5             |

# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect fittings are designed to work with potable water and beverages. Installing or removing flexible tubing is quick and easy. All fittings are made of NSF approved materials with NSF-51® and NSF-61® certifications. The body and collet of the fittings are made from polyoxymethylene (POM) also known as acetal, while the o-rings are made from ethylene propylene diene monomer (EPDM) which is a type of synthetic rubber.

## Features

- Designed for potable water and beverages
- NSF-51 and NSF-61 certified
- Easy tubing installation and removal
- Optional retaining clips prevent accidental tube removal
- Fittings rated for up to 145psi at 70°C (158°F)



*Push-to-Connect Fitting  
Cut-away Diagram*