

# Polycarbonate Enclosures – Premium Series

## Subpanels and Swing-Out Panels



### Construction

- Subpanels available in aluminum, PVC, and steel with white powder coat finish
- Swing-out panels available in aluminum
- Mounting hardware included
- Use the Adjustable Depth Subpanel Mounting Kit with any subpanel to create a dead-front panel with adjustable depth
- Mounting screw torque - 10 to 15 lb-in
- Aluminum panels are 0.063in [1.6mm] thick
- Painted steel panels are 0.075in [1.9mm] thick
- PVC panels are 0.187in [4.7mm] thick

### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Premium Series – Polycarbonate Enclosures – Subpanels

| Aluminum                     | Price   | PVC                            | Price    | Aluminum and PVC Dimensions HxW | Painted Steel                | Price    | Painted Steel Dimensions HxW | For Use With     | Drawing Link        |
|------------------------------|---------|--------------------------------|----------|---------------------------------|------------------------------|----------|------------------------------|------------------|---------------------|
| <a href="#">ABP66-P10</a>    | \$17.00 | <a href="#">PVCBP66-P10</a>    | \$22.00  | 4.88 x 4.88 [124 x 124]         | <a href="#">SBP66-P10</a>    | \$38.50  | 4.88 x 4.88 [124 x 124]      | H606 enclosures  | <a href="#">PDF</a> |
| <a href="#">ABP86-P10</a>    | \$19.75 | <a href="#">PVCBP86-P10</a>    | \$25.00  | 6.75 x 4.88 [171 x 124]         | <a href="#">SBP86-P10</a>    | \$43.00  | 6.88 x 4.88 [175 x 124]      | H806 enclosures  | <a href="#">PDF</a> |
| <a href="#">ABP88-P10</a>    | \$22.50 | <a href="#">PVCBP88-P10</a>    | \$28.50  | 6.88 x 6.75 [175 x 171]         | <a href="#">SBP88-P10</a>    | \$44.00  | 6.88 x 6.88 [175 x 175]      | H808 enclosures  | <a href="#">PDF</a> |
| <a href="#">ABP108-P10</a>   | \$28.00 | <a href="#">PVCBP108-P10</a>   | \$35.00  | 8.75 x 6.88 [222 x 175]         | <a href="#">SBP108-P10</a>   | \$49.00  | 8.88 x 6.88 [226 x 175]      | H1008 enclosures | <a href="#">PDF</a> |
| <a href="#">ABP1210-P10</a>  | \$32.50 | <a href="#">PVCBP1210-P10</a>  | \$40.00  | 10.75 x 8.88 [273 x 226]        | <a href="#">SBP1210-P10</a>  | \$59.00  | 10.88 x 8.88 [276 x 226]     | H1210 enclosures | <a href="#">PDF</a> |
| <a href="#">ABP-1412-P10</a> | \$48.50 | <a href="#">PVCBP-1412-P10</a> | \$57.00  | 12.75 x 10.88 [324 x 276]       | <a href="#">SBP-1412-P10</a> | \$75.00  | 12.75 x 10.88 [324 x 276]    | H1412 enclosures | <a href="#">PDF</a> |
| <a href="#">ABP-1614-P10</a> | \$56.00 | <a href="#">PVCBP-1614-P10</a> | \$74.00  | 14.75 x 12.88 [375 x 327]       | <a href="#">SBP-1614-P10</a> | \$91.00  | 14.75 x 12.88 [375 x 327]    | H1614 enclosures | <a href="#">PDF</a> |
| <a href="#">ABP-1816-P10</a> | \$76.00 | <a href="#">PVCBP-1816-P10</a> | \$110.00 | 16.75 x 14.88 [425 x 378]       | <a href="#">SBP-1816-P10</a> | \$106.00 | 16.75 x 14.88 [425 x 378]    | H1816 enclosures | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

### Premium Series – Polycarbonate Enclosures – Swing-Out Panels

| Aluminum                          | Price    | Dimension HxW             | For Use With               | Drawing Link        |
|-----------------------------------|----------|---------------------------|----------------------------|---------------------|
| <a href="#">ABP-66USOPK-P10</a>   | \$49.00  | 4.92 x 4.92 [125 x 125]   | H606 enclosures            | <a href="#">PDF</a> |
| <a href="#">ABP-86USOPK-P10</a>   | \$52.00  | 6.75 x 4.87 [171 x 124]   | H806 enclosures            | <a href="#">PDF</a> |
| <a href="#">ABP-88USOPK-P10</a>   | \$55.00  | 6.75 x 6.87 [171 x 174]   | H808 enclosures            | <a href="#">PDF</a> |
| <a href="#">ABP-108USOPK-P10</a>  | \$60.00  | 8.75 x 6.88 [222 x 175]   | H1008 and P1008 enclosures | <a href="#">PDF</a> |
| <a href="#">ABP-1210USOPK-P10</a> | \$65.00  | 10.88 x 8.88 [276 x 226]  | H1210 enclosures           | <a href="#">PDF</a> |
| <a href="#">ABP-1412USOPK-P10</a> | \$80.00  | 12.75 x 10.88 [324 x 276] | H1412 enclosures           | <a href="#">PDF</a> |
| <a href="#">ABP-1614USOPK-P10</a> | \$88.00  | 14.75 x 12.88 [375 x 327] | H1614 enclosures           | <a href="#">PDF</a> |
| <a href="#">ABP-1816USOPK-P10</a> | \$108.00 | 16.75 x 14.88 [425 x 378] | H1816 enclosures           | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

### Premium Series – Polycarbonate Enclosures – Adjustable Depth Subpanel Mounting Kit

| Part Number                | Price   | Includes                     |
|----------------------------|---------|------------------------------|
| <a href="#">BPAKG-P10</a>  | \$24.50 | 4 brackets with set screws   |
| <a href="#">UBPAKG-P10</a> | \$28.00 | 4 brackets with thumb screws |

Note: Also fits P1008 Impact series enclosures.



UBPAKG-P10





BPAKG-P10



# Polycarbonate Enclosures – Premium Series



## Dimensions

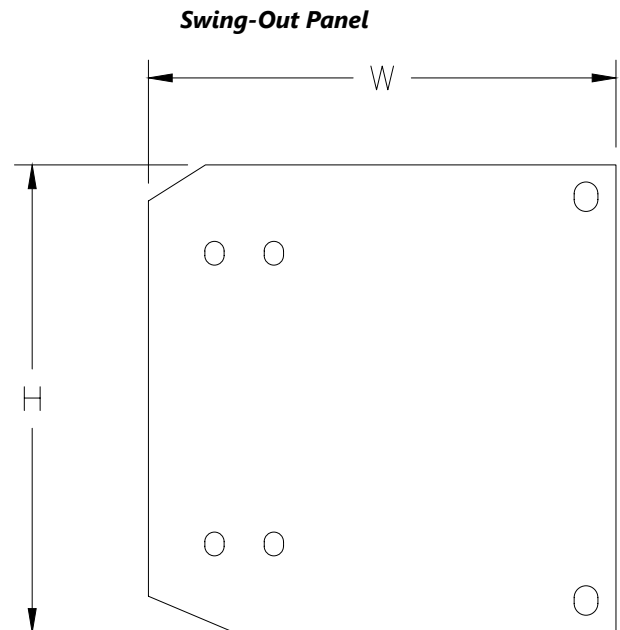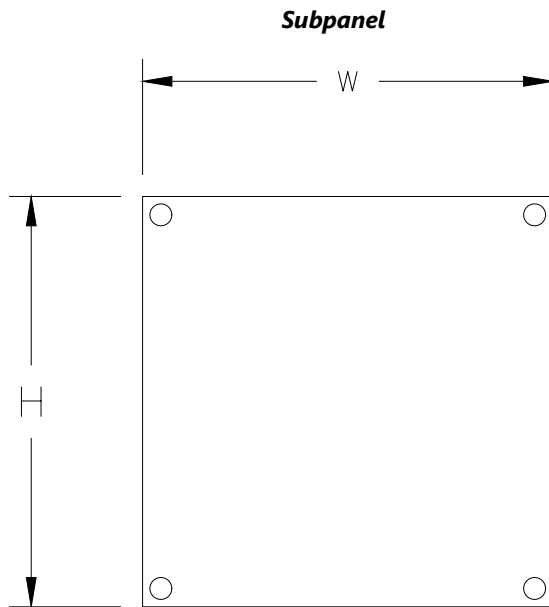

# Polycarbonate Enclosures

## Pole-Mounting Kits



### Construction

- All kits include galvanized steel strut rails and plated steel fasteners
- Kits for 9.5 to 12 in [241 to 305 mm] diameter poles include galvanized steel band clamps and brackets. All other kits include galvanized steel pipe clamps



### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Pole Mounting Kits for Integra Premium Series Enclosures

| Part Number                      | Price   | Pole Diameter                  | Kit Includes  | For Use With Enclosure Width |
|----------------------------------|---------|--------------------------------|---|------------------------------|
| <a href="#">PMKG-26-P10</a>      | \$56.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-36-P10</a>      | \$68.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-46-P10</a>      | \$70.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-126-P10</a>     | \$87.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-28-P10</a>      | \$61.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-38-P10</a>      | \$68.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-48-P10</a>      | \$70.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-128-P10</a>     | \$88.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-210-P10</a>     | \$61.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 10 in [254 mm]               |
| <a href="#">PMKG-310-P10</a>     | \$68.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 10 in [254 mm]               |
| <a href="#">PMKG-410-P10</a>     | \$72.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 10 in [254 mm]               |
| <a href="#">PMKG-1210-P10</a>    | \$91.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 10 in [254 mm]               |
| <a href="#">PMKG-212-P10</a>     | \$62.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 12 in [305 mm]               |
| <a href="#">PMKG-312-P10</a>     | \$70.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 12 in [305 mm]               |
| <a href="#">PMKG-412-P10</a>     | \$73.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 12 in [305 mm]               |
| <a href="#">PMKG-1212-P10</a>    | \$94.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 12 in [305 mm]               |
| <a href="#">PMKG-214-P10</a>     | \$65.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 14 in [354 mm]               |
| <a href="#">PMKG-314-P10</a>     | \$73.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 14 in [354 mm]               |
| <a href="#">PMKG-414-P10</a>     | \$79.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 14 in [354 mm]               |
| <a href="#">PMKG-1214-P10</a>    | \$95.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 14 in [354 mm]               |
| <a href="#">PMKG-216-P10</a>     | \$69.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <a href="#">PMKG-316-P10</a>     | \$77.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <a href="#">PMKG-416-P10</a>     | \$86.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <a href="#">PMKG-1216-P10</a>    | \$97.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <a href="#">PMKG-12-IMP-P10*</a> | \$37.50 | 2 in [51 mm] to 12 in [305 mm] | Plastic tie wrap and mount adapter; plated steel fasteners                      | 4 in [102 mm]                |
| <a href="#">PMKG-26-IMP-P10</a>  | \$56.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-36-IMP-P10</a>  | \$68.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-46-IMP-P10</a>  | \$70.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-126-IMP-P10</a> | \$87.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 6 in [152 mm]                |
| <a href="#">PMKG-28-IMP-P10</a>  | \$61.00 | 2 in [51 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-38-IMP-P10</a>  | \$68.00 | 3 in [76 mm]                   | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-48-IMP-P10</a>  | \$70.00 | 4 in [102 mm]                  | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |
| <a href="#">PMKG-128-IMP-P10</a> | \$88.00 | 9.5 to 12 in [241 to 305 mm]   | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 8 in [203 mm]                |

Notes: Dimensions in inches [millimeters].

All kits include galvanized steel strut rails and plated steel fasteners, except PMKG-12-IMP-P10, which does not have strut rails.

# Polycarbonate Enclosures

## Pole-Mounting Kits



### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Pole Mounting Kits for Integra Genesis Series Enclosures

| Part Number                     | Price   | Pole Diameter                | Kit Includes  | For Use With Enclosure Width |
|---------------------------------|---------|------------------------------|---|------------------------------|
| <b><u>PMKG-216-GEN-P10</u></b>  | \$70.00 | 2 in [51 mm]                 | Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <b><u>PMKG-316-GEN-P10</u></b>  | \$78.00 | 3 in [76 mm]                 | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <b><u>PMKG-416-GEN-P10</u></b>  | \$87.00 | 4 in [102 mm]                | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <b><u>PMKG-1216-GEN-P10</u></b> | \$99.00 | 9.5 to 12 in [241 to 305 mm] | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 16 in [406 mm]               |
| <b><u>PMKG-224-P10</u></b>      | \$64.00 | 2 in [51 mm]                 | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 24 in [102 mm]               |
| <b><u>PMKG-324-P10</u></b>      | \$70.00 | 3 in [76 mm]                 | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 24 in [102 mm]               |
| <b><u>PMKG-424-P10</u></b>      | \$77.00 | 4 in [102 mm]                | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 24 in [102 mm]               |
| <b><u>PMKG-1224-P10</u></b>     | \$94.00 | 9.5 to 12 in [241 to 305 mm] | Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners | 24 in [102 mm]               |

# Polycarbonate Enclosures – Accessories



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Slotted DIN Rail 35mm x 7mm Plated Steel

| Part Number                          | Price   | Length      | For Use With                        |
|--------------------------------------|---------|-------------|-------------------------------------|
| <a href="#"><u>DIN4-IMP-P10</u></a>  | \$18.00 | 3.82 [97]   | 4in wide Impact series enclosures   |
| <a href="#"><u>DIN6-IMP-P10</u></a>  | \$18.00 | 4.88 [124]  | 6in wide Impact series enclosures   |
| <a href="#"><u>DIN8-IMP-P10</u></a>  | \$24.50 | 6.75 [171]  | 8in wide Impact series enclosures   |
| <a href="#"><u>DIN6-P10</u></a>      | \$18.00 | 4.88 [124]  | 6in wide Premium series enclosures  |
| <a href="#"><u>DIN8-P10</u></a>      | \$24.50 | 6.75 [171]  | 8in wide Premium series enclosures  |
| <a href="#"><u>DIN10-P10</u></a>     | \$25.50 | 8.88 [225]  | 10in wide Premium series enclosures |
| <a href="#"><u>DIN12-P10</u></a>     | \$33.00 | 10.75 [273] | 12in wide Premium series enclosures |
| <a href="#"><u>DIN14-P10</u></a>     | \$36.00 | 12.75 [324] | 14in wide Premium series enclosures |
| <a href="#"><u>DIN16-P10</u></a>     | \$39.00 | 15.00 [381] | 16in wide Premium series enclosures |
| <a href="#"><u>DIN16-GEN-P10</u></a> | \$39.00 | 16.8 [427]  | 16in wide Genesis series enclosures |
| <a href="#"><u>DIN24-P10</u></a>     | \$62.00 | 23.63 [600] | 24in wide Genesis series enclosures |

Notes: Each item includes (2) DIN rails and mounting hardware.  
Dimensions in inches [millimeters].



## Mounting Feet Kits

| Part Number                      | Price   | Material            | For Use With              |
|----------------------------------|---------|---------------------|---------------------------|
| <a href="#"><u>MFKG-P10</u></a>  | \$16.25 | polycarbonate       | Premium series enclosures |
| <a href="#"><u>MFKSS-P10</u></a> | \$45.00 | 304 stainless steel | Premium series enclosures |

Note: Each kit includes (4) mounting feet and mounting hardware.



## Screw Packs (10 Pcs)

| Part Number                             | Price   | Screw Type        | Size                | Screw Head        | For Use With   |
|---|---------|-------------------|---------------------|-------------------|--|
| <a href="#"><u>SP-8-P10</u></a>         | \$12.25 | 25-thread cutting | #8 x 3/8 in         | Phillips pan head | 4in and 6in wide Impact series enclosures                |
| <a href="#"><u>SP-10I-P10</u></a>       | \$14.00 | 25-thread cutting | #10 x 3/8 in        | Phillips pan head | 8in wide Impact series and all Premium series enclosures |
| <a href="#"><u>GMFLK-SCREWS-P10</u></a> | \$25.50 | Machine-screw     | 1/4-20 UNC x 1/2 in | Phillips pan head | Genesis series mounting flanges                          |
| <a href="#"><u>GSP10-P10</u></a>        | \$14.50 | 25-thread cutting | #10 x 1/2 in        | Phillips pan head | Genesis series polycarbonate enclosures                  |



SP-8-P604



GMFLK-SCREWS-P10

# Polycarbonate Enclosures – Accessories



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Outdoor Labyrinth Vent

| Part Number              | Price   | Material      | Dimension HxWxD                   | For Use With                                  |
|--------------------------|---------|---------------|-----------------------------------|---|
| <b><u>VENT-2-P10</u></b> | \$15.75 | polypropylene | 2.72 x 2.03 x 0.88 [69 x 52 x 22] | Impact, Premium and Genesis series enclosures |

Notes: Installation of vent de-rates enclosure to NEMA 3R.  
Dimensions in inches [millimeters].



## Replacement Quick-Release Latches

| Part Number                    | Price   | Latch Material      | For Use With                          |
|--------------------------------|---------|---------------------|---------------------------------------|
| <b><u>SSLL-KIT-P10</u></b>     | \$25.50 | 304 stainless steel | Premium and Genesis series enclosures |
| <b><u>KIT-GPCL-2PK-P10</u></b> | \$25.00 | glass-filled nylon  | Genesis series enclosures (set of 2)  |



SSLL-KIT-P10



KIT-GPCL-2PK-P10