

# KILLARK Accessories and Replacement Parts

## Sealing Fitting

The purpose of seals in a Class I hazardous location is to minimize the passage of gases and vapors and prevent the passage of flames from one electrical installation to another through the conduit system. Consult the electrical code or your local inspector for more detailed information.




**ENY-2**  
Sealing Fitting

| ENY-2 Sealing Fitting Dimensions |         |                 |                    |             |                 |
|----------------------------------|---------|-----------------|--------------------|-------------|-----------------|
| Part Number                      | Price   | Hub Size (inch) | Dimensions (in-mm) |             | Turning Radius* |
|                                  |         |                 | A                  | B           |                 |
| <b>ENY-2</b>                     | \$30.50 | 3/4             | 4-1/16 (103)       | 2-1/16 (52) | 1-9/32 (33)     |

\*Use Turning Radius to help determine if sealing fitting will fit properly in your installation.

### ENY-2 Sealing Fitting

- Suitable for vertical or horizontal installation
- Copper-free aluminum (less than 0.4 %)
- Electro-statically applied powder coating

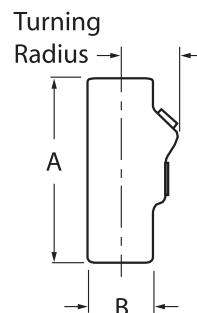

## Sealing Compound and Packing Fiber

| Ounces Required per Fitting |                 |                  |               |
|-----------------------------|-----------------|------------------|---------------|
| Sealing Fitting             | Hub Size (inch) | Sealing Compound | Packing Fiber |
| <b>ENY-2</b>                | 3/4             | 2 oz.            | 1/8 oz.       |

### Sealing Compound

SC series sealing compound is a cement used extensively for sealing conduit to prevent the spread of explosive gases.

- Non-shrinking and forms a secure seal
- Resists acids, water, oil, etc.
- UL listed when used with ENY series sealing fittings
- CE certified when used with any CSA certified sealing fitting

| Sealing Compound |         |                   |
|------------------|---------|-------------------|
| Part Number      | Price   | Size              |
| <b>SC-4-OZ</b>   | \$12.00 | 4-ounce container |
| <b>SC-8-OZ</b>   | \$12.00 | 8-ounce container |
| <b>SC-1-LB</b>   | \$22.00 | 1-pound container |



Sealing Compound

### Packing Fiber

- Made from environmentally safe, non-asbestos material
- Easy to use and forms a positive dam to hold sealing compound

| Packing Fiber |          |                   |
|---------------|----------|-------------------|
| Part Number   | Price    | Size              |
| <b>PF-2</b>   | \$29.00  | 2-ounce container |
| <b>PF-4</b>   | \$52.00  | 4-ounce container |
| <b>PF-16</b>  | \$153.00 | 1-pound container |



Packing Fiber

# KILLARK Accessories and Replacement Parts - Continued

## Accessories and Replacement Parts Overview

We offer an accessory blank cover, a large selection of legend plates, and replacement keys and LEDs.

Replacement contacts are not available for any of our Killark hazardous duty controls. We also do not offer replacement switches, covers, or bolts.

## Blank Cover and Replacement Key



**X-10**  
Blank Cover



**KEY-C002B**  
Replacement Key

| Blank Cover and Replacement Key |         |                     |                                                                         |
|---------------------------------|---------|---------------------|-------------------------------------------------------------------------|
| Part Number                     | Price   | Drawing Link        | Description                                                             |
| <b><u>X-10</u></b>              | \$68.00 | <a href="#">PDF</a> | Blank cover for use with splice/device boxes.                           |
| <b><u>KEY-C002B</u></b>         | \$14.50 | N/A                 | Replacement key for FXCS and XCS series key-operated selector switches. |

## Replacement LED Lamps



Replacement 110 VAC/VDC LED lamps for FXCS and XCS series pilot lights.

| Replacement LED Lamps    |         |       |             |
|--------------------------|---------|-------|-------------|
| Part Number              | Price   | Color | Volts AC/DC |
| <b><u>GOLED-A110</u></b> | \$66.00 | Amber | 110 VAC/VDC |
| <b><u>GOLED-G110</u></b> | \$66.00 | Green |             |
| <b><u>GOLED-R110</u></b> | \$66.00 | Red   |             |
| <b><u>GOLED-W110</u></b> | \$66.00 | White |             |